


Server enclosures TE 7000

Catalogue 33, page 117

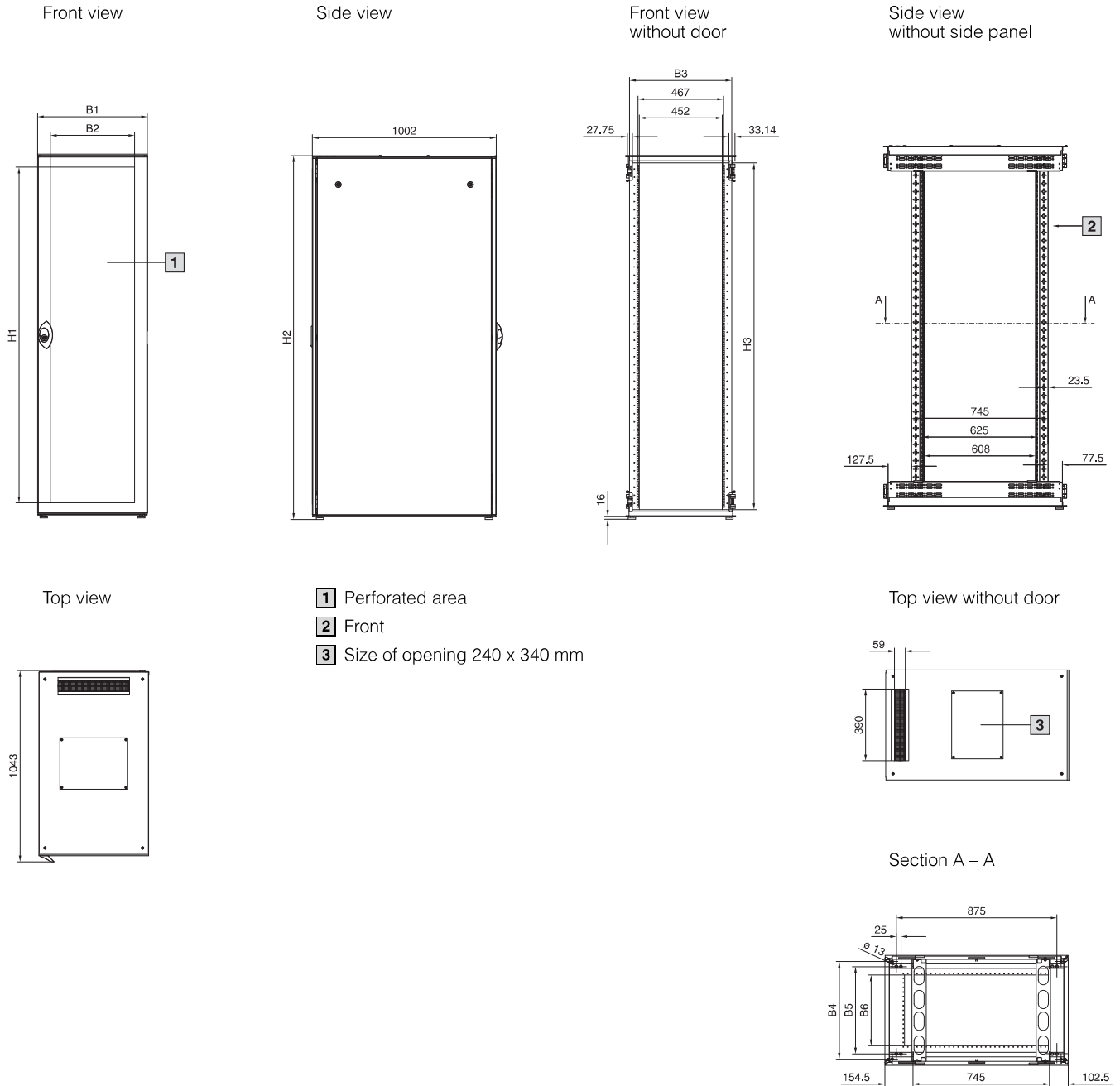

| Model No. DK | U | Width dimensions mm | | | | | | Height dimensions mm | | |
|--------------|----|---------------------|-------|-----|-----|-----|-----|----------------------|------|------|
| | | B1 | B2 | B3 | B4 | B5 | B6 | H1 | H2 | H3 |
| 7000.875 | 21 | 599 | 459.6 | 557 | 532 | 475 | 385 | 1025 | 1182 | 1090 |
| 7000.882 | 42 | 599 | 459.6 | 557 | 532 | 475 | 385 | 1830 | 1982 | 1890 |
| 7000.885 | 42 | 599 | 459.6 | 557 | 532 | 475 | 385 | 1830 | 1982 | 1890 |
| 7000.892 | 42 | 799 | 661.7 | 757 | 732 | 675 | 585 | 1830 | 1982 | 1890 |
| 7000.895 | 42 | 799 | 661.7 | 757 | 732 | 675 | 585 | 1830 | 1982 | 1890 |