


Jakokaapit

TE 7000 avoin Pääluettelo 33, sivu 110


DK 7000.940

Edestä

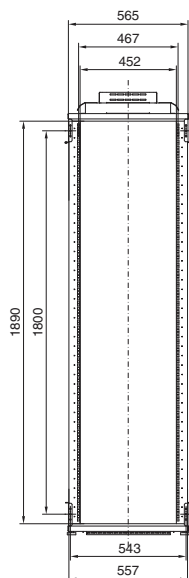


DK 7000.944

Edestä

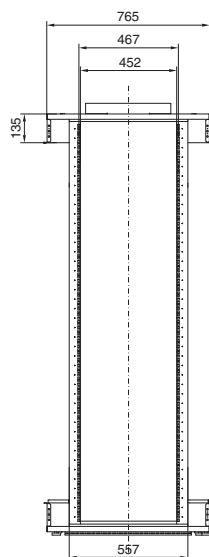


Sivulta

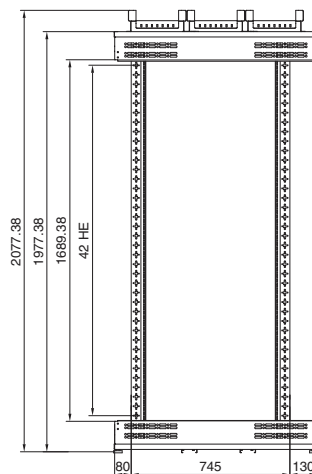


HE = U

Ylhäältä

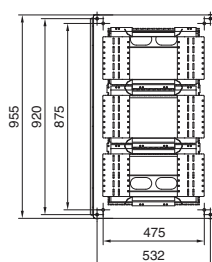


Ylhäältä

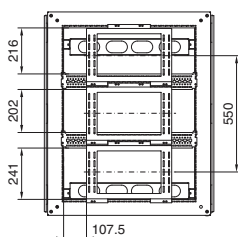


Data Rack Pääluettelo 33, sivu 111

Edestä

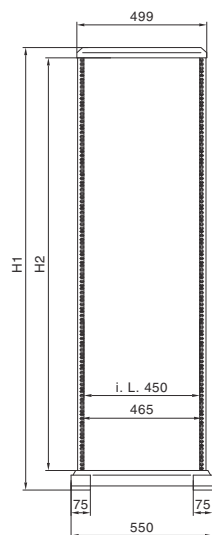

i.L. = Sisämitta

Sivulta

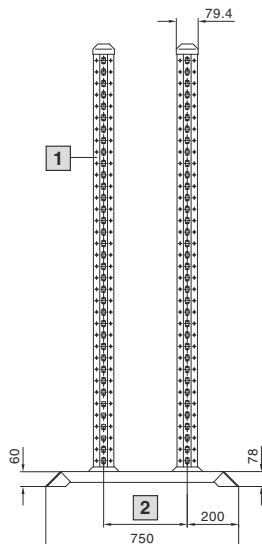

- 1 Toinen kiinnitystaso
DK 7296.000/31 U
DK 7297.000/36 U
DK 7298.000/40 U
DK 7299.000/45 U
- 2 50 mm rasterissa
(min. 150 – maks. 350)

Til.nro DK	U	Korkeusmitta mm	
		H1	H2
7391.000	31	1500	i.L. 1382
7396.000	36	1722	i.L. 1604
7400.000	40	1900	i.L. 1782
7445.000	45	2122	i.L. 2004