
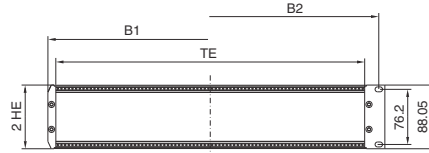




### Ripac Vario-Modul

Päälueetelo 33, sivu 252 – 255



2 U

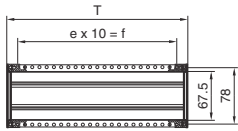



3 U

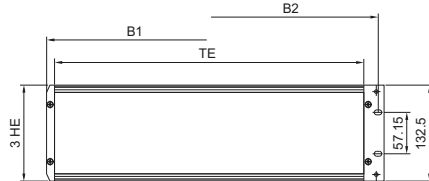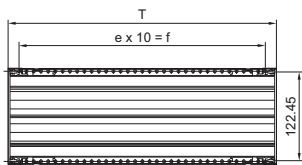



4 U

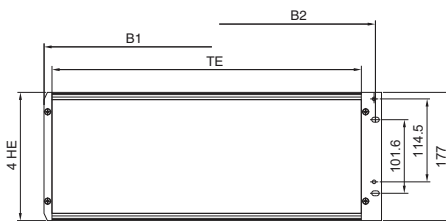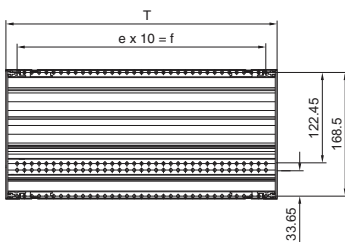

6 U

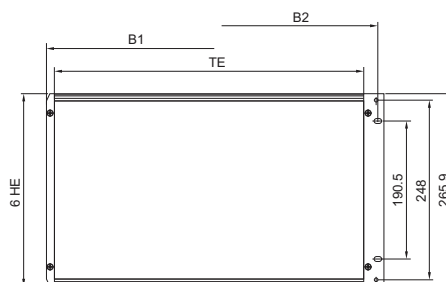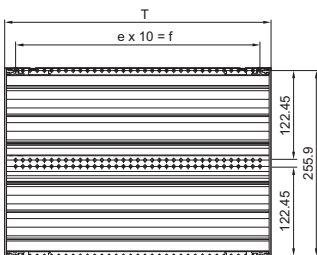

7 U

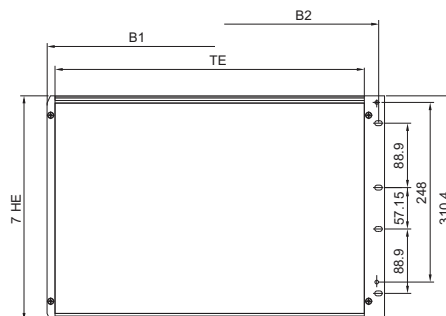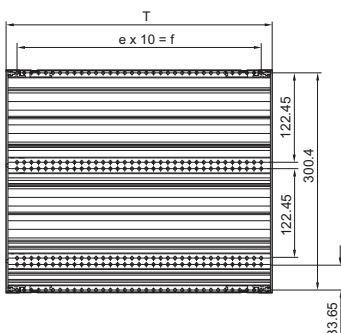

Til.nro VM	U	TE	T mm	e	B1 mm	B2 mm
3982.040	3	42	250,4	22	235,6	251,6
3982.070	3	42	310,4	28	235,6	251,6
3982.050	3	63	250,4	22	342,3	358,3
3982.080	3	63	310,4	28	342,3	358,3
3982.060	3	84	250,4	22	449,0	465,1
3982.090	3	84	310,4	28	449,0	465,1
3982.100	3	84	370,4	34	449,0	465,1
3982.110	4	84	250,4	22	449,0	465,1
3982.120	4	84	310,4	28	449,0	465,1
3982.130	4	84	370,4	34	449,0	465,1
3982.140	6	84	310,4	28	449,0	465,1
3982.150	6	84	370,4	34	449,0	465,1
3982.160	6	84	430,4	40	449,0	465,1
3982.170	7	84	310,4	28	449,0	465,1
3982.190	7	84	430,4	40	449,0	465,1

Til.nro VM (EMC)	U	TE	T mm	e	B1 mm	B2 mm
3983.040	3	42	250,4	22	235,6	251,6
3983.070	3	42	310,4	28	235,6	251,6
3983.050	3	63	250,4	22	342,3	358,3
3983.080	3	63	310,4	28	342,3	358,3
3983.030	2	84	310,4	28	449,0	465,1
3983.090	3	84	310,4	28	449,0	465,1
3983.100	3	84	370,4	34	449,0	465,1
3983.120	4	84	310,4	28	449,0	465,1
3983.130	4	84	370,4	34	449,0	465,1
3983.140	6	84	310,4	28	449,0	465,1
3983.150	6	84	370,4	34	449,0	465,1
3983.160	6	84	430,4	40	449,0	465,1

B = Leveys  
T = Syvyys  
HE = U