


Kyt kentäkaapit

Pöytäkotelo


RiCase

269,2 mm (1½ 19") Pääluettelo 33, sivu 258


482,6 mm (19") Pääluettelo 33, sivu 259

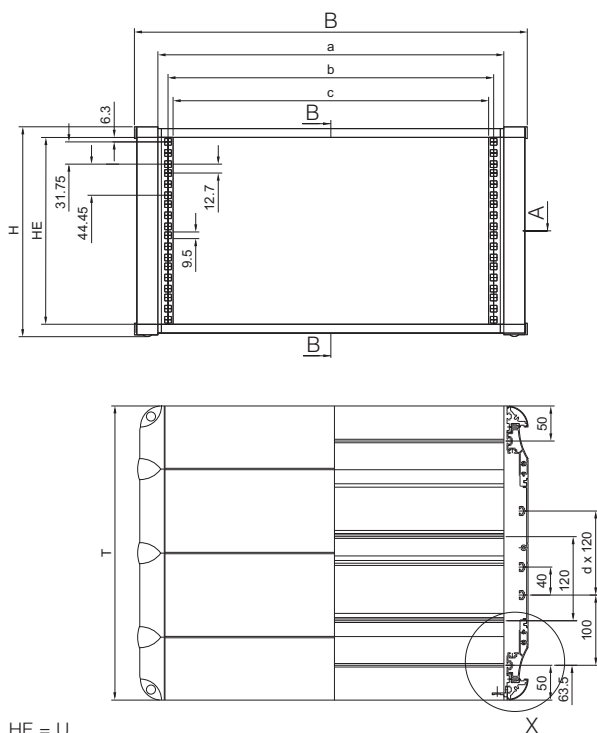

Leikkaus B – B

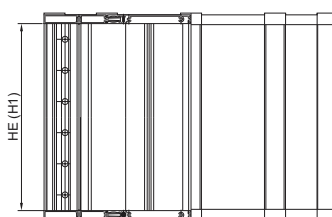

Detalji X

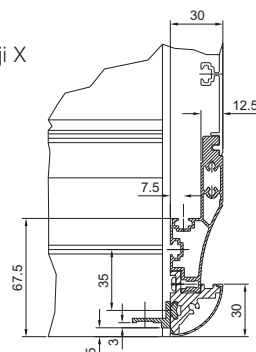

HE = U

RiCase 269,2 mm (1½ 19")

tuulettamaton			
Til.nro RC	3750.200	3750.210	3750.400
U	2	3	4
Leveys (B) mm	348,6	348,6	348,6
Korkeus (H) mm	121,9	166,4	210,8
H1 (U) mm	89,4	133,8	178,3
Syvyys (T) mm	300,0	300,0	420,0
a mm	280,6	280,6	280,6
b mm	251,6	251,6	251,6
c mm	237,2	237,2	237,2
d	–	–	1

RiCase 482,6 mm (19")

tuulettamaton										
Til.nro RC	3750.310	3750.320	3750.420	3750.600	3750.610	3750.620	–	3750.710	–	3750.000
tuuletetty										
Til.nro RC	3750.330	3750.340	3750.440	–	3750.640	3750.650	3750.720	3750.730	3750.930	3750.030
U	3		4	6			7		9	12
Leveys (B) mm	562,0	562,0	562,0	562,0	562,0	562,0	562,0	562,0	562,0	562,0
Korkeus (H) mm	166,4	166,4	210,8	299,7	299,7	299,7	344,2	344,2	433,1	566,5
H1 (U) mm	133,8	133,8	178,3	267,2	267,2	267,2	311,7	311,7	400,6	534,0
Syvyys (T) mm	300,0	420,0	420,0	300,0	420,0	540,0	420,0	540,0	540,0	540,0
a mm	494,0	494,0	494,0	494,0	494,0	494,0	494,0	494,0	494,0	494,0
b mm	465,0	465,0	465,0	465,0	465,0	465,0	465,0	465,0	465,0	465,0
c mm	450,6	450,6	450,6	450,6	450,6	450,6	450,6	450,6	450,6	450,6
d	–	1	1	–	1	2	1	2	2	2