


TFT holder

2383.030

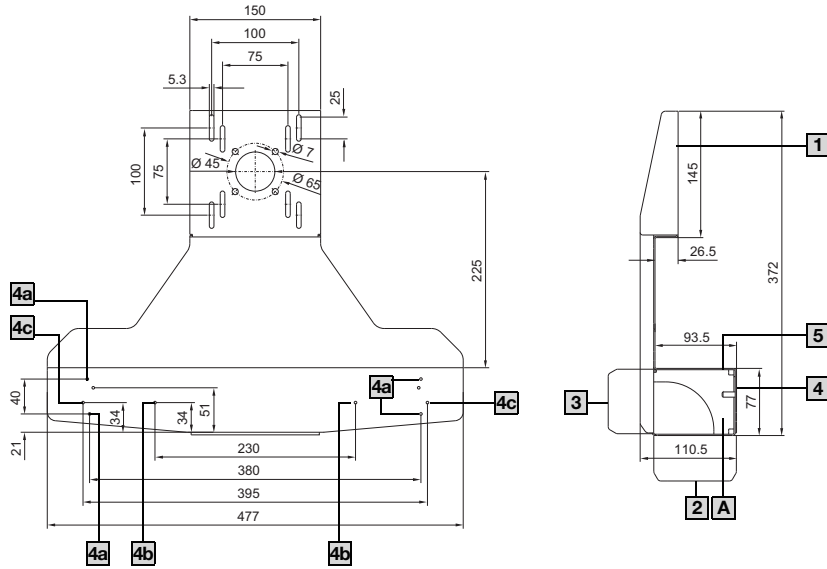

View **A**

Mounting cut-out
□ 90 x 71 mm



Mounting cut-out
□ 120 x 65 mm



1

- VESA 75 or 100 rigid
- VESA 75 and tilt adjustment via IW 6206.460

2

- Enclosure attachment/housing coupling with support arm connection
- □ 90 x 71 mm
- □ 120 x 65 mm

3

- Enclosure attachments on the horizontal support arm CP 40, steel or □ 120 x 65 mm, for mounting on the vertical support arm via tilt adjuster IW 6206.460
- □ 120 x 65 mm

4

- Support for keyboards SM 2383.000 via enclosure surface connector SM 2383.010

4a

- U handle CP 6107.100

4c

- U handle CP 6107.200

via marked points

5

- Connector gland SZ 2400.300/.500 as strain relief for the connection cable