 


Climate control


Enclosure heaters

Enclosure heaters

Without fan



With fan

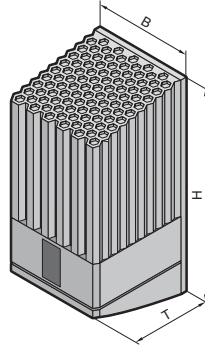

Without fan


Model No. SK	W (B) mm	H mm	D (T) mm
3105.310	45	120	46
3105.320	45	120	46
3105.330	64	155	56
3105.340	64	155	56
3105.350	64	230	56
3105.360	90	165	75
3105.370	90	180	75

With fan


Model No. SK	W (B) mm	H mm	D (T) mm
3105.380	103	200	103
3105.390	103	200	103
3105.400	103	200	103
3105.410	103	200	103
3105.420	103	200	103
3105.430	103	200	103

SK 3105.380 – SK 3105.430

Attachment on mounting plate

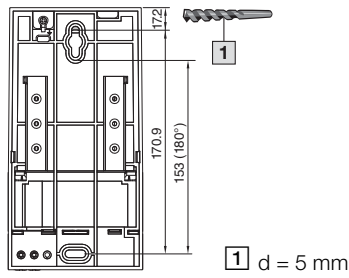


Mounting options on support rail

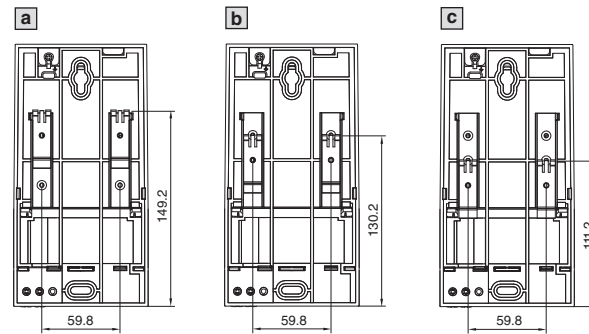


SK 3105.310/SK 3105.320

Attachment on mounting plate

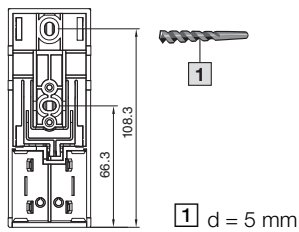


SK 3105.330/SK 3105.340

Attachment on mounting plate

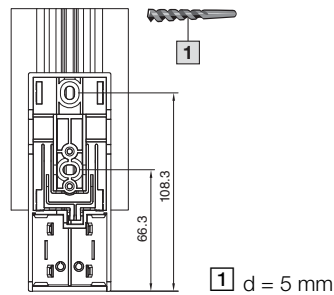


SK 3105.350/SK 3105.360/SK 3105.370


Attachment on mounting plate

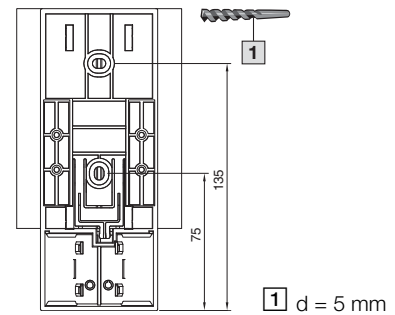

Mounting options on support rail

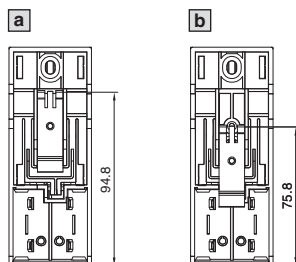

Mounting options on support rail

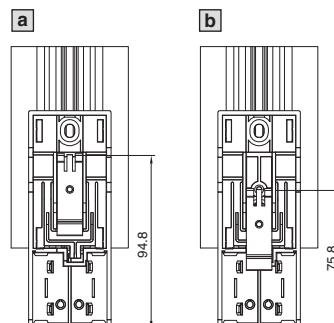

Mounting options on support rail

