
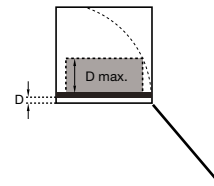
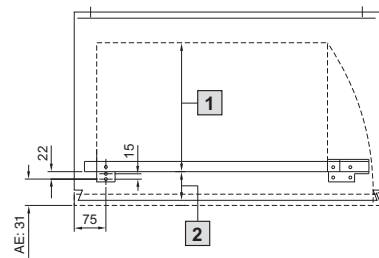


Compact-zwenkraam voor AE

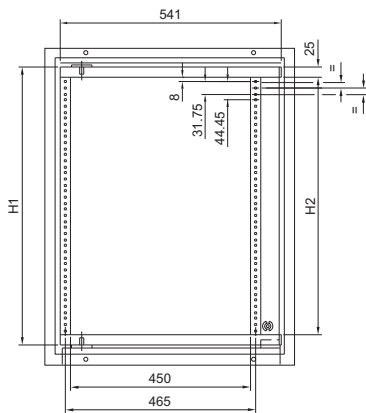

- 1** T = max. inbouwdiepte (zie tabel)
- 2** D = 38 (53, 68, 83)

Voor wandkasten AE			Hoogte-eenheden	6 HE	11 HE	14 HE
Kast		Max. inbouwdiepte (T max.) mm	Bestelnr. SR	2026.200	2027.200	2034.200
Breedte mm	Diepte mm		Voor kasthoogte mm	380	600	760
			H1 (mm)	320	542	676
			H2 (mm)	270	492	626
600	210	145	Gelakt	1039.500	1060.500	1076.500
			Roestvaststaal	1009.600	1010.600	1012.600
600	350	265	Gelakt	1339.500	1360.500	1376.500
760	210	145	Gelakt	-	-	1077.500
760	300	235	Gelakt	-	-	1073.500
			Roestvaststaal	-	-	1014.600