
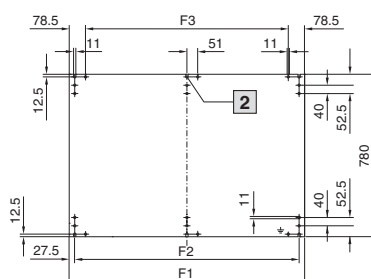
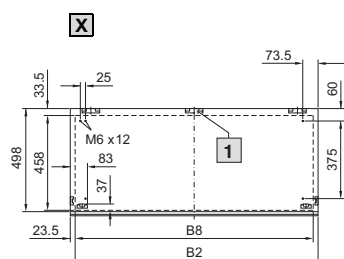
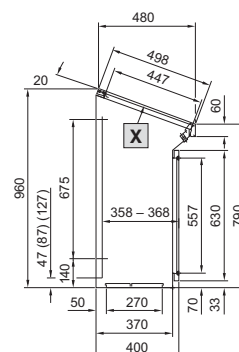
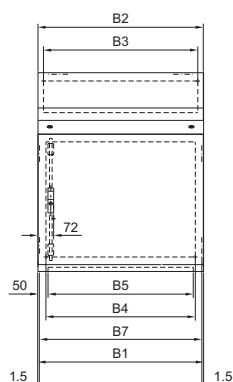


Standerpulte

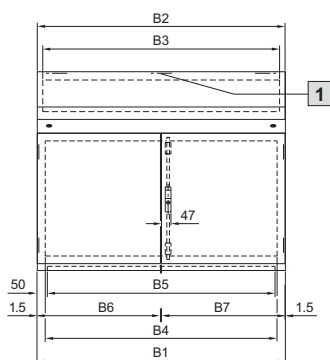

- 1** Hængsel kun ved TP 2686.600
- 2** Bortfalder ved TP 2683.600/
TP 2684.600
- X** Låg set indefra

| Best.nr. TP | 2683.600 | 2684.600 | 2685.600 | 2686.600 |
|----------------------------|----------|----------|----------|----------|
| Bredde (B1) mm | 600 | 800 | 1000 | 1200 |
| Højde mm | 960 | | | |
| Dybde mm | 400 /480 | | | |
| B2 = Bredde låg | 597 | 797 | 997 | 1197 |
| B3 = Indv. bredde foroven | 544 | 744 | 944 | 1144 |
| B4 = Indv. bredde fortil | 524 | 724 | 924 | 1124 |
| B5 = Indv. bredde forned | 500 | 700 | 900 | 1100 |
| B6 = Bredde sidelåge | - | - | 495 | 595 |
| B7 = Bredde affåselig låge | 597 | 797 | 997 | 1197 |
| B8 = Strækning med huller | 500 | 700 | 900 | 1100 |
| F1 = Montagepladebredde | 530 | 730 | 930 | 1130 |
| F2 = Afstand montagehuller | 475 | 675 | 875 | 1075 |
| F3 = Afstand montagehuller | 373 | 573 | 773 | 973 |