
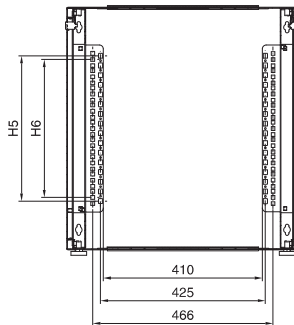
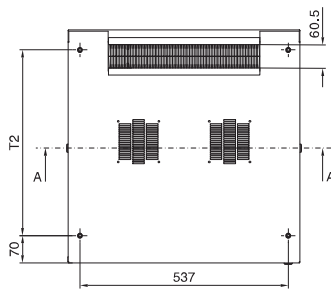
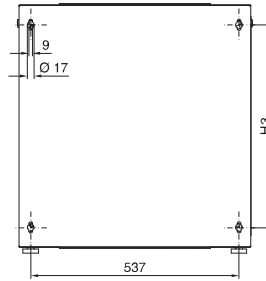
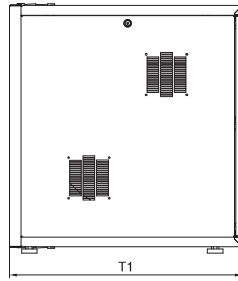



FlatBox

Mit 19"-Profilschienen Handbuch 33, Seite 57

Mit 19"-Montagerahmen Handbuch 33, Seite 58

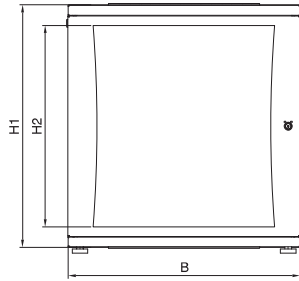




Version 21 U/700 x 700

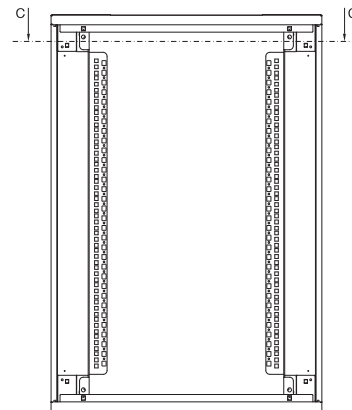

Schnitt A – A

Schnitt B – B

Schnitt C – C

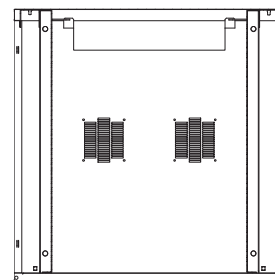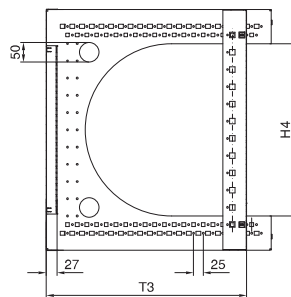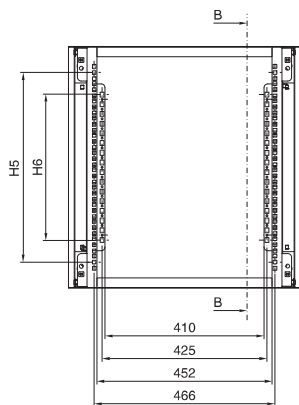

Best.-Nr. DK	HE	Breitenmaße mm			Höhenmaße mm					Tiefenmaße mm		
		B	H1	H2	H3	H4	H5	H6	H7	T1	T2	T3
7507.000	6	600	365,1	252,7	255,6	177,8	266,7	125	88,9	400	279	342
7507.100	6	600	365,1	252,7	255,6	177,8	266,7	125	88,9	600	279	542
7507.010	9	600	498,5	386,1	389	311,2	400,1	250	222,3	400	379	342
7507.110	9	600	498,5	386,1	389	311,2	400,1	250	222,3	600	379	542
7507.020	12	600	631,8	519,4	522,3	444,5	533,4	375	355,6	400	479	342
7507.120	12	600	631,8	519,4	522,3	444,5	489	375	355,6	600	479	542
7507.030	15	600	765,2	652,8	655,7	577,9	666,8	525	489	400	579	342
7507.200	15	700	765,2	652,8	655,7	577,9	666,8	525	489	700	579	642
7507.210	18	700	898,5	736,1	789	711,2	800,1	650	622,3	700	579	642
7507.220	21	700	1031,9	869,5	922,4	844,6	933,5	775	755,7	700	579	642