
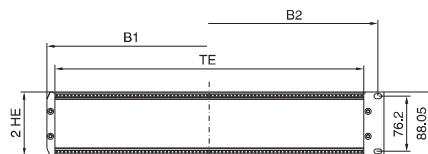




Ripac Vario-Modul

Handbuch 33, Seite 252 – 255



2 HE

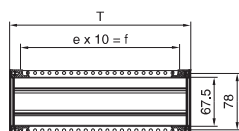



3 HE

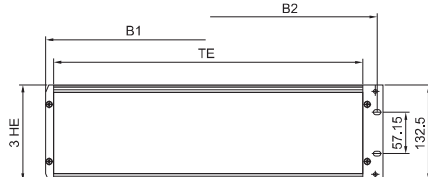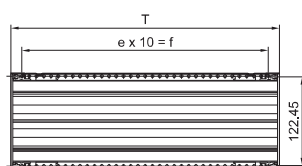



4 HE

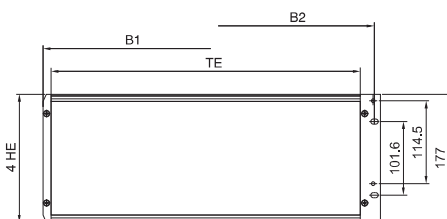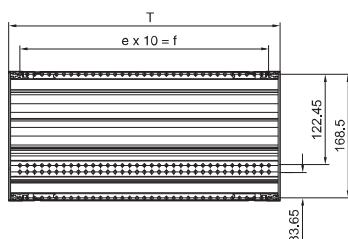

6 HE

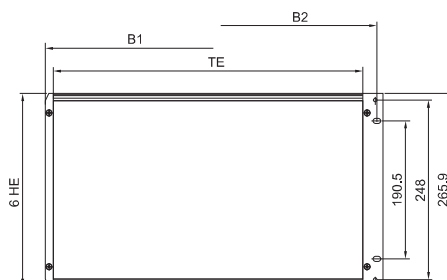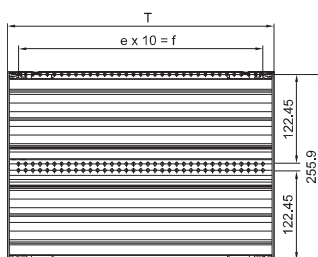

7 HE

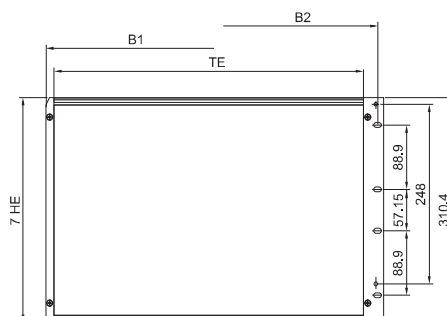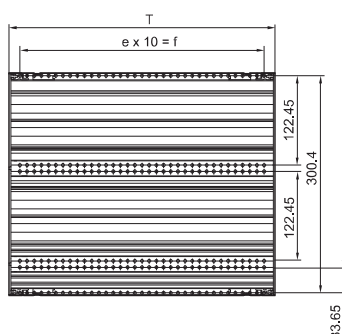

Best.-Nr. VM	HE	TE	T mm	e	B1 mm	B2 mm
3982.040	3	42	250,4	22	235,6	251,6
3982.070	3	42	310,4	28	235,6	251,6
3982.050	3	63	250,4	22	342,3	358,3
3982.080	3	63	310,4	28	342,3	358,3
3982.060	3	84	250,4	22	449,0	465,1
3982.090	3	84	310,4	28	449,0	465,1
3982.100	3	84	370,4	34	449,0	465,1
3982.110	4	84	250,4	22	449,0	465,1
3982.120	4	84	310,4	28	449,0	465,1
3982.130	4	84	370,4	34	449,0	465,1
3982.140	6	84	310,4	28	449,0	465,1
3982.150	6	84	370,4	34	449,0	465,1
3982.160	6	84	430,4	40	449,0	465,1
3982.170	7	84	310,4	28	449,0	465,1
3982.190	7	84	430,4	40	449,0	465,1

Best.-Nr. VM (EMV)	HE	TE	T mm	e	B1 mm	B2 mm
3983.040	3	42	250,4	22	235,6	251,6
3983.070	3	42	310,4	28	235,6	251,6
3983.050	3	63	250,4	22	342,3	358,3
3983.080	3	63	310,4	28	342,3	358,3
3983.030	2	84	310,4	28	449,0	465,1
3983.090	3	84	310,4	28	449,0	465,1
3983.100	3	84	370,4	34	449,0	465,1
3983.120	4	84	310,4	28	449,0	465,1
3983.130	4	84	370,4	34	449,0	465,1
3983.140	6	84	310,4	28	449,0	465,1
3983.150	6	84	370,4	34	449,0	465,1
3983.160	6	84	430,4	40	449,0	465,1