


Schaltschränke

Tischgehäuse


RiCase

269,2 mm (1½ 19") Handbuch 33, Seite 258


482,6 mm (19") Handbuch 33, Seite 259

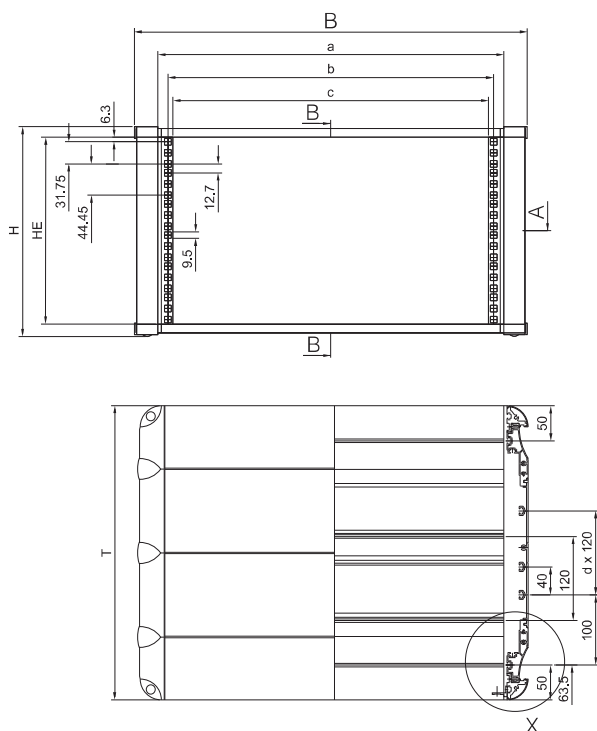

Schnitt B – B

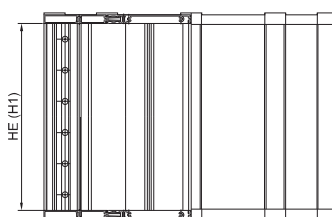

Einzelheit X

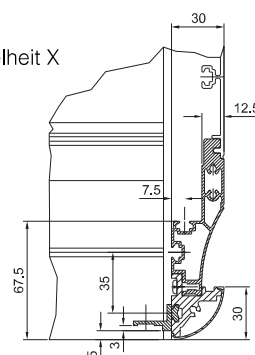

RiCase 269,2 mm (1½ 19")

unbelüftet			
Best.-Nr. RC	3750.200	3750.210	3750.400
HE	2	3	4
Breite (B) mm	348,6	348,6	348,6
Höhe (H) mm	121,9	166,4	210,8
H1 (HE) mm	89,4	133,8	178,3
Tiefe (T) mm	300,0	300,0	420,0
a mm	280,6	280,6	280,6
b mm	251,6	251,6	251,6
c mm	237,2	237,2	237,2
d	–	–	1

RiCase 482,6 mm (19")

unbelüftet										
Best.-Nr. RC	3750.310	3750.320	3750.420	3750.600	3750.610	3750.620	–	3750.710	–	3750.000
belüftet										
Best.-Nr. RC	3750.330	3750.340	3750.440	–	3750.640	3750.650	3750.720	3750.730	3750.930	3750.030
HE	3		4	6			7		9	12
Breite (B) mm	562,0	562,0	562,0	562,0	562,0	562,0	562,0	562,0	562,0	562,0
Höhe (H) mm	166,4	166,4	210,8	299,7	299,7	299,7	344,2	344,2	433,1	566,5
H1 (HE) mm	133,8	133,8	178,3	267,2	267,2	267,2	311,7	311,7	400,6	534,0
Tiefe (T) mm	300,0	420,0	420,0	300,0	420,0	540,0	420,0	540,0	540,0	540,0
a mm	494,0	494,0	494,0	494,0	494,0	494,0	494,0	494,0	494,0	494,0
b mm	465,0	465,0	465,0	465,0	465,0	465,0	465,0	465,0	465,0	465,0
c mm	450,6	450,6	450,6	450,6	450,6	450,6	450,6	450,6	450,6	450,6
d	–	1	1	–	1	2	1	2	2	2