




System accessories

482.6 mm (19") installation system

Swing frame, small

For 600 mm wide enclosures

For 800 mm wide enclosures optionally at the side or in the centre

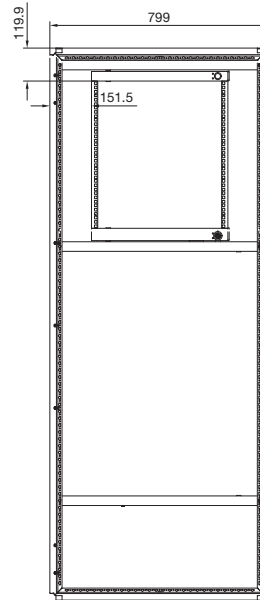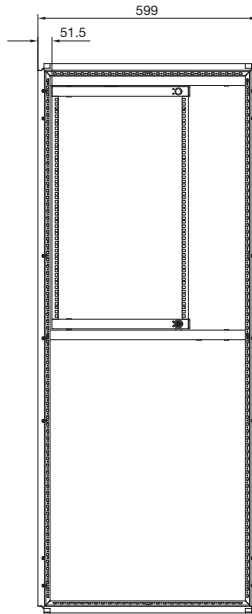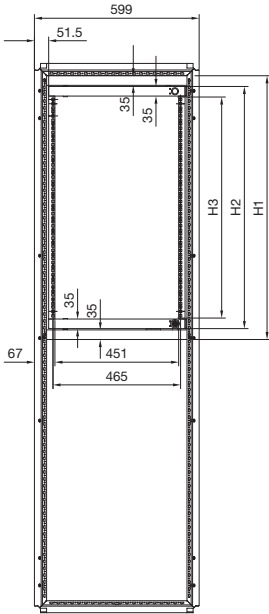

Height units	3 U	6 U	9 U	12 U	15 U	18 U
Model No. SR	8619.500	8619.510	8619.520	8619.530	8619.540	8619.550
H1 mm	285	435	560	685	835	960
H2 mm	206	356	481	606	756	881
H3 mm	136	286	411	536	686	811

Installation depth T max. = mm with dimension D¹⁾ of at least 45 mm

Enclosure width mm	600	800	800
Internal mounting	Centre	Side	Centre
Enclosure depth mm	1 T max.	1 T max.	1 T max.
400	185	310	310
500	185	410	370
≥ 600	185	500	370


¹⁾ D = Distance from inner edge of door to front edge of swing frame, may be installed deeper on a 25 mm pitch pattern

Swing frame, small


VX25 installation examples

Partial installation

in 600 and 800 mm wide enclosures, each in the highest or lowest position.

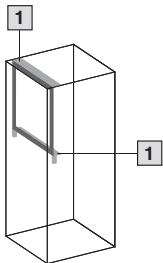


Front

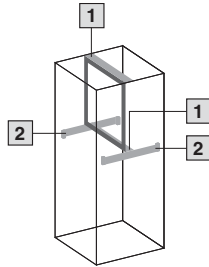


Set back

Partial installation, centre

in 600 and 800 mm wide enclosures.

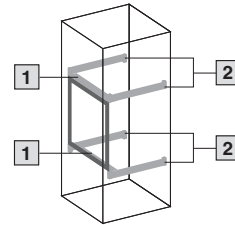

Front

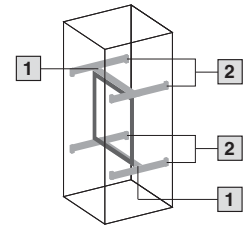


Set back

Side installation

With an enclosure depth of 600 or 800 mm, side installation of a small swing frame is identical to installation parallel to the front.

For access to the swing frame, we recommend hinges for the side panel.

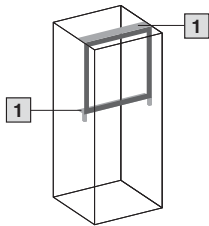

1 Installation kit for swing frame, small

2 Punched section with mounting flange, 23 x 64 mm