


System accessories

482.6 mm (19") installation system

Swing frame, large

Without trim panel

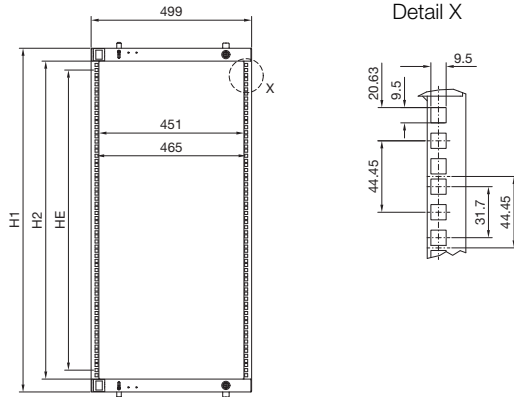

Height units	22 U	31 U	35 U	40 U	44 U
Model No. SR	8619.010	8619.011	8619.012	8619.013	8619.014
for enclosure height mm (or higher)	1200	1600	1800	2000	2200
H1 mm	1068	1468	1668	1868	2068
H2 mm	988	1388	1588	1788	1988
Depth mm	80	80	80	80	80

Installation depth T max. = mm with dimension D¹⁾ of at least 48 mm


Enclosure width mm	600	1200	1200
Internal mounting	Centre	Left or right	Left and right
Enclosure depth mm	1 T max.	1 T max.	1 T max.
400	210	295	295
500	210	395	360
600	210	495	360
800	210	695	360

¹⁾D = Distance from inner edge of door to front edge of swing frame, may be installed deeper on a 25 mm pitch pattern


Swing frame, large

Without trim panel, VX25 installation examples


Full installation

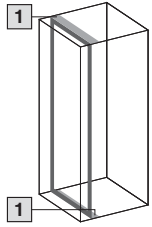


600 mm front

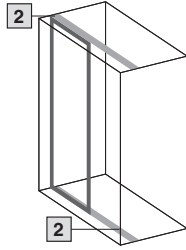

1200 mm front

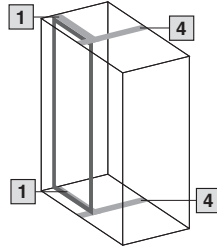


1200 mm front with system divider

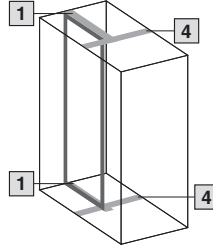


1200 mm set back with system divider

Side installation

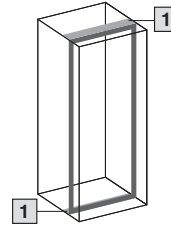


With an enclosure depth of 600 mm, side installation of a large swing frame is identical to installation parallel to the front. For access to the swing frame, we recommend hinges for the side panel.


Partial installation, top

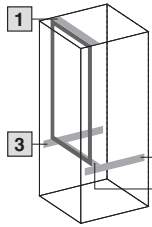


600 mm front

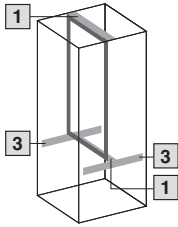

600 mm set back

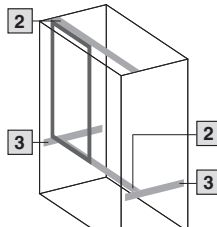


1200 mm front

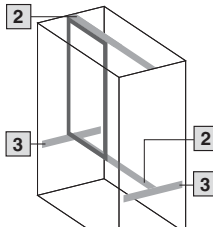


1200 mm set back

- 1 Installation kit for 600 mm wide enclosures
- 2 Installation kit for 1200 mm wide enclosures
- 3 Punched section with mounting flange, 23 x 64 mm
- 4 System divider


Partial installation, centre

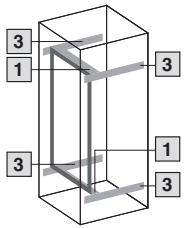


600 mm front

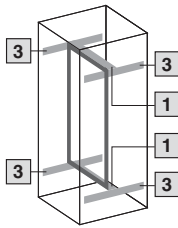

600 mm set back

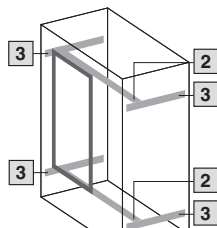

1200 mm front

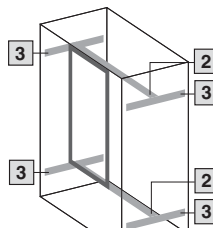

1200 mm set back


System accessories

482.6 mm (19") installation system


Swing frame, large

With trim panel


Mounting components, sides
(built into VX25)

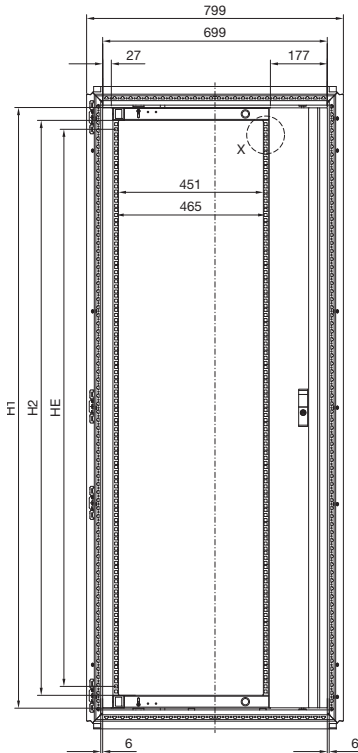

Mounting components, centre
(built into VX25)

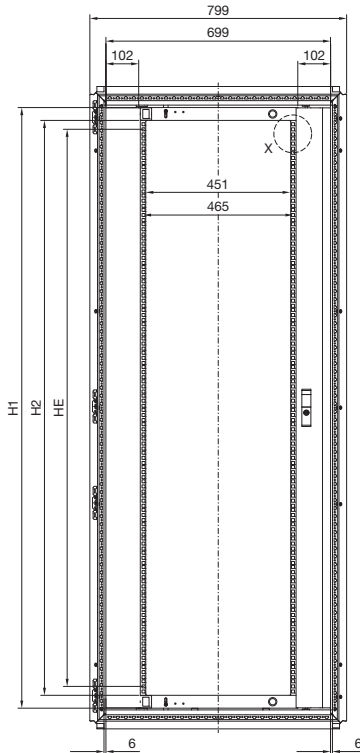

Detail X

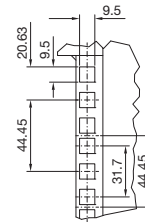

Height units	22 U		31 U		35 U		40 U		44 U		
	Side	Centre	Side	Centre	Side	Centre	Side	Centre	Side	Centre	
Trim panel											
Model No. SR	RAL 7035	8619.020	8619.030	8619.021	-	8619.022	8619.032	8619.023	8619.033	8619.024	8619.034
For enclosure height mm (or higher)		1200		1600		1800		2000		2200	
H1 mm		1068		1468		1668		1868		2068	
H2 mm		988		1388		1588		1788		1988	
Depth mm		80		80		80		80		80	

Installation depth T max. = mm with dimension D¹⁾ of at least 48 mm


Enclosure width mm	800			
Internal mounting	Side		Centre	
Hinge	130°	180°	130°	180°
Enclosure depth mm	1 T max.	1 T max.	1 T max.	1 T max.
400	295	260	265	150
500	395	360	370	250
600	470	440	370	330
800	470	440	370	330

¹⁾ D = Distance from inner edge of door to front edge of swing frame, may be installed deeper on a 25 mm pitch pattern


Swing frame, large

With trim panel, VX25 installation examples


Full installation

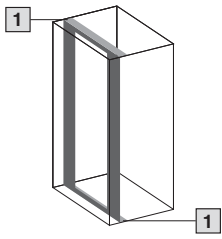

800 mm front

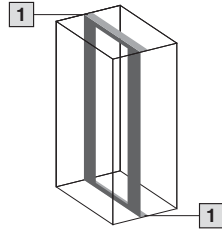


800 mm set back

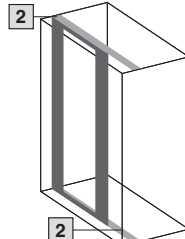


1200 mm front

Side installation

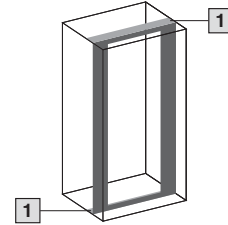


With an enclosure depth of 800 mm, side installation of a large swing frame is identical to installation parallel to the front. For access to the swing frame, we recommend hinges for the side panel.


Partial installation, top

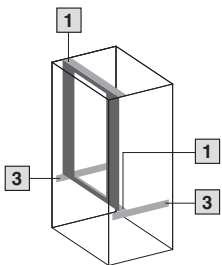

800 mm front

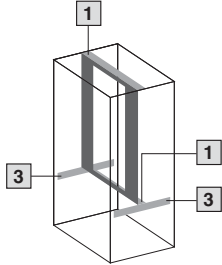


800 mm set back

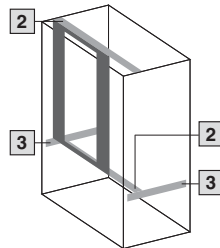


1200 mm front

- 1 Installation kit for 800 mm wide enclosures
- 2 Installation kit for 1200 mm wide enclosures
- 3 Punched section with mounting flange, 23 x 64 mm

Partial installation, centre

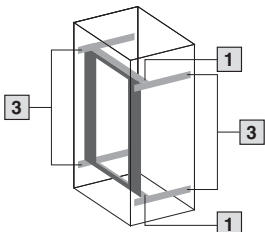

800 mm front

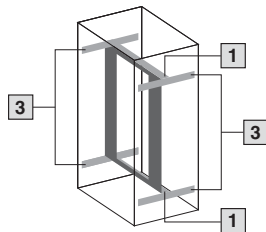

800 mm set back