


# Kytöntäkaapit

## Kaappijärjestelmät


### Rivikaappijärjestelmä VX25

Elektronikkakaappi


Näkymä etupuolelta ilman etukehystä

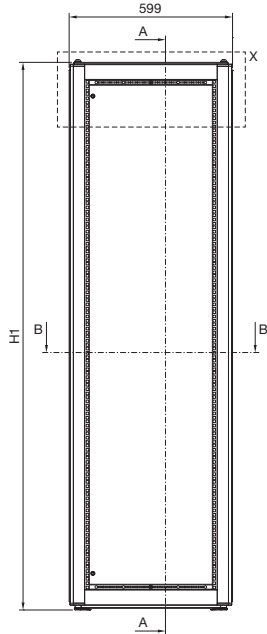


Leikkaus A – A

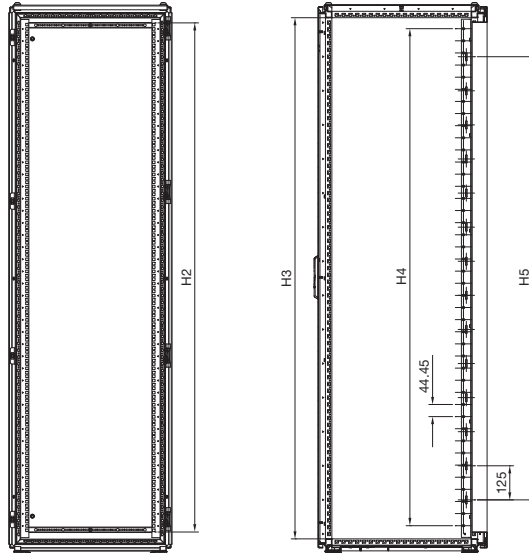


Detalji X

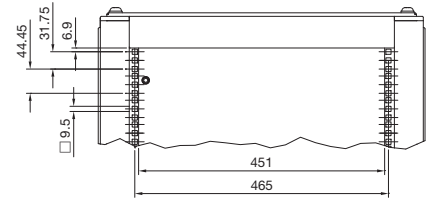

Detalji Y

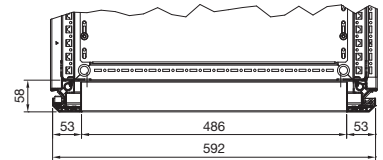

Leikkaus B – B

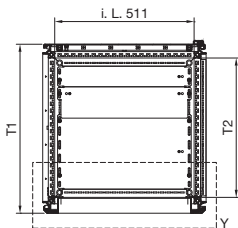

| Til.nro         | Korkeusmitat |        |    |            |         |    | Syvysmitat |          |           |
|-----------------|--------------|--------|----|------------|---------|----|------------|----------|-----------|
|                 | H1<br>mm     | H2     |    | H3<br>mm   | H4      |    | H5<br>mm   | T1<br>mm | T2<br>mm  |
|                 |              | mm     | U  |            | mm      | U  |            |          |           |
| <b>8410.000</b> | 1608         | 1466,6 | 33 | i. L. 1511 | 1422,4  | 32 | 1375       | 619,5    | i. L. 511 |
| <b>8418.000</b> | 1608         | 1466,6 | 33 | i. L. 1511 | 1422,4  | 32 | 1375       | 819,5    | i. L. 711 |
| <b>8430.000</b> | 2008         | 1866,9 | 42 | i. L. 1911 | 1822,45 | 41 | 1625       | 619,5    | i. L. 511 |
| <b>8438.000</b> | 2008         | 1866,9 | 42 | i. L. 1911 | 1822,45 | 41 | 1625       | 819,5    | i. L. 711 |

i.L. = vapaa tila