


Enclosures

IT enclosure systems


Network/server enclosures TS IT

with glazed door, pre-configured, with 482.6 mm (19") swing frame, width 800 mm


Front view

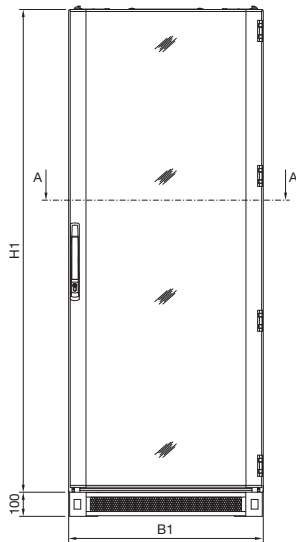


Side view

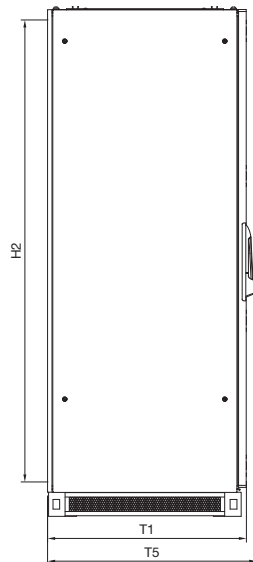


Rear view

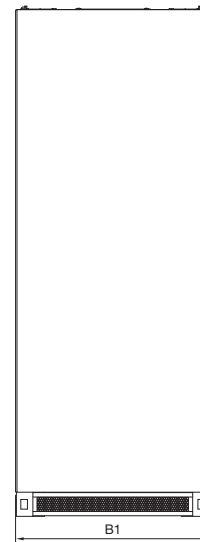

Top view

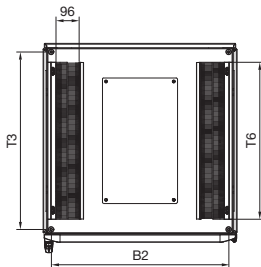

Section A – A

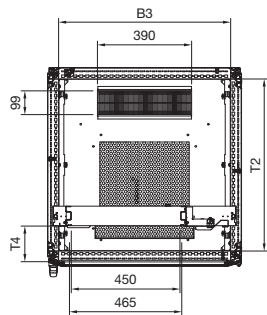

Enclosure

- B1 = Overall width
- B2 = Roof attachment spacing
- B3 = Clearance of enclosure frame
- H1 = Overall height
- H2 = Clearance of enclosure frame
- T1 = Overall depth
- T2 = Clearance of enclosure frame
- T3 = Roof attachment spacing
- T4 = Distance between frame and 482.6 mm (19") swing frame
- T5 = Overall depth with handle
- T6 = Length of brush strips

Model No. DK	U	Width dimensions mm			Height dimensions mm		Depth dimensions mm					
		B1	B2	B3	H1	H2	T1	T2	T3	T4	T5	T6
5507.170	42	806	735	712	1998.5	1912	824	712	735	145	865	650