


Network/server enclosures TS IT

with glazed door, IP55, empty enclosure, width 600/800 mm

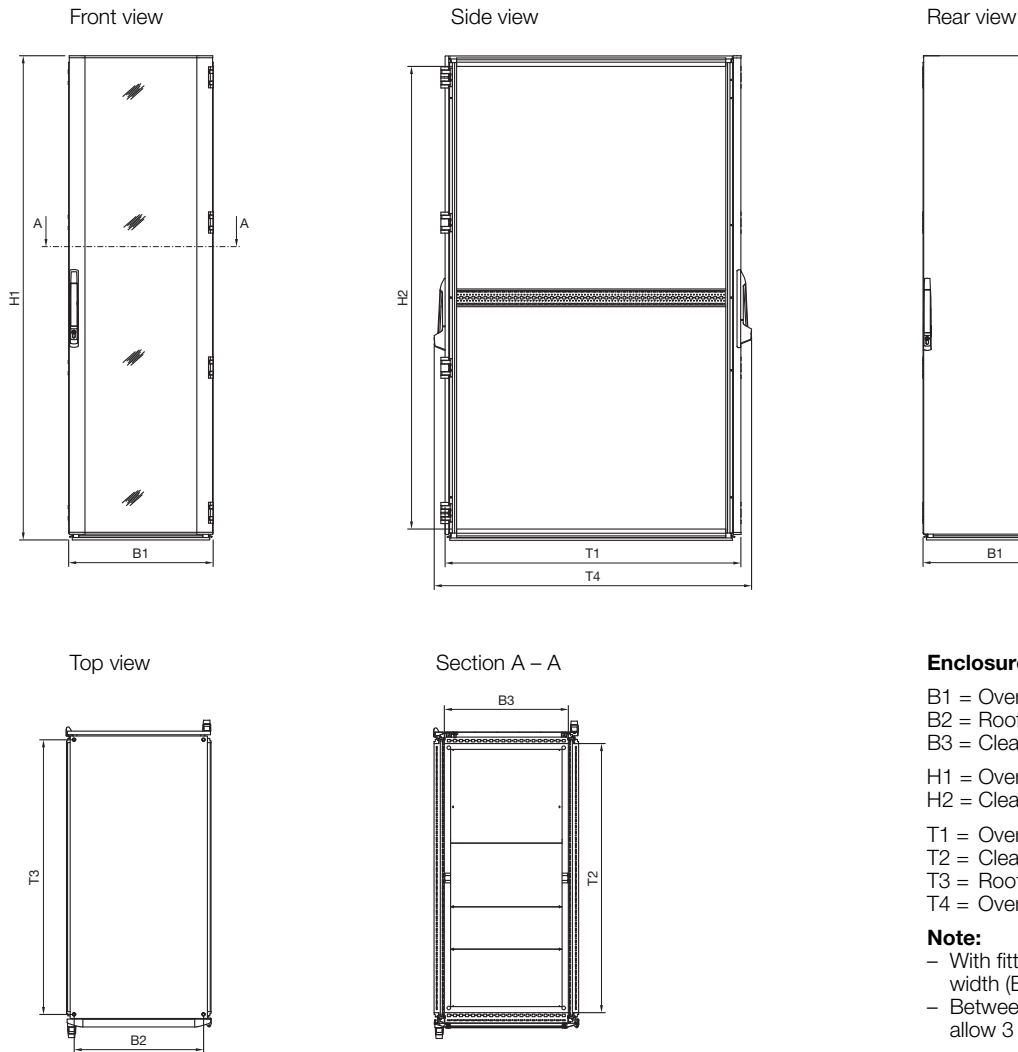

Enclosure

- B1 = Overall width
- B2 = Roof attachment spacing
- B3 = Clearance of enclosure frame
- H1 = Overall height
- H2 = Clearance of enclosure frame
- T1 = Overall depth
- T2 = Clearance of enclosure frame
- T3 = Roof attachment spacing
- T4 = Overall depth with handles

Note:

- With fitted side panels, the overall width (B1) is increased by 9 mm.
- Between bayed enclosures, allow 3 mm for the seal.

Model No. DK	U	Width dimensions mm			Height dimensions mm		Depth dimensions mm			
		B1	B2	B3	H1	H2	T1	T2	T3	T4
5503.790	24	797	735	712	1198.5	1112	824	712	735	911
5504.790	24	797	735	712	1198.5	1112	1024	912	935	1111
5505.790	38	797	735	712	1798.5	1712	824	712	735	911
5506.790	42	797	735	712	1998.5	1912	624	512	535	711
5507.790	42	797	735	712	1998.5	1912	824	712	735	911
5508.790	42	597	535	512	1998.5	1912	1024	912	935	1111
5509.790	42	797	735	712	1998.5	1912	1024	912	935	1111
5510.790	42	597	535	512	1998.5	1912	1224	1112	1135	1311
5511.790	42	797	735	712	1998.5	1912	1224	1112	1135	1311
5512.790	47	797	735	712	2198.5	2112	824	712	735	911
5513.790	47	597	535	512	2198.5	2112	1024	912	935	1111
5514.790	47	797	735	712	2198.5	2112	1024	912	935	1111
5515.790	47	597	535	512	2198.5	2112	1224	1112	1135	1311
5516.790	47	797	735	712	2198.5	2112	1224	1112	1135	1311
5525.790	15	597	535	512	798.5	712	624	512	535	711
5526.790	24	597	535	512	1198.5	1112	624	512	535	711
5527.790	38	597	535	512	1798.5	1712	624	512	535	711
5528.790	38	597	535	512	1798.5	1712	824	712	735	911
5529.790	42	597	535	512	1998.5	1912	624	512	535	711
5530.790	42	597	535	512	1998.5	1912	824	712	735	911
5531.790	47	597	535	512	2198.5	2112	824	712	735	911