

Rittal – The System.

Faster – better – everywhere.

Wallmount Enclosures



Rittal Wallmounts.

A good thing just got better.

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES




The Rittal Wallmount Difference

You've known Rittal quality in Wallmount Enclosures for years. Now you can get the industry's highest-quality enclosures in over 100 standard sizes, available in both carbon and stainless steel. And, with our American manufacturing plant located in central Ohio, you won't have to wait for the perfect Rittal enclosure you need for your facility today.

Wallmount Enclosure Carbon Steel			
	Rittal (mounting panel included)	Hoffman Concept	SCE Enviroline
8017528	WM121206NC	CSD12126	SCE-12EL1206LP
8017529	WM161206NC	CSD16126	SCE-16EL1206LP
1034250	WM161208NC	CSD16128	SCE-16EL1208LP
8017530	WM161606NC	CSD16166	SCE-16EL1606LP
1244250	WM161608NC	CSD16168	SCE-16EL1608LP
8017531	WM162006NC	CSD16206	SCE-16EL2006LP
8017541	WM162008NC	CSD16208	SCE-16EL2008LP
8017532	WM201606NC	CSD20166	SCE-20EL1606LP
1045250	WM201608NC	CSD20168	SCE-20EL1608LP
8017533	WM202006NC	CSD20206	SCE-20EL2006LP
1050250	WM202008NC	CSD20208	SCE-20EL2008LP
8018963	WM202010NC	CSD202010	SCE-20EL2010LP
1350250	WM202012NC	CSD202012	SCE-20EL2012LP
8017544	WM202408NC	CSD20248	SCE-20EL2408LP
8017534	WM241606NC	CSD24166	SCE-24EL1606LP
8017545	WM241608NC	CSD24168	SCE-24EL1608LP
8017535	WM242006NC	CSD24206	SCE-24EL2006LP
8017546	WM242008NC	CSD24208	SCE-24EL2008LP
8017561	WM242010NC	CSD242010	SCE-24EL2010LP
8017574	WM242012NC	CSD242012	SCE-24EL2012LP
8017536	WM242406NC	CSD24246	SCE-24EL2406LP
1060250	WM242408NC	CSD24248	SCE-24EL2408LP
8017562	WM242410NC	CSD242410	SCE-24EL2410LP
8017575	WM242412NC	CSD242412	SCE-24EL2412LP
8017549	WM243008NC	CSD24308	SCE-24EL3008LP
8017551	WM302008NC	CSD30208	SCE-30EL2008LP
1076250	WM302408NC	CSD30248	SCE-30EL2408LP
8017563	WM302410NC	CSD302410	SCE-30EL2410LP
8017576	WM302412NC	CSD302412	SCE-30EL2412LP
8017598	WM302420NC	CSD302420	SCE-30EL2420LP
1077250	WM303008NC	CSD30308	SCE-30EL3008LP

Wallmount Enclosure Carbon Steel			
	Rittal (mounting panel included)	Hoffman Concept	SCE Enviroline
8018902	WM303010NC	CSD303010	SCE-30EL3010LP
1073250	WM303012NC	CSD303012	SCE-30EL3012LP
8017554	WM362408NC	CSD36248	SCE-36EL2408LP
8017566	WM362410NC	CSD362410	SCE-36EL2410LP
8017578	WM362412NC	CSD362412	SCE-36EL2412LP
8017555	WM363008NC	CSD36308	SCE-36EL3008LP
8017567	WM363010NC	CSD363010	SCE-36EL3010LP
8017579	WM363012NC	CSD363012	SCE-36EL3012LP
8017594	WM363016NC	CSD363016	SCE-36EL3016LP
8017557	WM363608NC	CSD36368	SCE-36EL3608LP
8017581	WM363612NC	CSD363612	SCE-36EL3612LP
8017558	WM423008NC	CSD42308	SCE-42EL3008LP
8017559	WM423608NC	CSD42368	SCE-42EL3608LP
8017569	WM423610NC	CSD423610	SCE-42EL3610LP
8017586	WM423612NC	CSD423612	SCE-42EL3612LP
8017560	WM483608NC	CSD48368	SCE-48EL3608LP
8017570	WM483610NC	CSD483610	SCE-48EL3610LP
8017588	WM483612NC	CSD483612	SCE-48EL3612LP
8017595	WM483616NC	CSD483616	SCE-48EL3616LP
8017599	WM483620NC	CSD483620	SCE-48EL3620LP
8017571	WM603610NC	CSD603610	SCE-60EL3610LP
8017591	WM603612NC	CSD603612	SCE-60EL3612LP
8017597	WM603616NC	CSD603616	SCE-60EL3616LP
8017550	WM244208NC	CTD24428	SCE-244208WFLP
8017564	WM304210NC	CTD304210	SCE-304210WFLP
8017565	WM304810NC	CTD304810	SCE-304810WFLP
8017582	WM364212NC	CTD364212	SCE-364212WFLP
8017583	WM364812NC	CTD364812	SCE-364812WFLP
8017584	WM366012NC	CTD366012	SCE-366012WFLP
8017587	WM426012NC	CTD426012	SCE-426012WFALP
8017590	WM484812NC	CTD484812	SCE-484812WFLP

Experience The Rittal Wallmount Difference

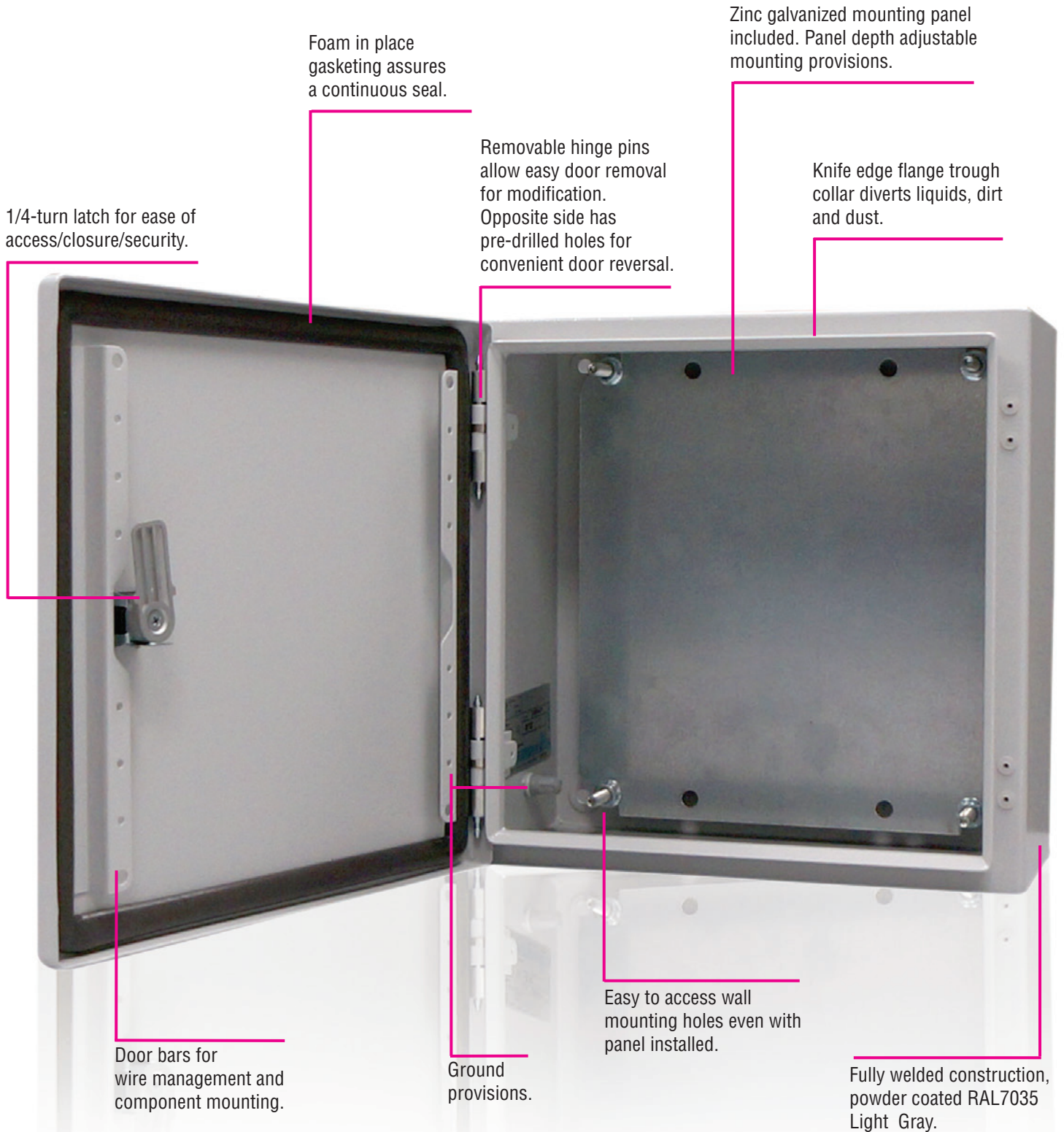

Wallmount Enclosure Stainless Steel

Rittal (mounting panel included)		Hoffman Concept or Continuous Hinge	SCE Enviroline
8017620	WM121206N4	CSD12126SS	SCE-12EL1206SSLP
8017614	WM161206N4	CSD16126SS	SCE-16EL1206SSLP
8017610	WM161606N4	CSD16166SS	SCE-16EL1606SSLP
8017613	WM201606N4	CSD20166SS	SCE-20EL1606SSLP
8017616	WM202006N4	CSD20206SS	SCE-20EL2006SSLP
8017608	WM161208N4	CSD16128SS	SCE-16EL1208SSLP
9851532	WM161608N4	CSD16168SS	SCE-16EL1608SSLP
8017605	WM201608N4	CSD20168SS	SCE-20EL1608SSLP
8018478	WM202008N4	CSD20208SS	SCE-20EL2008SSLP
8017621	WM241608N4	CSD24168SS	SCE-24EL1608SSLP
8017603	WM242008N4	CSD24208SS	SCE-24EL2008SSLP
9851500	WM242008N43PT	A24H2008SSLP3PT	-
8017600	WM242408N4	CSD24248SS	SCE-24EL2408SSLP
9851501	WM242408N43PT	A24H2408SSLP3PT	-
8017607	WM302408N4	CSD30248SS	SCE-30EL2408SSLP
9851504	WM302408N43PT	A30H2408SSLP3PT	-
8017611	WM303008N4	CSD30308SS	SCE-30EL3008SSLP
9851505	WM303008N43PT	A30H3008SSLP3PT	-
8017618	WM362408N4	CSD36248SS	SCE-36EL2408SSLP
9851507	WM362408N43PT	A36H2408SSLP3PT	-
8017615	WM363008N4	CSD36308SS	SCE-36EL3008SSLP
9851508	WM363008N43PT	A36H3008SSLP3PT	-
8017622	WM242010N4	CSD242010SS	SCE-24EL2010SSLP
9851502	WM242010N43PT	A24H2010SSLP3PT	SCE-24EL2010SSLPPL
8018493	WM302410N4	CSD302410SS	SCE-30EL2410SSLP
9851529	WM302410N43PT	NA	-
8018903	WM303010N4	CSD303010SS	SCE-30EL3010SSLP
8017619	WM363010N4	CSD363010SS	SCE-36EL3010SSLP
9851509	WM363010N43PT	A36H3010SSLP3PT	-
8018514	WM483610N4	A48H3610SSLP3PT	-
8018474	WM242412N4	CSD242412SS	SCE-24EL2412SSLP
9851503	WM242412N43PT	A24H2412SSLP3PT	-
8017612	WM302412N4	CSD302412SS	SCE-30EL2412SSLP
9851506	WM302412N43PT	A30H2412SSLP3PT	SCE-30EL2412SSLPPL
8017606	WM363012N4	CSD363012SS	SCE-36EL3012SSLP
9851510	WM363012N43PT	A36H3012SSLP3PT	SCE-36EL3012SSLPPL
8017602	WM363612N4	A36H3612SSLP	SCE-36EL3612SSLP
9851511	WM363612N43PT	A36H3612SSLP3PT	-
8017617	WM423612N4	A42H3612SSLP3PT	SCE-42EL3612SSLPPL
8017601	WM483612N4	A48H3612SSLP3PT	SCE-48EL3612SSLPPL
8017604	WM603612N4	A60H3612SSLP3PT	SCE-60EL3612SSLPPL
8018500	WM363016N4	A36H3016SSLP	SCE-36EL3016SSLP
9851527	WM363016N43PT	-	-
8018515	WM483616N4	A48H3616SSLP3PT	SCE-48EL3616SSLP
8018521	WM603616N4	A60H3616SSLP3PT	SCE-60EL3616SSLP

Wallmount Enclosure Stainless Steel

Rittal (mounting panel included)		Hoffman Concept or Continuous Hinge	SCE Enviroline
8018525	WM121206N6	CSD12126SS6	SCE-12EL1206SS6LP
8017636	WM161206N6	CSD16126SS6	SCE-16EL1206SS6LP
8017638	WM161606N6	CSD16166SS6	SCE-16EL1606SS6LP
8017639	WM201606N6	CSD20166SS6	SCE-20EL1606SS6LP
8018529	WM202006N6	CSD20206SS6	SCE-20EL2006SS6LP
8017644	WM161208N6	CSD16128SS6	SCE-16EL1208SS6LP
9851531	WM161608N6	CSD16168SS6	SCE-16EL1608SS6LP
8017628	WM201608N6	CSD20168SS6	SCE-20EL1608SS6LP
8017624	WM202008N6	CSD20208SS6	SCE-20EL2008SS6LP
8018532	WM241608N6	CSD24168SS6	SCE-24EL1608SS6LP
8017632	WM242008N6	CSD24208SS6	SCE-24EL2008SS6LP
9851512	WM242008N63PT	A24H2008SS6LP3PT	-
8017623	WM242408N6	CSD24248SS6	SCE-24EL2408SS6LP
9851513	WM242408N63PT	A24H2408SS6LP3PT	-
8017625	WM302408N6	CSD30248SS6	SCE-30EL2408SS6LP
9851516	WM302408N63PT	A30H2408SS6LP3PT	-
8018546	WM303008N6	CSD30308SS6	SCE-30EL3008SS6LP
9851517	WM303008N63PT	A30H3008SS6LP3PT	-
8017643	WM362408N6	CSD36248SS6	SCE-36EL2408SS6LP
9851519	WM362408N63PT	A36H2408SS6LP3PT	-
8017642	WM363008N6	CSD36308SS6	SCE-36EL3008SS6LP
9851520	WM363008N63PT	A36H3008SS6LP3PT	-
8018534	WM242010N6	CSD242010SS6	SCE-24EL2010SS6LP
9851514	WM242010N63PT	A24H2010SS6LP3PT	SCE-24EL2010SS6LPPL
8017634	WM302410N6	CSD302410SS6	SCE-30EL2410SS6LP
9851530	WM302410N63PT	-	-
8018904	WM303010N6	CSD303010SS6	SCE-30EL3010SS6LP
8018552	WM363010N6	CSD363010SS6	SCE-36EL3010SS6LP
9851521	WM363010N63PT	A36H3010SS6LP3PT	-
8017641	WM483610N6	A48H3610SS6LP3PT	-
8017627	WM242412N6	CSD242412SS6	SCE-24EL2412SS6LP
9851515	WM242412N63PT	A24H2412SS6LP3PT	-
8017637	WM302412N6	CSD302412SS6	SCE-30EL2412SS6LP
9851518	WM302412N63PT	A30H2412SS6LP3PT	SCE-30EL2412SS6LPPL
8017630	WM363012N6	CSD363012SS6	SCE-36EL3012SS6LP
9851522	WM363012N63PT	A36H3012SS6LP3PT	SCE-36EL3012SS6LPPL
8017629	WM363612N6	A36H3612SS6LP	SCE-36EL3612SS6LP
9851523	WM363612N63PT	A36H3612SS6LP3PT	-
8018564	WM423612N6	CSD423612SS6R	SCE-42EL3612SS6LPPL
8017626	WM483612N6	A48H3612SS6LP3PT	SCE-48EL3612SS6LPPL
8017631	WM603612N6	A60H3612SS6LP3PT	SCE-60EL3612SS6LPPL
8017635	WM363016N6	A36H3016SS6LP	-
9851528	WM363016N63PT	-	-
8017640	WM483616N6	A48H3616SS6LP3PT	SCE-48EL3616SS6LP
8017633	WM603616N6	A60H3616SS6LP3PT	SCE-60EL3616SS6LP

Stainless Steel Wallmount Enclosures


Removable stainless steel hinge pins allow easy door removal for modification.

Zinc galvanized mounting panel included. Panel depth adjustable mounting provisions.



Rear, blind nut design enables enclosure to be mounted to the wall and maintain the integrity of the Nema 4X rating.

Stainless steel screw driver insert and 1/4-turn latch for ease of access/closure/security.

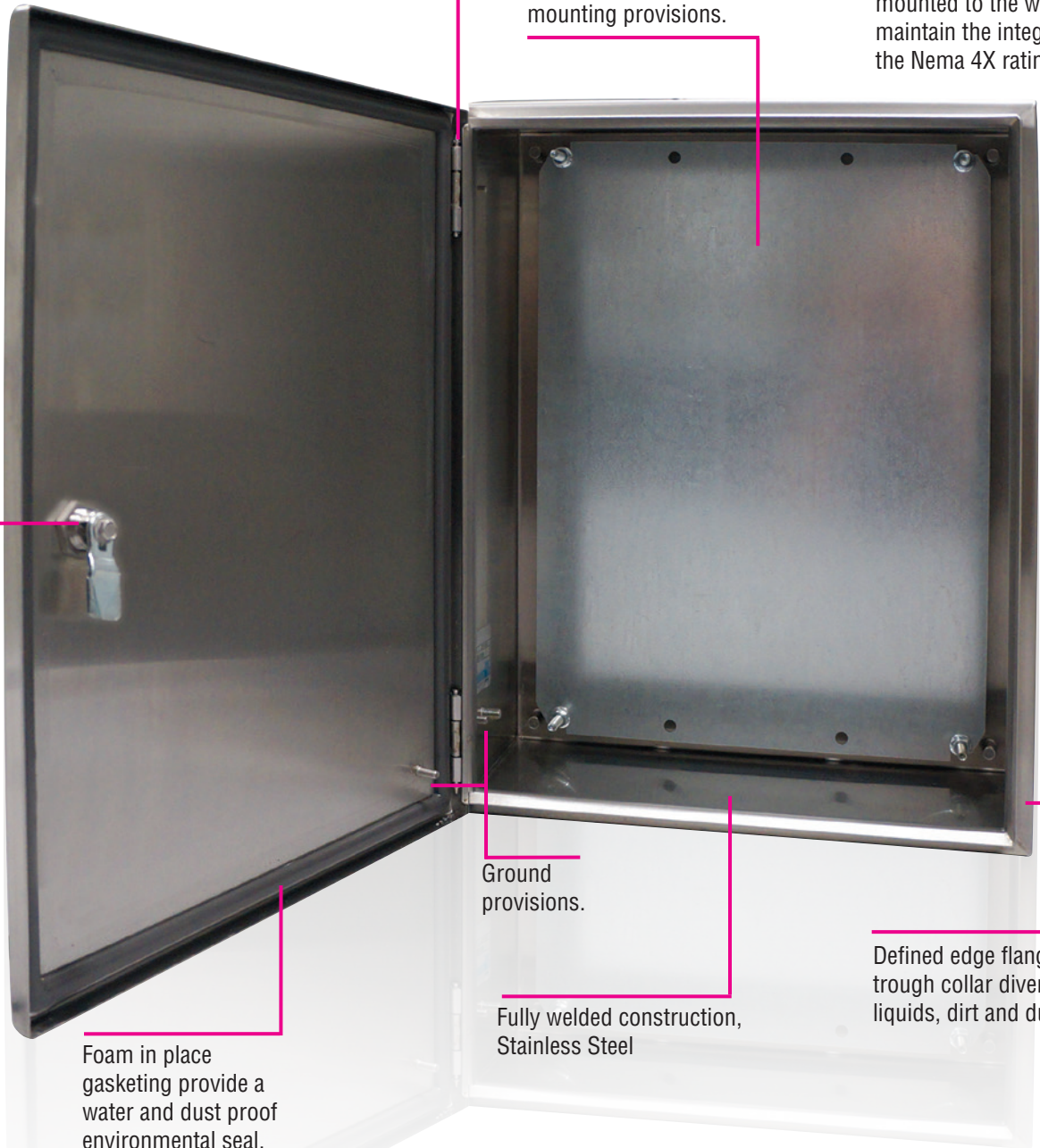

Ground provisions.

Fully welded construction, Stainless Steel

Defined edge flange trough collar diverts liquids, dirt and dust.

Foam in place gasketing provide a water and dust proof environmental seal.

Rittal – The System.

Faster – better – everywhere.

- Enclosures
- Power Distribution
- Climate Control
- IT Infrastructure
- Software & Services



Get the **FREE Wallmount App** for iOS and Android

RITTAL SHIPS QUICK!
Made in the USA

www.RittalEnclosures.com

Rittal North America LLC

Woodfield Corporate Center
425 North Martingale Road, Suite 400 • Schaumburg, Illinois 60173 • USA
Phone: 937-399-0500 • Toll-free: 800-477-4000
Email: rittal@rittal.us • Online: www.rittal.us

Rittal Systems Ltd.

6485 Ordan Drive • Mississauga, Ontario L5T 1X2 • Canada
Phone: 905-795-0777 • Toll-free: 800-399-0748
E-Mail: marketing@rittal.ca • Online: www.rittal.ca

Rittal Mexico

Dr. Roberto Gayol 1219-1B • Col. Del Valle Sur, 03100 • Mexico, D.F.
Phone: (+52) (55) 5559-5369 • Toll-free: 01 800 8 Rittal (748.825)
E-Mail: info@rittal.com.mx • Website: www.rittal.com.mx

6/18 ■ US326

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

