

Rittal – The System.

Faster – better – everywhere.

► The base/plinth system VX. The best of everything.

The base/plinth system VX suits almost any enclosure application. By combining the best of all existing Rittal base/plinth functions into one variable modular system we can offer you extra space, easier assembly, time savings and additional flexibility with less parts.

The VX system with its largely tool-free mounting simplifies assembly, configuration and buying, while saving time, parts and warehousing costs.

- Matches the new large enclosure system to perfection
- Fully compatible with enclosure systems TS 8, TS IT, SE 8, PC, IW, CM, TP

- Replaces the Flex-Block base/plinth system and the TS base/plinth
- Just two Model Numbers for one base/plinth size
- Buying trim panel included with the supply
- Robust sheet steel corner piece
- Pre-fitted captive nuts for fast, simple assembly
- Trim panels simply clip in, with optional screw-fastening

For more information on the New Base/Plinth System VX visit www.rittal.com or call toll-free 800-477-4000.



ENCLOSURES

POWER DISTRIBUTION


CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP




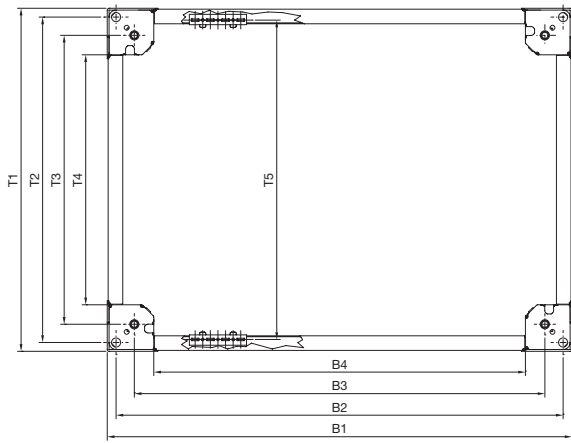

Base/plinth, 100 mm (4 in.) high




Base/plinth, trim panels, solid, 100 mm (4 in.) high, front view

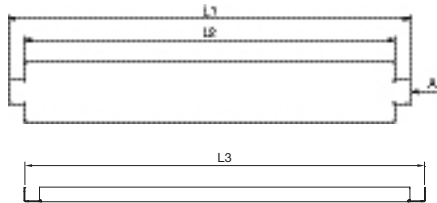


Rear view



 
Base/plinth trim panels with brush strip, 100 mm (4 in.) high, front view



 
Base/plinth trim panels, vented, 100 mm (4 in.) high, front view




View A

 


View B

 

Base/plinth, 200 mm (3 in.) high

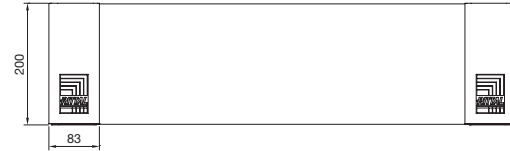

Base/plinth, trim panels, solid, 200 mm (8 in.) high, front view

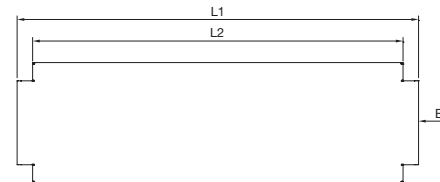

Rear view



For enclosure width or depth mm	Width dimensions mm				Length dimensions mm				Depth dimensions mm				
	B1	B2	B3	B4	L1	L2	L3	L4	T1	T2	T3	T4	T5 ¹⁾
300	264	235	175	111	160	109	157	–	264	235	175	111	225
400	364	335	275	211	260	209	257	–	364	335	275	211	325
500	464	435	375	311	360	309	357	–	464	435	375	311	425
600	564	535	475	411	460	409	457	349	564	535	475	411	525
800	764	735	675	611	660	609	657	549	764	735	675	611	725
850	814	785	725	661	710	659	707	–	–	–	–	–	775
1000	964	935	875	811	860	809	857	–	964	935	875	811	925
1100	1064	1035	975	911	960	909	957	–	–	–	–	–	1025
1200	1164	1135	1075	1011	1060	1009	1057	–	1164	1135	1075	1011	1125
1600	1564	1535	1475	1411	1460	1409	1457	–	–	–	–	–	1525
1800	1764	1735	1675	1611	1660	1609	1657	–	–	–	–	–	1725

¹⁾T5 = Distance between system punchings including base/plinth installation bracket

Rittal North America LLC

Woodfield Corporate Center • 425 North Martingale Road, Suite 400 • Schaumburg, Illinois 60173 • USA
Phone: 937-399-0500 • Toll-free: 800-477-4000 • Email: rittal@rittal.us • Website: www.rittal.us

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES



FRIEDHELM LOH GROUP