

Rittal – The System.

Faster – better – everywhere.

▶ TS punched section with mounting flange, 23 x 73 mm – TS 8612.550

Date : Nov 30, 2019

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



TS punched section with mounting flange, 23 x 73 mm – TS 8612.550

created: 30.11.2019 on www.rittal.com/com-en

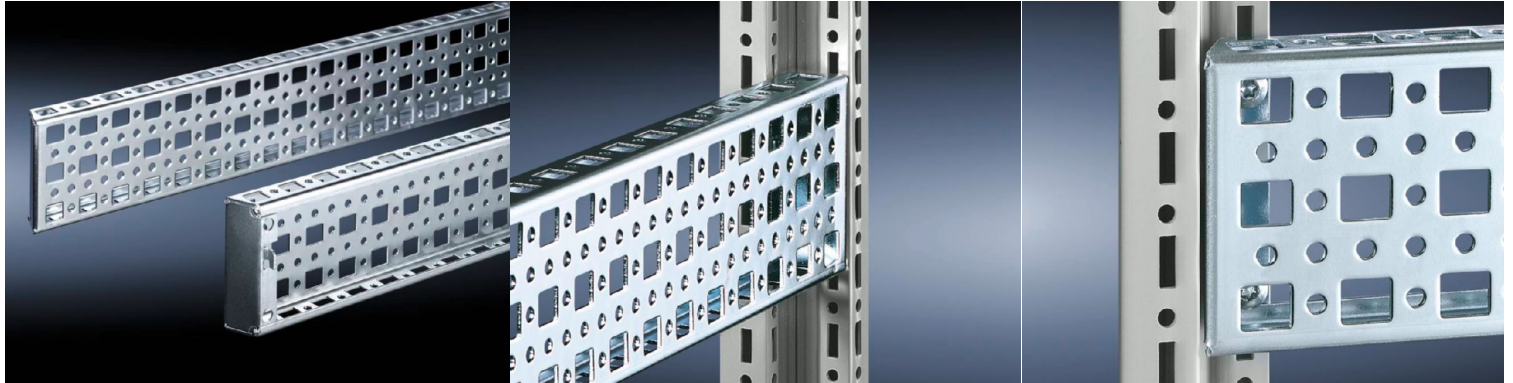

Product description

| | |
|-------------------------|---|
| Description: | The alternative to the TS punched section with mounting flange 17 x 73 mm, with punchings for captive nuts/threaded blocks instead of the slotted holes top and bottom. Simply locate and secure. |
| Material: | Sheet steel |
| Surface finish: | Zinc-plated |
| Supply includes: | Assembly screws |

Product features

| | |
|--------------------------------------|---|
| To fit: | Enclosure type: the inner mounting level Width/depth: 500 mm |
| Installation options: | On the vertical TS, SE enclosure section |
| Packs of: | 4 pc(s). |
| Weight/pack: | 2.28 kg |
| Copper weight (kg per piece): | 0 |
| EAN: | 4028177236264 |
| Customs tariff number: | 73269098 |

| | |
|-----------------------------|--|
| ETIM 7.0: | EC002625 |
| ETIM 6.0: | EC002625 |
| eCl@ss 8.0/8.1: | 27189234 |
| eCl@ss 6.0/6.1: | 23159101 |
| Product description: | TS TS punched section with mounting flange, 23 x 73 mm, for inner mounting level: W/D: 500 mm |
| Approvals | |
| Certificates: | EAC |