

# Rittal – The System.

Faster – better – everywhere.

## ► Prirubne ploče kabela od umjetnog materijala s PG utisnućem – KL 1581.000

Date : 2021.04.15

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# Prirubne ploče kabela od umjetnog materijala s PG utisnućem – KL 1581.000

created: 15.04.2021 build on [www.rittal.com/hr-hr](http://www.rittal.com/hr-hr)

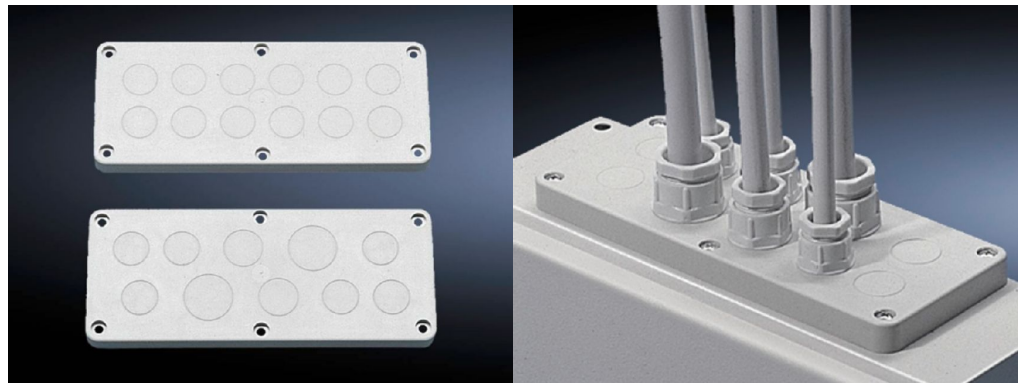

Discontinued article.

## Product description

**Description:** With pre-punched PG holes for cable glands. Use seal for standard gland plates.

**Material:** ABS

**Colour:** RAL 7035

**Protection category  
IP to IEC 60 529:** IP 55 if installed correctly

**Note:** The allocation of gland plate sizes is indicated on the relevant enclosures

## Product description

**To fit:** Enclosure type: KL

**Dimensions:** Width: 220 mm  
Depth: 90 mm

**Operating  
temperature:** Operation (environment): -40 °C...+70 °C

**Gland plate, size:** 2

**Cable entry:** Number x PG diameter: 12 x 13.5

**Packs of:** 5 pc(s).

<b>Weight/pack:</b>	0,6 kg
<b>Copper weight (kg per piece):</b>	0
<b>EAN:</b>	4028177010888
<b>Customs tariff number:</b>	73269098
<b>ETIM 7.0:</b>	EC000211
<b>ETIM 6.0:</b>	EC000211
<b>eCl@ss 8.0/8.1:</b>	27142421
<b>eCl@ss 6.0/6.1:</b>	27189190
<b>Product description:</b>	KL Plastic cable gland plate, with PG knock-outs, WD: 220x90 mm, size: 2, PG knockouts: 13.5
<b>Approvals</b>	
<b>Certificates:</b>	NA