

Rittal – The System.

Faster – better – everywhere.

Wire end ferrules on a reel – AS 4051.536

Date : May 12, 2021

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



Wire end ferrules on a reel – AS 4051.536

created: 12.05.2021 build on www.rittal.com/il-en

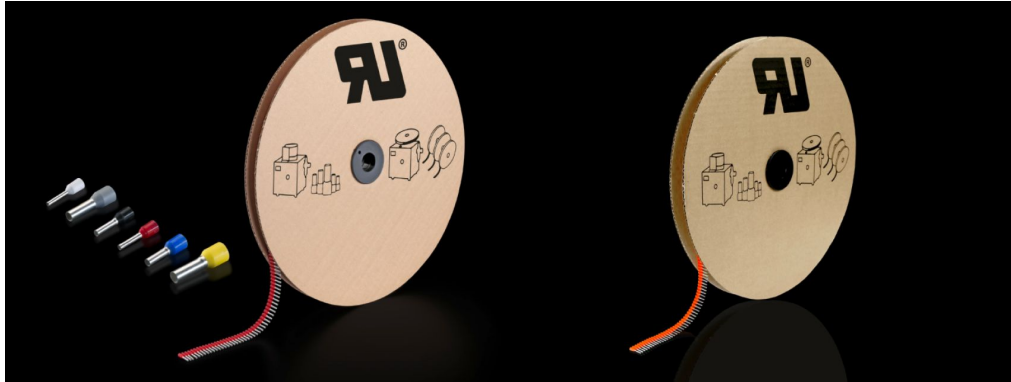

Product description

Description: With plastic collar.

Technical specifications: Heat-resistant to 105 °C

Material: E-Cu, galvanic tin-plated
Plastic collar: Polypropylene

Note: UL-certified in conjunction with the relevant tools, such as crimping machines.

Product description

For cross-section: 0.5 mm²

AWG: 20

Length: 10 mm

Internal diameter: 2.9 mm

Design: for crimping machines, multiple colour codes supported

Colour: Orange

Colour code: Rittal colour code: yes
Multiple colour codes supported: yes

For: Crimping machine RC

Delivery form:	Taped
Packs of:	4000 pc(s).
Weight/pack:	4 kg
Copper weight (kg per piece):	0
EAN:	4028177937840
Customs tariff number:	85369010
ETIM 7.0:	EC000005
ETIM 6.0:	EC000005
eCl@ss 8.0/8.1:	36659290
eCl@ss 6.0/6.1:	36659290
Product description:	Wire end ferrules 0.5 mm ² x 10 mm AWG 20 multinorm, packs of 4,000 pc(s)., colour: orange, delivery form: on belt (in accordance with the Rittal colour code), 0.5 mm ²

Approvals

Approvals:	UL + C-UL
-------------------	-----------