


Rittal – The System.

Faster – better – worldwide.

► TS IT Network/Server Enclosures

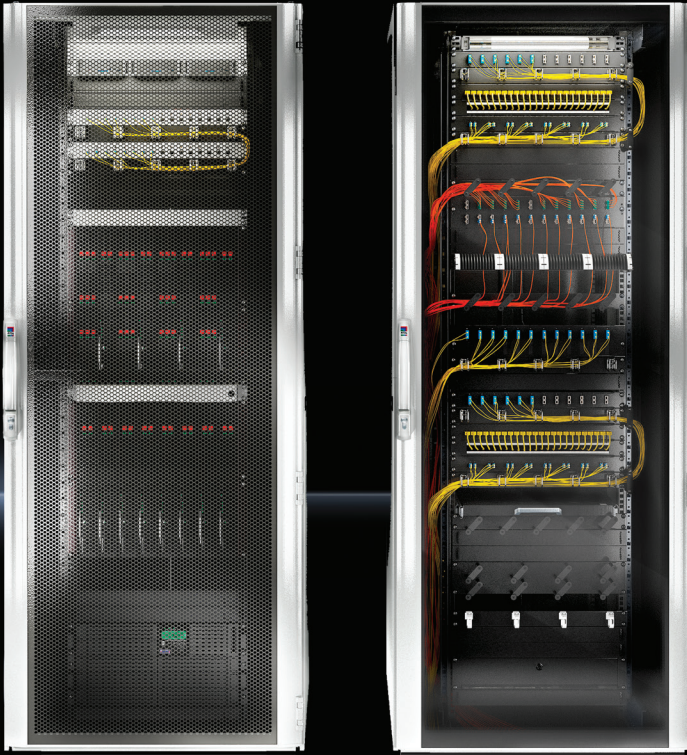

Rittal has redefined the standard in network and server enclosures with its TS IT modular system, featuring tool-less, snap-in assembly technology to boost operating efficiency while lowering costs. It's easy to deploy, provides a safe environment for servers and other components, can be easily reconfigured and offers an optimum price/performance ratio. The TS IT System has established a new standard in functionality and efficiency, encompassing virtually all the requirements placed on network and server enclosures through its simple, tool-less design. For complete details on the entire line, go to www.rittal.us/makeItEasy.

- Tool-free assembly for racks and accessories makes the most of snap-in technology
- Integrated locks, latches and quick-fasteners help to make completion a one-person task
- Offset positioning for mounting widths of 19", 21", 23" and 24"
- Glazed or vented door options
- Unique 180-degree hinges on both front and back doors
- Divided rear doors as tall as 71 inches
- Multifunctional roof design
- High load capacity of more than 3,000 pounds
- Can be used with optional Flex Block Base
- Intelligent, integrated cable management
- High energy efficiency
- Engineered solutions to cable routing and management
- Seamlessly accommodates all LCP cooling options
- Expansive range of accessories
- Comprehensive lineup of standard features
- A lengthy list of value-adding extras

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP

www.rittal.us



TS IT Enclosure with Perforated Front/Rear Doors

Part No. RAL 9005	Part No. RAL 7035	U	Height inches (mm)	Width inches (mm)	Depth inches (mm)
5504.210	5504.110	24	48 (1200)	32 (800)	40 (1000)
5508.210	5508.110	42	79 (2000)	24 (600)	40 (1000)
5509.210	5509.110	42	79 (2000)	32 (800)	40 (1000)
5521.210	—	42	79 (2000)	24 (600)	41 (1050)
9972.000	9972.001	42	79 (2000)	28 (700)	41 (1050)
5522.210	—	42	79 (2000)	32 (800)	41 (1050)
5510.210	5510.110	42	79 (2000)	24 (600)	48 (1200)
9972.002	9972.003	42	79 (2000)	28 (700)	48 (1200)
5511.210	5511.110	42	79 (2000)	32 (800)	48 (1200)
5513.210	5513.110	47	87 (2200)	24 (600)	40 (1000)
5514.210	5514.110	47	87 (2200)	32 (800)	40 (1000)
5524.210	5523.210	47	87 (2200)	24 (600)	41 (1050)
9972.004	9972.005	47	87 (2200)	28 (700)	41 (1050)
5515.210	5515.110	47	87 (2200)	24 (600)	48 (1200)
9972.006	9972.007	47	87 (2200)	28 (700)	48 (1200)
5516.210	5516.110	47	87 (2200)	32 (800)	48 (1200)

TS IT Enclosure with Viewing Front Door – Solid Rear Door

Part No. RAL 9005	Part No. RAL 70 35	U	Height inches (mm)	Width inches (mm)	Depth inches (mm)
5503.220	5503.120	24	48 (1200)	32 (800)	32 (800)
5504.220	5504.120	24	48 (1200)	32 (800)	40 (1000)
5505.220	5505.120	38	71 (1800)	32 (800)	32 (800)
5506.220	5506.120	42	79 (2000)	32 (800)	24 (600)
5507.220	5507.120	42	79 (2000)	32 (800)	32 (800)
5508.220	5508.120	42	79 (2000)	24 (600)	40 (1000)
5509.220	5509.120	42	79 (2000)	32 (800)	40 (1000)
5510.220	5510.120	42	79 (2000)	24 (600)	48 (1200)
5511.220	5511.120	42	79 (2000)	32 (800)	48 (1200)
5512.220	5512.120	47	87 (2200)	32 (800)	32 (800)

Cable Management

Part No.	Description	Packs of
5502.105	Cable duct for enclosure height 79" (2000 mm)	1
5502.145	Cable duct for enclosure height 87" (2200 mm)	1
5502.115	Cable finger 6 U	14
5502.205	Cable management panel	1
7257.105	Cable management panel	1
5502.225	Cable management panel with cable routing bars	1
5502.235	Cable management panel, 2 U	1
5502.245	Cable routing channel	1
5502.255	Cable entry panel	1
5502.265	Cable entry panel	1
5502.120	Cable route, height 79 - 87" (2000 - 2200 mm)	1
5502.155	Nylon tape supports	10
9969.599	Quarter-turn velcro cable fastener 17" (420 mm)	10
9969.600	Quarter-turn cable collection	10
9961.780	Quarter-turn D-ring, 5 x 3.5" (127 x 88.9 mm)	10
9961.779	Quarter-turn D-ring, 3.5 x 1.75" (88.9 x 44.5 mm)	10

Airflow Management

Part No.	Description	Packs of
5501.805	Air baffle plate 24 x 79" (600 x 2000 mm)	1 set
5501.815	Air baffle plate 32 x 79" (800 x 2000 mm)	1 set
5501.825	Air baffle plate 24 x 87" (600 x 2200 mm)	1 set
5501.835	Air baffle plate 32 x 87" (800 x 2200 mm)	1 set
9960.676	Blanking panel (sand texture black)	12

Shelves

Part No.	Description	Packs of
5501.615	Component shelf, 2 U, static installation (250 mm)	1 set
5501.625	Component shelf, 2 U, static installation (400 mm)	1 set
5501.665	Component shelf, static installation	1 set
5501.695	Component shelf, static installation	1 set
5501.705	Component shelf, static installation	1 set
5501.675	Component shelf, pull-out	1 set
5501.685	Component shelf, pull-out	1 set
5501.715	Component shelf, pull-out	1 set
5501.725	Component shelf, pull-out	1 set

Sidewalls

Part No.	Color	Description	Packs of
5501.000	RAL 7035	Side panel divided 71 x 32" (1800 x 800 mm)	1
5501.010	RAL 7035	Side panel divided 79 x 24" (2000 x 600 mm)	1
5501.020	RAL 7035	Side panel divided 79 x 32" (2000 x 800 mm)	1
5501.030	RAL 7035	Side panel divided 79 x 40" (2000 x 1000 mm)	1
5501.040	RAL 7035	Side panel divided 79 x 48" (2000 x 1200 mm)	1
5501.050	RAL 7035	Side panel divided 87 x 32" (2200 x 800 mm)	1
5501.060	RAL 7035	Side panel divided 87 x 40" (2200 x 1000 mm)	1
5501.070	RAL 7035	Side panel divided 87 x 48" (2200 x 1200 mm)	1
5501.005	RAL 9005	Side panel divided 71 x 32" (1800 x 800 mm)	1
5501.015	RAL 9005	Side panel divided 79 x 24" (2000 x 600 mm)	1
5501.025	RAL 9005	Side panel divided 79 x 32" (2000 x 800 mm)	1
5501.035	RAL 9005	Side panel divided 79 x 40" (2000 x 1000 mm)	1
5501.045	RAL 9005	Side panel divided 79 x 48" (2000 x 1200 mm)	1
5501.055	RAL 9005	Side panel divided 87 x 32" (2200 x 800 mm)	1
5501.065	RAL 9005	Side panel divided 87 x 40" (2200 x 1000 mm)	1
5501.075	RAL 9005	Side panel divided 87 x 48" (2200 x 1200 mm)	1
5501.095	RAL 9005	Side panel divided 79 x 41" (2000 x 1050 mm)	1
5501.105	RAL 9005	Side panel divided 87 x 41" (2200 x 1050 mm)	1

Other Accessories

Part No.	Description	Packs of
9968.751	Caster kit	4 casters
8800.490	Baying connectors, external	6

Rittal Corporation

Urbana, Ohio • Schaumburg, Illinois • Houston, Texas • Sparks, Nevada • USA
Toll-free: 800-477-4000 • Fax: 800-477-4003 • Email: rittal@rittal.us • Online: www.rittal.us