


Rittal – The System.

Faster – better – everywhere.

Rittal Hose-Proof Fan Shroud

Rittal offers water-resistant fan shrouds to fit many indoor and outdoor applications. Made in carbon and stainless steel for Type 3R/4 and Type 4X protection from large debris, wind-driven rain and hose-directed water and corrosion.

Our Hi-Visibility blue silicone gasket quickly identifies the seal meets FDA Guideline 21 CFR 177.2600. Additionally, the material allows easy cleaning in food and beverage environments.

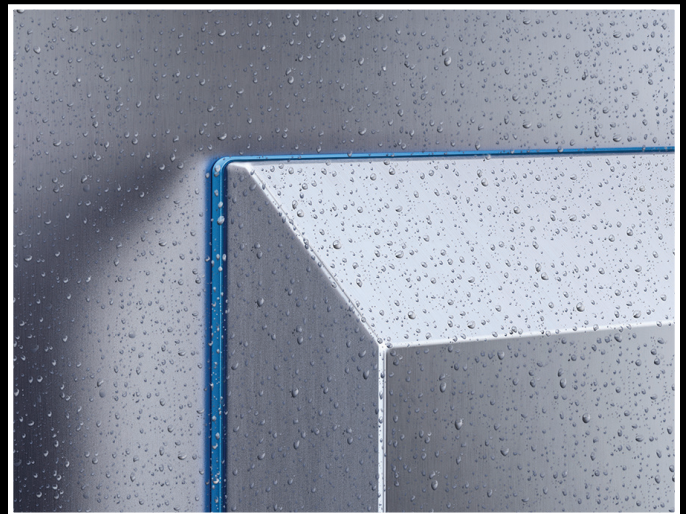

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



Stainless Steel, AISI 304

For filter fan/ outlet filter	Dimensions H x W x D inches (mm)	Part No.
3237. . . .	9.1 x 5.9 x 1.6 (230 x 150 x 40)	3237.080
3238. . . .	9.6 x 6.9 x 2.2 (245 x 176 x 55)	3238.080
3239. . . .	13 x 9.2 x 2.2 (330 x 233 x 55)	3239.080
3240. . . ./3241. . . .	15.3 x 11.1 x 3.3 (390 x 282 x 85)	3240.080
3243. . . ./3244. . . .	18.9 x 13.4 x 4.3 (480 x 350 x 110)	3243.080

UL Protection Category:


- 3237: Type 12, 3R
- 3238, 3239, 3240, 3241, 3243, and 3244: Type 12, 3, 3R, and 4X

Carbon Steel, RAL 7035

For filter fan/ outlet filter	Dimensions H x W x D inches (mm)	Part No.
3237. . . .	9.1 x 5.9 x 1.6 (230 x 150 x 40)	3237.085
3238. . . .	9.6 x 6.9 x 2.2 (245 x 176 x 55)	3238.085
3239. . . .	13 x 9.2 x 2.2 (330 x 233 x 55)	3239.085
3240. . . ./3241. . . .	15.3 x 11.1 x 3.3 (390 x 282 x 85)	3240.085
3243. . . ./3244. . . .	18.9 x 13.4 x 4.3 (480 x 350 x 110)	3243.085

UL Protection Category:

- 3237: Type 12, 3R
- 3238, 3239, 3240, 3241, 3243, and 3244: Type 12, 3, 3R, and 4

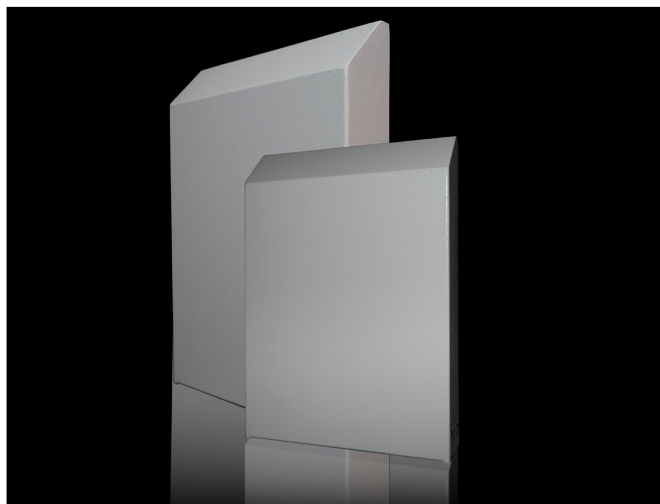

You can find the contact details of all
Rittal companies throughout the world here.



www.rittal.com/contact