



QR-Code
gemäß
RIINT-00009

SV

9677.865

9677.866

9677.875

9677.876

9677.885

9677.886


9677.958

9677.960



www.rittal.com

1x

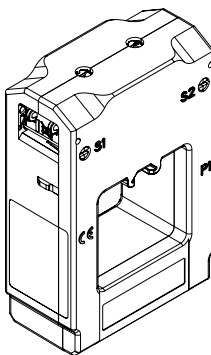

Dok.-Nr. / No of doc.: D-0000-00003253-01
Versandbeutel-Nr. / No. of accessory bag:


Lieferanten-Nr. / No. of supplier:

RITTAL GmbH & Co. KG, Auf dem Stuetzelberg, 35745 Herborn
RITTAL Limited, Braithwell Way, Hellaby, Rotherham, S66 8QY, UK


DIN A6, doppelseitig
DIN A6, double sheet

1

Typ Type	Best.-Nr. Model No.	
	5 A	333 mV
250 A	9677.865	9677.866
400 A	9677.875	9677.876
600 A	9677.885	9677.886
800 A	9677.958	9677.960

 

2 x
2,5 - 4 mm²
AWG13 - AWG11

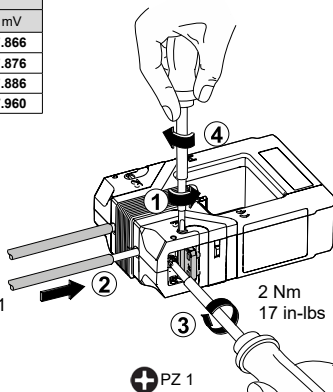
Hinweis!

Hochtemperaturfeste Leitungen > 130 °C verwenden

Note!

Use high temperature resistant cables > 130 °C

Remarque :

Utiliser des câbles résistants aux hautes températures > 130 °C

2