


 
 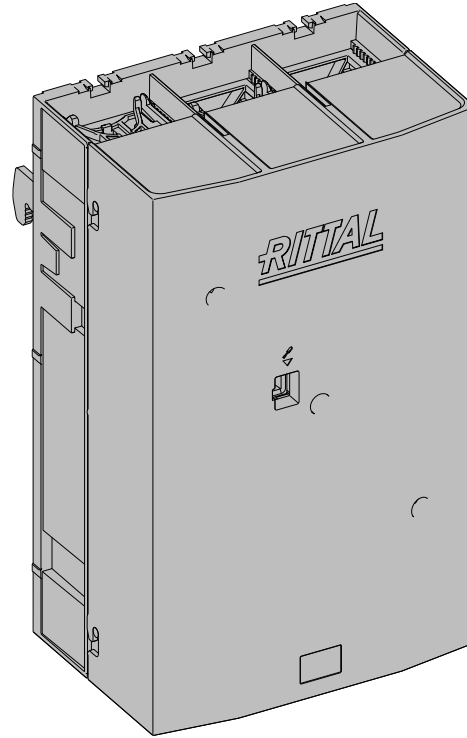




 



www.rittal.com

1 x



	Rundleiter mehrdrähtig Round conductor multi-wire Conducteur rond multifilaire	Feindrähtig mit isolierter Aderendhülse Fine wires with insulated ferrule Fils fins avec embout isolé	Feindrähtig mit unisolierter Aderendhülse Fine wires with uninsulated ferrule Fils fins avec embouts non-isolés	Lamellierte Kupferschiene Laminated copper bar Barre de cuivre lamellée
	Class B/C			
				
IEC	95 – 300 mm ²	95 – 300 mm ²	95 – 300 mm ²	15,5x4,8 mm 32x20 mm
UL	AWG 3/0 – kcmil 600	-	-	2 x 10x32x1 mm

	Sektorleiter eindrätig Sector conductor single-wire Conducteur sectoriel unifilaire	Sektorleiter mehrdrätig Sector conductor multi-wire Conducteur sectoriel multifilaire	Flachkupferschiene Flat copper busbar Barre de cuivre plate	Feindrähtig Fine wires Fils fins
				Class I
				
IEC	120 – 240 mm ²	95 – 300 mm ²	20x5 mm 30x10 mm	95 – 300 mm ²
UL	-	-	-	AWG 3/0 – kcmil 600

TX30

0.6x4

