
 








 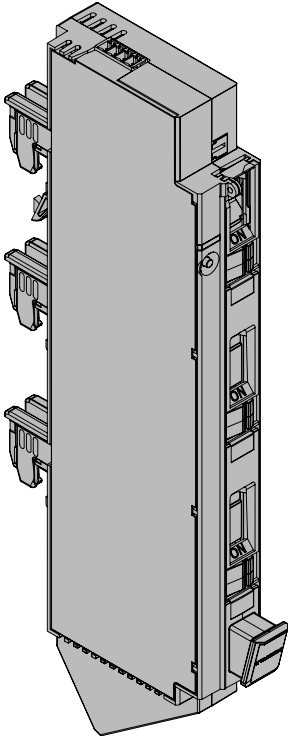


www.rittal.com

1 x



	Rundleiter eindräftig Round conductor sing- le-wire Conducteur rond, unifilaire	Rundleiter mehrdräftig Round conductor multi-wire Conducteur rond, multifilaire	Feindräftig Fine wires Fils fins	Feindräftig mit isolierter Aderendhülse Fine wires with insulated ferrule Fils fins, avec embout isolé	Feindräftig mit unisolierter Aderendhülse Fine wires with uninsulated ferrule Fils fins, avec embouts non-isolés
					
IEC	1,5 ... 6 mm ² (Cu)	1,5 ... 6 mm ² (Cu)	1,5 ... 6 mm ² (Cu) (feindräftig + Aderendhülse eventuell nicht mit maximalem Querschnitt möglich) (fine-wire + wire end ferrule may be not possible with the maximum cross-section) (fils de faible diamètre + embout éventuellement impossible avec section maximale)		

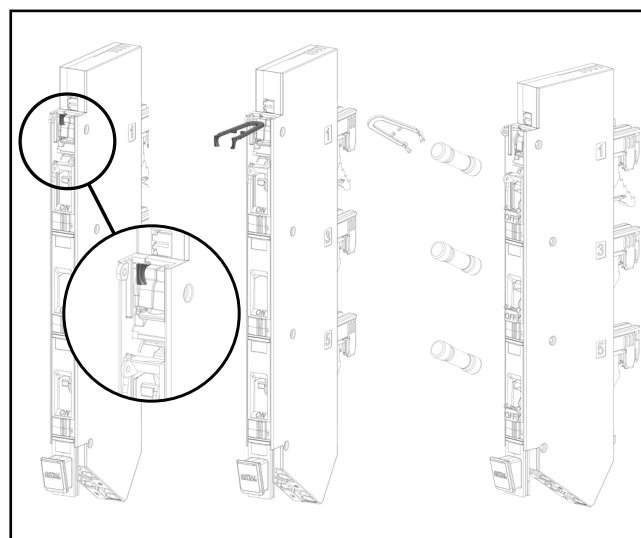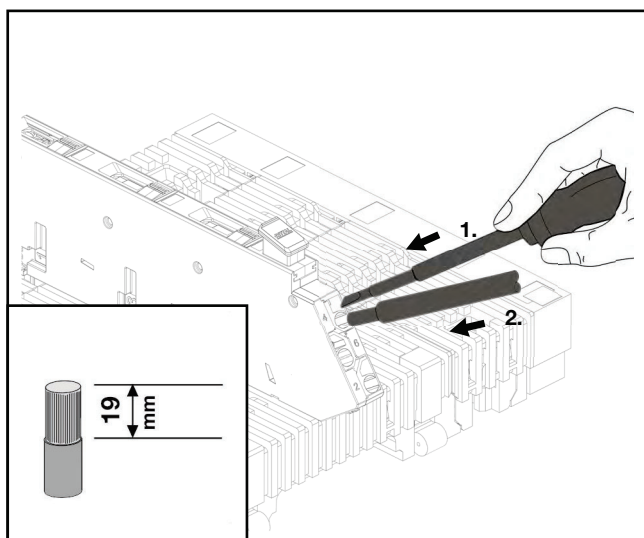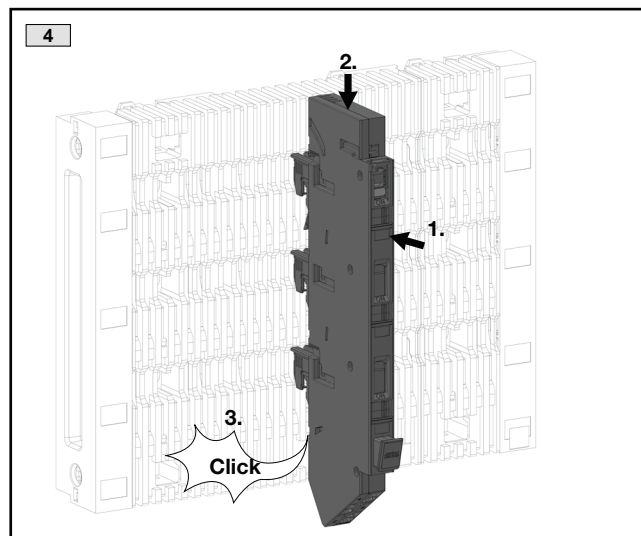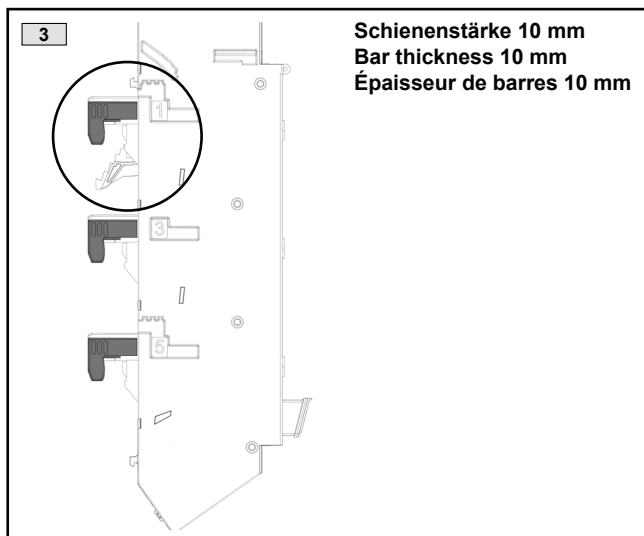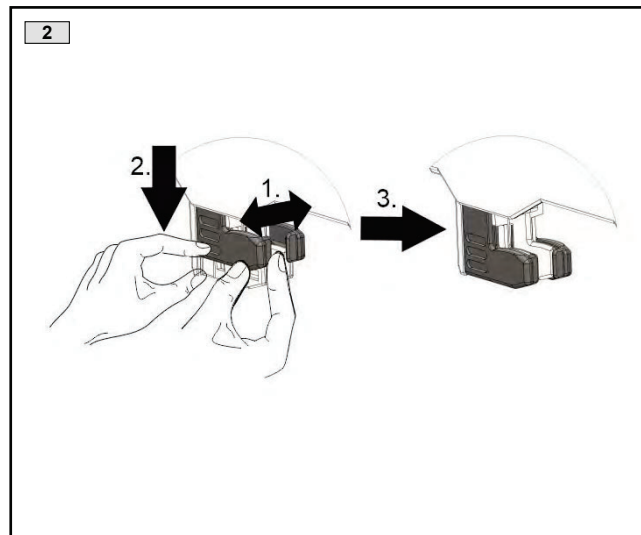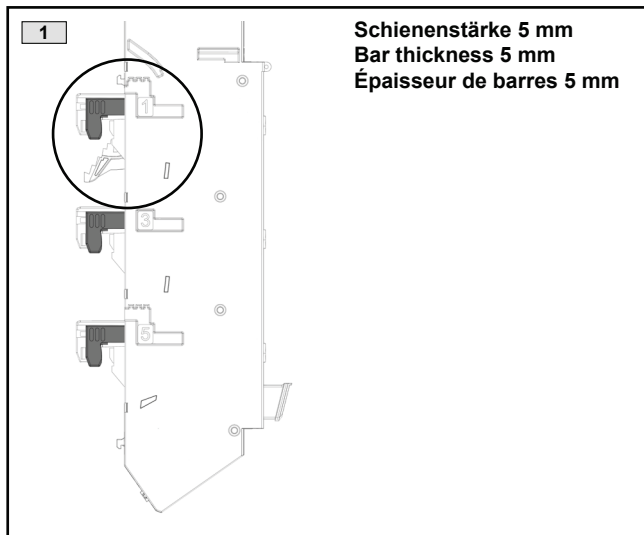

Bauteil Component Composant	Baugröße Size Taille	Wert Value Intensité	Bemerkung Comment Remarque
Sicherungseinsatz Fuse insert Type de fusibles	10x38	2 ... 32 A	