
 
 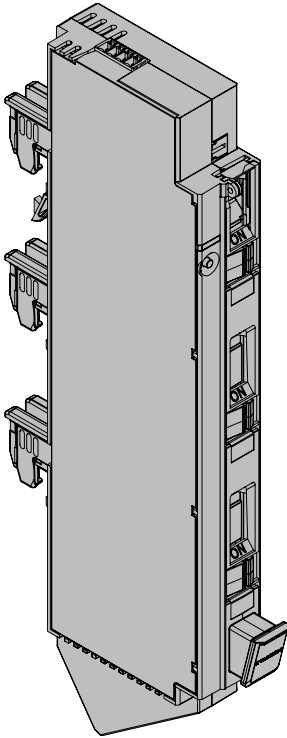








 


www.rittal.com

4 x



|     | Rundleiter eindrätig<br>Round conductor single-wire<br>Conducteur rond unifilaire   | Rundleiter mehrdrätig<br>Round conductor multi-wire<br>Conducteur rond multifilaire | Feindrätig<br>Fine wires<br>Fils fins                                                                                                                                                                                                                                                      | Feindrätig mit isolierter<br>Aderendhülse<br>Fine wires with insulated<br>ferrule<br>Fils fins avec embout isolé | Feindrätig mit unisolierter<br>Aderendhülse<br>Fine wires with uninsulated<br>ferrule<br>Fils fins avec embouts<br>non-isolés |
|-----|-------------------------------------------------------------------------------------|-------------------------------------------------------------------------------------|--------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|------------------------------------------------------------------------------------------------------------------|-------------------------------------------------------------------------------------------------------------------------------|
|     |  |  |                                                                                                                                                                                                         |                             |                                          |
| IEC | 1,5 ... 6 mm <sup>2</sup> (Cu)                                                      | 1,5 ... 6 mm <sup>2</sup> (Cu)                                                      | 1,5 ... 6 mm <sup>2</sup> (Cu)<br>(feindrätig + Aderendhülse eventuell nicht mit maximalem Querschnitt möglich)<br>(fine-wire + wire end ferrule may be not possible with the maximum cross-section)<br>(fils de faible diamètre + embout éventuellement impossible avec section maximale) |                                                                                                                  |                                                                                                                               |

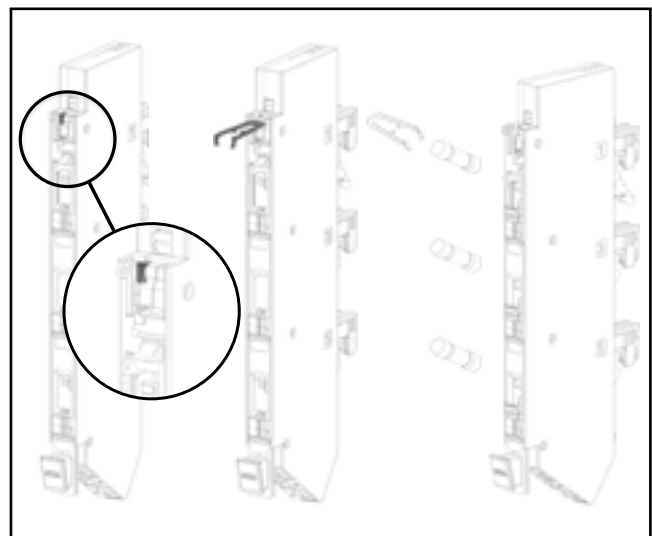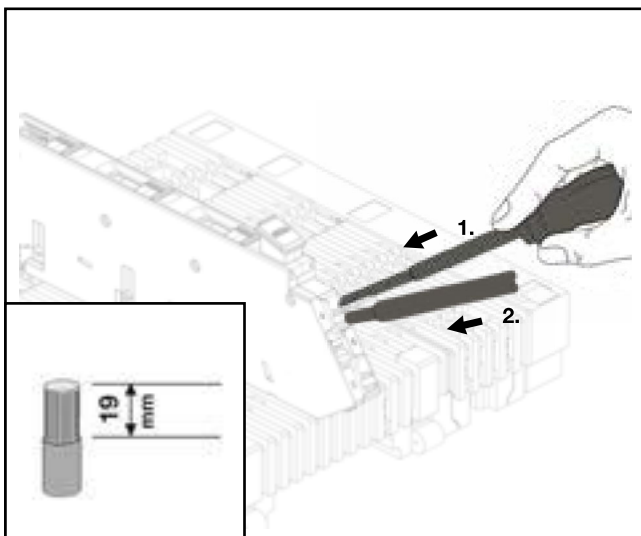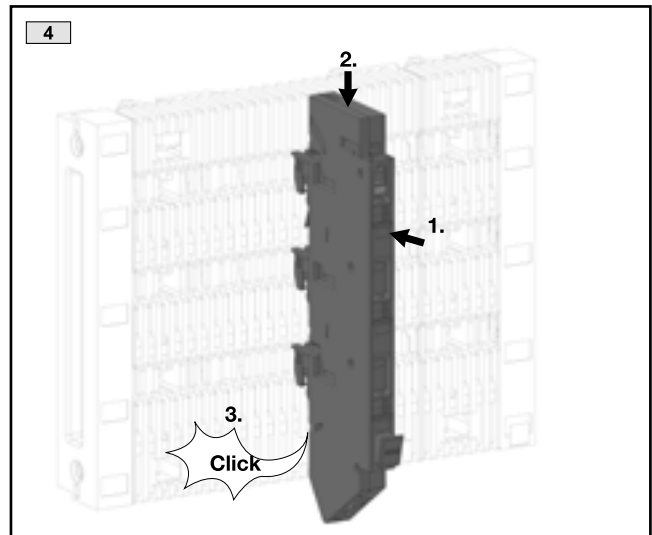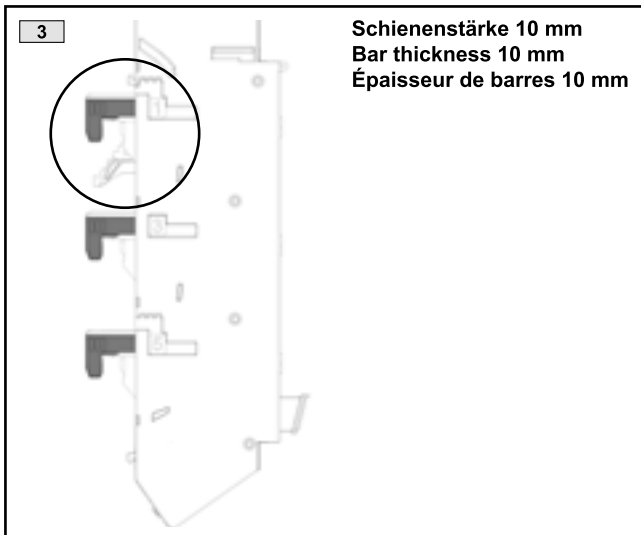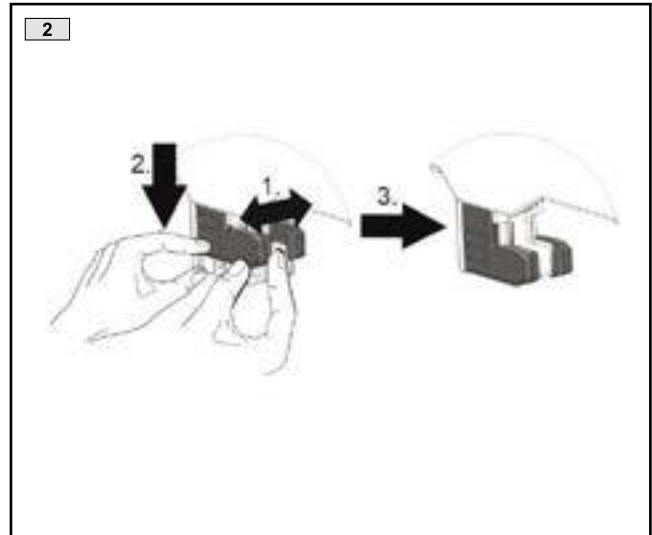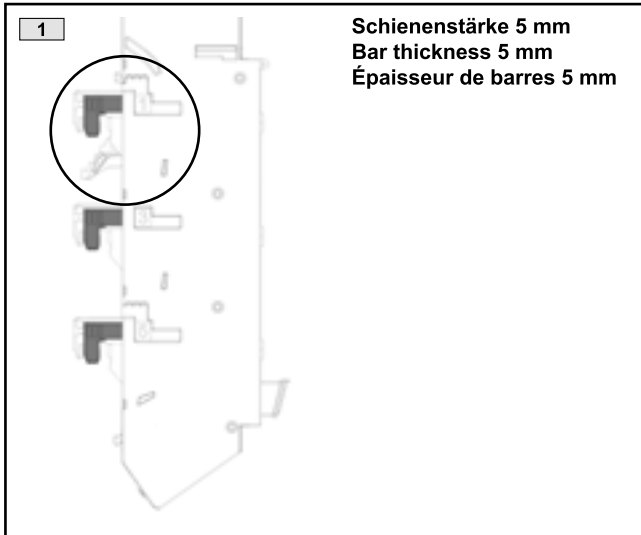

| Bauteil<br>Component<br>Composant                    | Baugröße<br>Size<br>Taille | Wert<br>Value<br>Intensité | Bemerkung<br>Comment<br>Remarque |
|------------------------------------------------------|----------------------------|----------------------------|----------------------------------|
| Sicherungseinsatz<br>Fuse insert<br>Type de fusibles | 10x38                      | 2 ... 32 A                 |                                  |