




www.rittal.com


DE Kurzanleitung
EN Quick Start Guide
FR Guide de démarrage rapide
BG Кратко ръководство
PT Guia rápido
SI Kratek vodnik
IE Treoir thapa
NL Beknopte gids
DK Hurtig guide

HU Gyors útmutató
ET Kiirjuhend
FI Pikaopas
EL Γρήγορος οδηγός
RO Ghid rapid
ES Guía rápida
IT Guida rapida
PL Krótki przewodnik
ZH 快速指南


SK Stručný sprievodca
HR Vodič za brzi početak
LV Īss ceļvedis
SE Snabbguide
CZ Stručný průvodce
LT Trumpasis vadovas
MT Gwida ta' bidu ta' malajr
JA クイックガイド

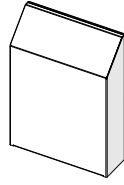

1

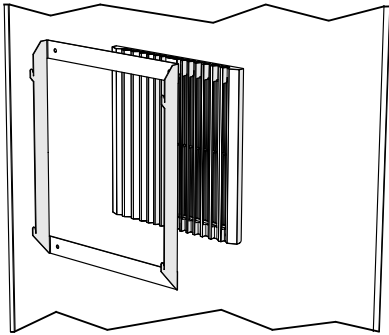


2

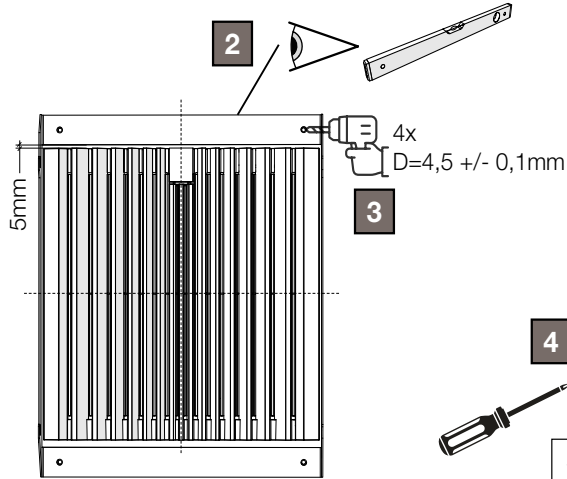

3


4

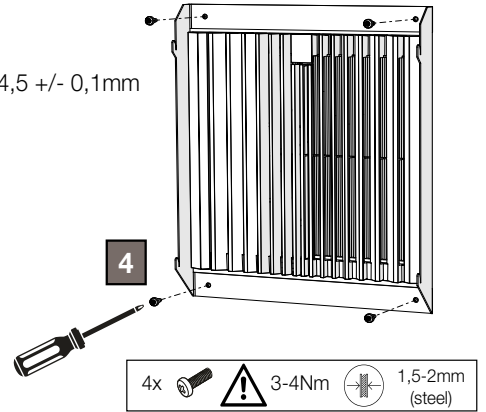



4x 3-4Nm 1,5-2mm (steel)

TX30


5

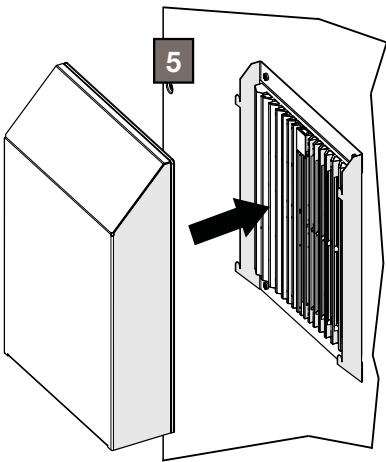

4x

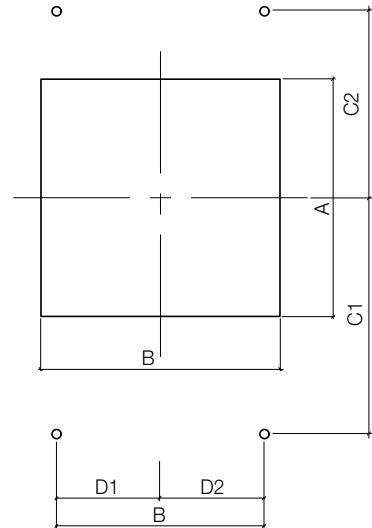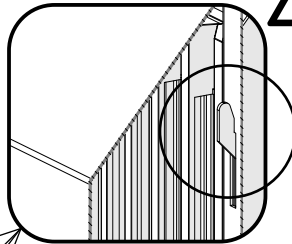

6

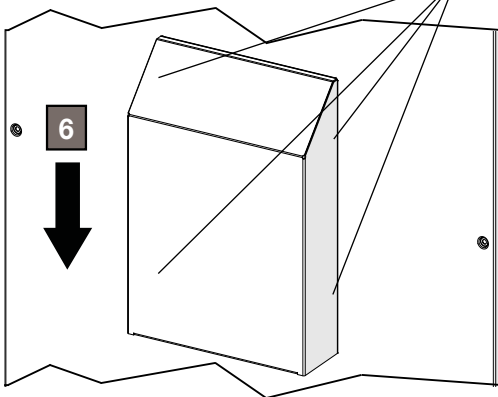

	A=B	C1	C2	D1=D2
3237.080	92	92	72	40
3238.080	124	108	88	56
3239.080	177	122,5	118,5	84
3240.080	224	150,5	146,5	109
3243.080	292	187	183	143
3245.080	292	187	183	143