


Compact enclosures

Compact enclosures AX



Operating housing AX

with handle strips, service access from the front

Section A – A

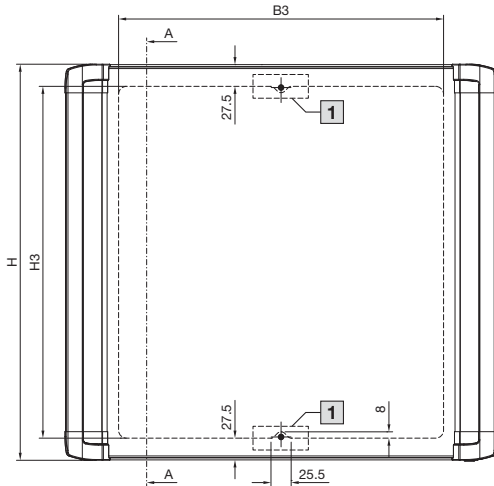

1 Not applicable to AX 6315.150

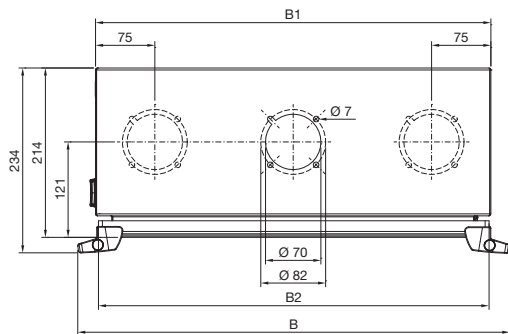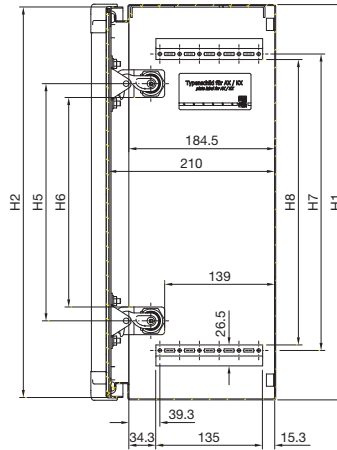

Enclosure

B = Overall width with handle strips

B1 = Enclosure width

B2 = Door width

B3 = Maximum usable mounting space in the width

H = Overall height with handle strips

H1 = Enclosure height

H2 = Door height

B3 = Maximum usable mounting space in the height

H5 = Lock spacing

H6 = Clearance height between positioning brackets

H7 = Mounting distance between mounting brackets

H8 = Clearance height between mounting brackets



Model No. AX	Width dimensions mm				Height dimensions mm							
	B	B1	B2	B3	H	H1	H2	H3	H5	H6	H7	H8
6315.150	345	300	294	211	301	300	294	245	–	–	175	161
6315.250	425	380	374	291	301	300	294	245	–	–	175	161
6315.350	425	380	374	291	381	380	374	325	–	–	275	261
6315.450	545	500	494	411	501	500	494	445	300	265	375	361
6315.650	645	600	594	511	601	600	594	545	400	365	475	461

Operating housing AX

with handle strips, service access from the rear

AX 6320.050, AX 6320.150

Section A – A

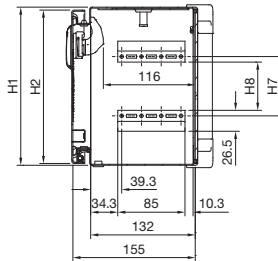
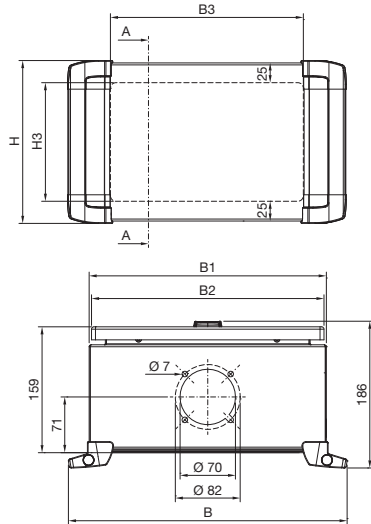


Enclosure

- B = Overall width with handle strips
- B1 = Enclosure width
- B2 = Door width
- B3 = Maximum usable mounting space in the width
- H = Overall height with handle strips
- H1 = Enclosure height
- H2 = Door height
- B3 = Maximum usable mounting space in the height
- H7 = Mounting distance between mounting brackets
- H8 = Clearance height between mounting brackets

AX 6320.350, AX 6320.450, AX 6320.550, AX 6320.650

Section A – A

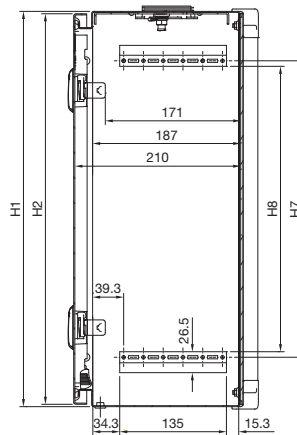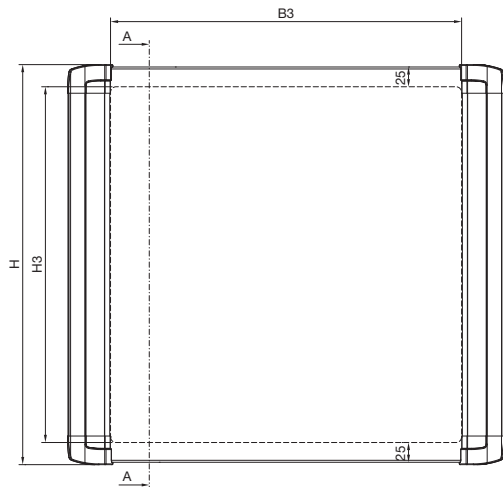

Model No. AX	Width dimensions mm				Height dimensions mm					
	B	B1	B2	B3	H	H1	H2	H3	H7	H8
6320.050	352.5	300	294	244	206	200	194	150	75	61
6320.150	702.5	650	644	594	456	450	444	400	275	261
6320.350	432.5	380	374	324	386	380	374	330	275	261
6320.450	552.5	500	494	444	506	500	494	450	375	361
6320.550	652.5	600	594	544	386	380	374	330	275	261
6320.650	652.5	600	594	544	606	600	594	550	475	461