


# System accessories

## Interior fit-out

### Mounting plates

for KX terminal boxes, KX bus enclosures, HD terminal boxes, stainless steel Ex enclosures with screw-fastened cover

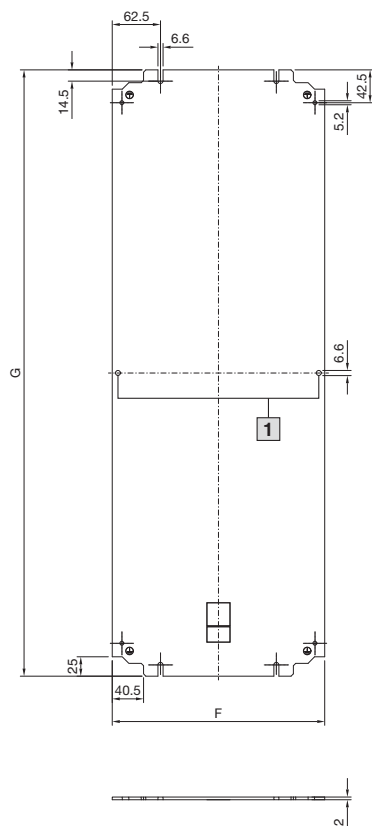

Model No. KX	For enclosure dimensions mm	F	G	For enclosure Model No.
1560.800	150 x 150	125	135	1500.000, 1514.000, 1560.000, 1564.000, 1670.600, 1671.600, 9301.000
1575.800	200 x 150	125	185	1528.000, 1529.000
1561.800	300 x 150	125	285	1501.000, 1515.000, 1530.000, 1561.000, 9302.000
1576.800	400 x 150	125	385	1589.000
1562.800	200 x 200	175	185	1502.000, 1516.000, 1562.000, 1565.000, 1672.600, 9303.000
1563.800	300 x 200	175	285	1503.000, 1517.000, 1531.000, 1563.000, 1566.000, 1583.000, 1674.600, 9304.000
1564.800	400 x 200	175	385	1504.000, 1518.000, 1532.000, 1568.000, 1585.000, 1610.000, 1675.600, 9305.000
1565.800	500 x 200	175	485	1505.000, 1533.000
1566.800	600 x 200	175	585	1506.000, 1586.000
1574.800	800 x 200	175	785	1527.000
1567.800	300 x 300	275	285	1507.000, 1535.000, 1567.000, 9306.000
1568.800	400 x 300	275	385	1508.000, 1536.000, 1569.000, 1611.000, 1676.600
1569.800	500 x 300	275	485	1509.000, 1537.000
1570.800	600 x 300	275	585	1510.000, 1538.000, 1612.000
1570.810	800 x 300	275	785	1613.000
1571.800	400 x 400	375	385	1511.000, 1539.000
1572.800	600 x 400	375	585	1512.000, 1540.000
1573.800	800 x 400	375	785	1513.000, 1541.000

F = Mounting plate width  
G = Mounting plate height

1 Holes in the centre only with G = 785