


System accessories




Roof

VX protective roof

Stainless steel

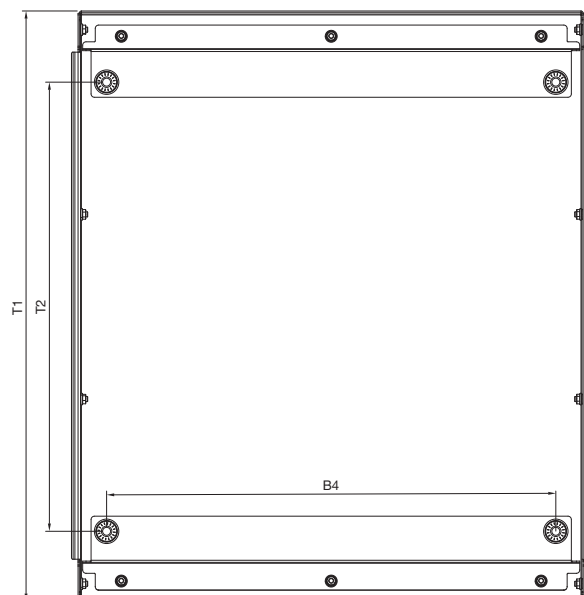

Side end pieces
Version l/h Version r/h side

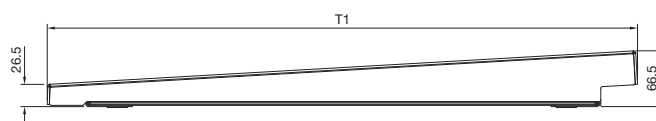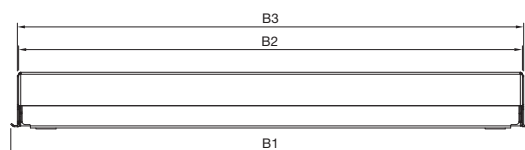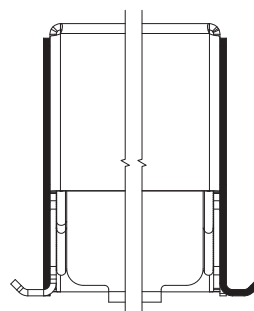

B1 = Total width of protective roof with side end pieces
B2 = Width of protective roof with side end pieces
B3 = Width of protective roof without side end pieces
B4 = Distance between mounting points of enclosure

T1 = Overall depth of protective roof
T2 = Distance between mounting points of enclosure

Model No. VX		For enclosure width mm	For enclosure depth mm	Width dimensions mm				Depth dimensions mm	
Protective roof	Side end pieces			B1	B2	B3	B4	T1	T2
8604.455	8104.460	600	400	619.2	603	600	535	503	335
8605.455	8105.460	600	500	619.2	603	600	535	603	435
8606.455	8106.460	600	600	619.2	603	600	535	703	535
8608.455	8108.460	600	800	619.2	603	600	535	903	735
8806.455	8106.460	800	600	819.2	803	800	735	703	535
8808.455	8108.460	800	800	819.2	803	800	735	903	735