
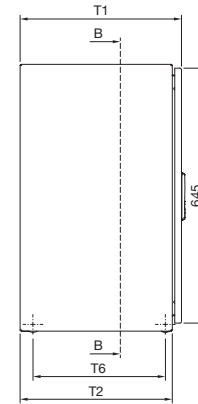
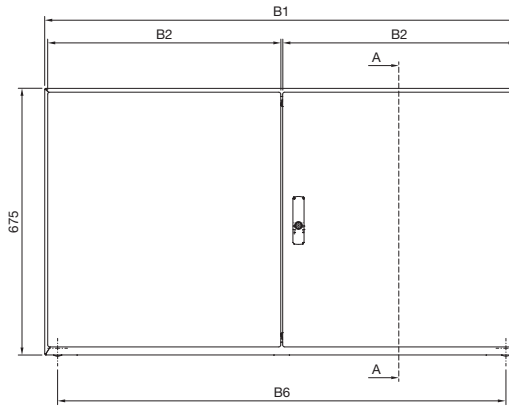


Enclosures



CX console system

CX pedestal


Width 600/800/1200/1600 mm

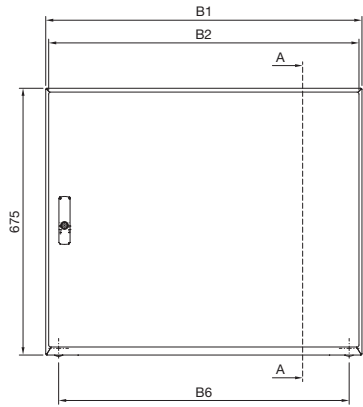


Mounting plate

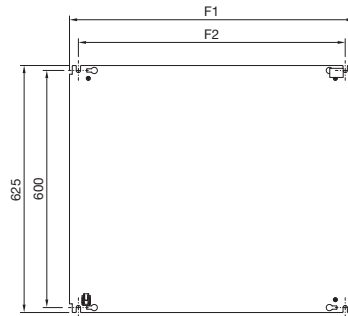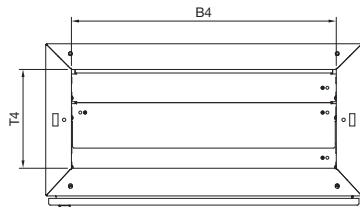


Section A – A

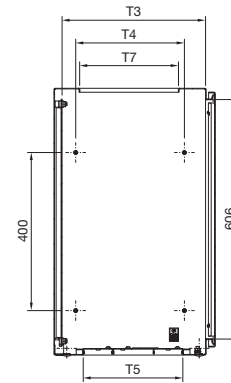

Section B – B

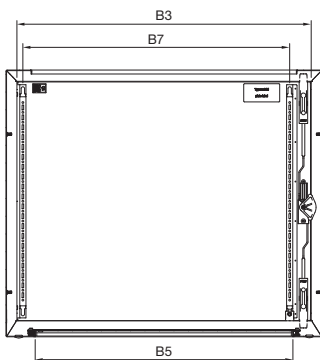

Section B – B

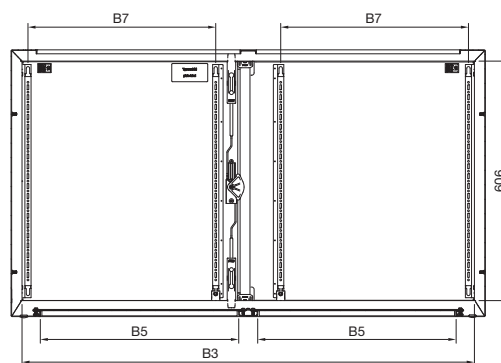

Enclosure

- B1 = Enclosure width
- B2 = Door width
- B3 = Clearance width, front
- B4 = Clearance width, top
- B5 = Clearance width, bottom
- B6 = Mounting distance, base/plinth
- B7 = Mounting distance, door

- T1 = Overall depth
- T2 = Enclosure depth
- T3 = Installation depth
- T4 = Clearance depth, top
- T5 = Clearance depth, bottom
- T6 = Mounting distance, base/plinth
- T7 = Interior installation depth

Mounting plate

- F1 = Mounting plate width
- F2 = Centre-to-centre spacing of the attachment holes

Model No. CX	Width dimensions mm							Depth dimensions mm							Mounting plate mm	
	B1	B2	B3	B4	B5	B6	B7	T1	T2	T3	T4	T5	T6	T7	F1	F2
6700.000	600	585	544.5	470	452	535	475	408	385	363	250	252	335	275	520	475
6701.000	800	785	744.5	670	652	735	675	408	385	363	250	252	335	275	720	675
6702.000	1200	585	1144.5	515	1052	1135	475	408	385	363	250	252	335	275	1120	1075
6703.000	1600	785	1544.5	615	1452	1535	675	408	385	363	250	252	335	275	1520	1475
6704.000	600	585	544.5	470	452	535	475	508	485	463	350	352	435	375	520	475
6705.000	800	785	744.5	670	652	735	675	508	485	463	350	352	435	375	720	675
6706.000	1200	585	1144.5	515	1052	1135	475	508	485	463	350	352	435	375	1120	1075
6707.000	1600	785	1544.5	615	1452	1535	675	508	485	463	350	352	435	375	1520	1475