


# Kompakt-Schaltschränke

## Kompakt-Schaltschränke AX


### Wandgehäuse AX

3-teilig, komplett montiert


Frontansicht

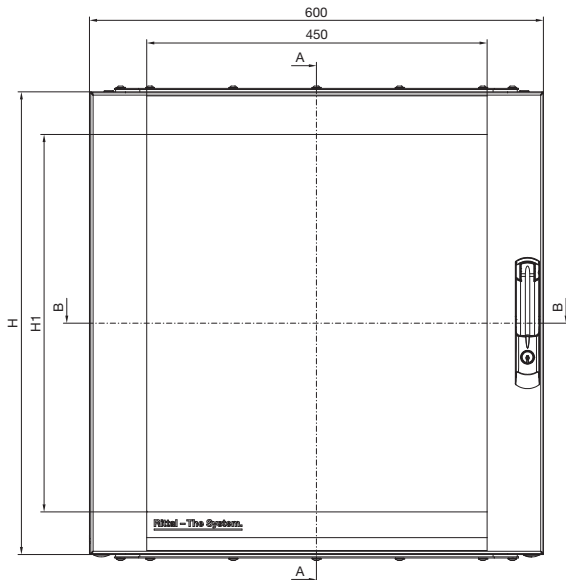

Schnitt A - A

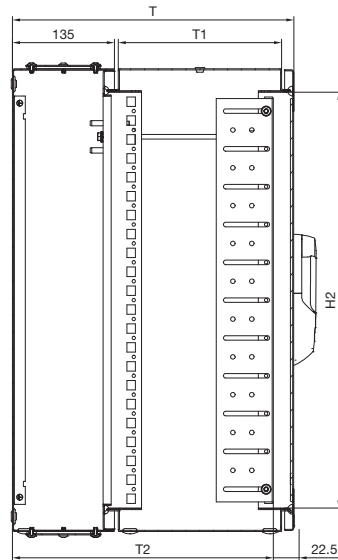

Schnitt B - B

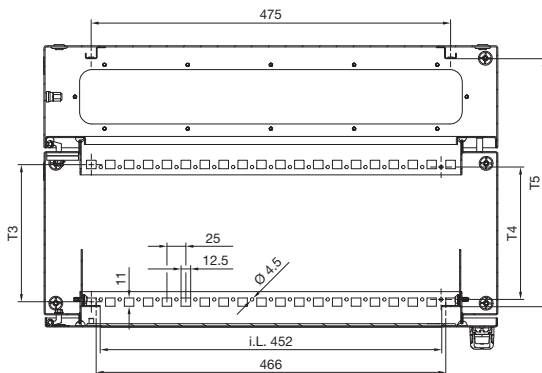

Art.-Nr. AX	Höhenmaße mm				Tiefenmaße mm					
	HE	H	H1	H2	T	T1	T2	T3	T4	T5
2260630	6	345	232,5	284	372	216	343,5	182	175	328
2260640	6	345	232,5	284	472	316	443,5	282	275	428
2260930	9	478	365,8	417	372	216	343,5	182	175	328
2260940	9	478	365,8	417	472	316	443,5	282	275	428
2260950	9	478	365,8	417	572	416	543,5	382	375	528
2260960	9	478	365,8	417	672	516	643,5	482	475	628
2261230	12	612	499,2	551	372	216	343,5	182	175	328
2261240	12	612	499,2	551	472	316	443,5	282	275	428
2261540	15	745	632,5	684	472	316	443,5	282	275	428
2261550	15	745	632,5	684	572	416	543,5	382	375	528
2261560	15	745	632,5	684	672	516	643,5	482	475	628
2262130	21	1012	899,2	951	372	216	343,5	182	175	328
2262140	21	1012	899,2	951	472	316	443,5	282	275	428
2262150	21	1012	899,2	951	572	416	543,5	382	375	528
2262160	21	1012	899,2	951	672	516	643,5	482	475	628