

www.rittal.com

SV

9666.903

9666.913

9666.923

9666.933

| Best.-Nr.<br>Model No.<br>Référence | 9666.903 | 9666.913 | 9666.923 | 9666.933 |                                                                                       |         |
|-------------------------------------|----------|----------|----------|----------|---------------------------------------------------------------------------------------|---------|
| A                                   | 4 x      | 4 x      | 4 x      | -        |    |         |
|                                     | -        | -        | -        | 4 x      |    |         |
| B                                   | 1 x      | 1 x      | 1 x      | 2 x      |    |         |
| C                                   | 1 x      | 1 x      | 1 x      | -        |   |         |
| D                                   | 2 x      | 4 x      | 6 x      | 2 x      |  |         |
| E                                   | 4 x      | 4 x      | 4 x      | 4 x      |  |         |
| F                                   | 2 x      | 4 x      | 6 x      | 2 x      |  | 16 x 54 |
| G                                   | 4 x      | 4 x      | 4 x      | 4 x      |  | 16 x 39 |
| H                                   | 6 x      | 8 x      | 10 x     | 6 x      |  |         |
| I                                   | -        | -        | 1 x      | -        |  |         |
|                                     | 1 x      | 1 x      | -        | 1 x      |  |         |
| J                                   | -        | -        | 1 x      | -        |  |         |
|                                     | 1 x      | 1 x      | -        | 1 x      |  |         |
| K                                   | 4 x      | 4 x      | 4 x      | 4 x      |  |         |
| L                                   | 2 x      | 2 x      | 2 x      | 2 x      |  |         |
| M                                   | 16 x     | 16 x     | 16 x     | 16 x     |  |         |
| N                                   | 12 x     | 12 x     | 12 x     | 12 x     |  |         |
| O                                   | 110 x    | 122 x    | 134 x    | 110 x    |  | M5 x 12 |

Dok.-Nr. / No. of doc.: D-0000-00004886-01  
Versandbeutel-Nr. / No. of accessory bag:

Lieferanten-Nr. / No. of supplier:




RITTAL GmbH & Co. KG, Auf dem Stuetzelberg, 35745 Herborn  
RITTAL Limited, Bralthwell Way, Helliaby, Rotherham, S66 8QY, UK

DIN A5, doppelseitig  
DIN A5, double sheet

mm



TX30

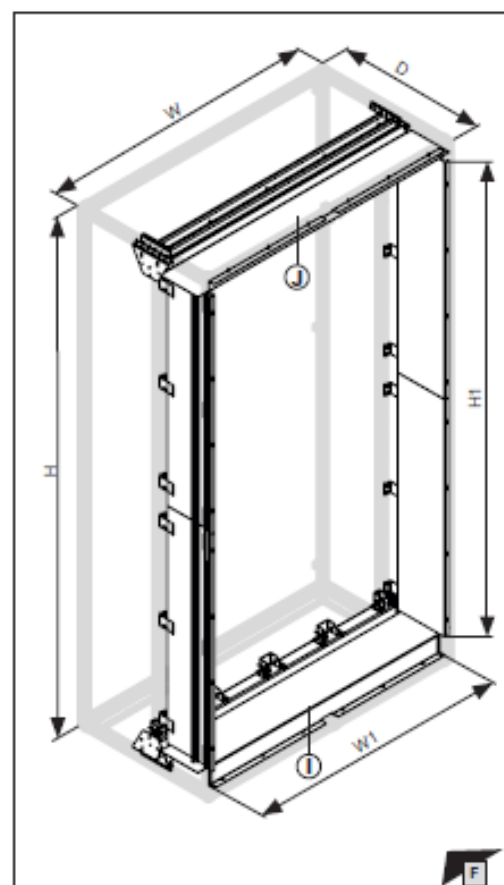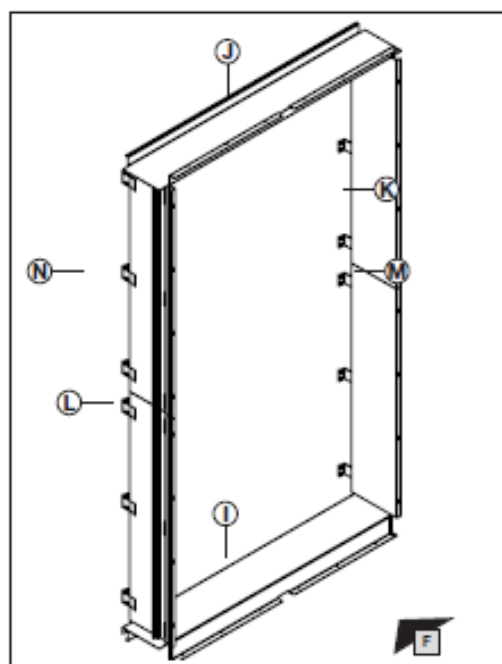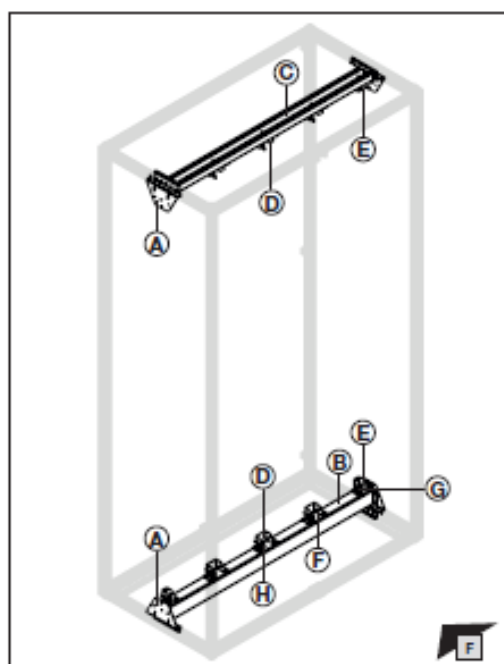

| ① + ②             |          |                                     | Passend für Best.-Nr.<br>To fit Model No.<br>Pour référence(s) |                                     |
|-------------------|----------|-------------------------------------|----------------------------------------------------------------|-------------------------------------|
| H1                | W1       | Best.-Nr.<br>Model No.<br>Référence | W x H x D                                                      | Best.-Nr.<br>Model No.<br>Référence |
| 1500              | 500      | 9666.933                            | 600 x 1800 x 400                                               | 8684.000                            |
|                   |          |                                     | 600 x 1800 x 500                                               | 8457.000                            |
|                   |          |                                     |                                                                | 8685.000                            |
|                   |          | 600 x 1800 x 600                    | 8686.000                                                       |                                     |
| 1800              | 500      | 9666.903                            | 600 x 2000 x 400                                               | 8604.000                            |
|                   |          |                                     | 600 x 2000 x 500                                               | 8605.000                            |
|                   |          |                                     | 600 x 2000 x 600                                               | 8606.000                            |
|                   | 8452.000 |                                     |                                                                |                                     |
|                   | 750      | 9666.913                            | 850 x 2000 x 400                                               | 9666.956                            |
|                   |          |                                     | 850 x 2000 x 600                                               | 9666.916                            |
|                   | 1000     | 9666.923                            | 1100 x 2000 x 400                                              | 9666.966                            |
| 1100 x 2000 x 600 |          |                                     | 9666.926                                                       |                                     |

 Moment  
 Torque  
 Torque


M5 x 12

5 Nm / 44 in-lbs