



www.rittal.com

1x

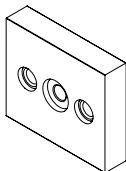

1x



M10/M12

1x



A13

1x



12,2

1x



M12

 


2x




M = 40 Nm / 354 in-lbs



M = 10 Nm / 88 in-lbs

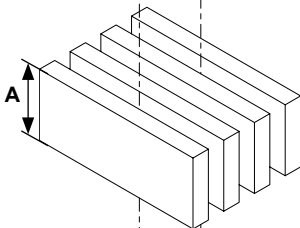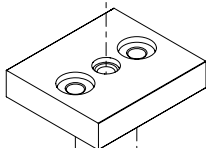

B

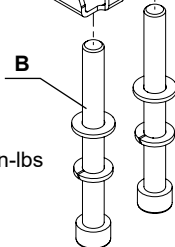

M = 40 Nm / 354 in-lbs

A	B	Best.-Nr. Model No. Référence
30	M10x50	9676.805
40	M10x60	9676.806
50	M10x70	9676.807
60	M10x80	9676.808
80	M10x100	9676.810
100	M10x120	9676.812