


Enclosures

Wall-mounted network enclosures

Wall-mounted enclosure EL, 3-part

Depth 573/673 mm, pre-configured Catalogue 33, page 62



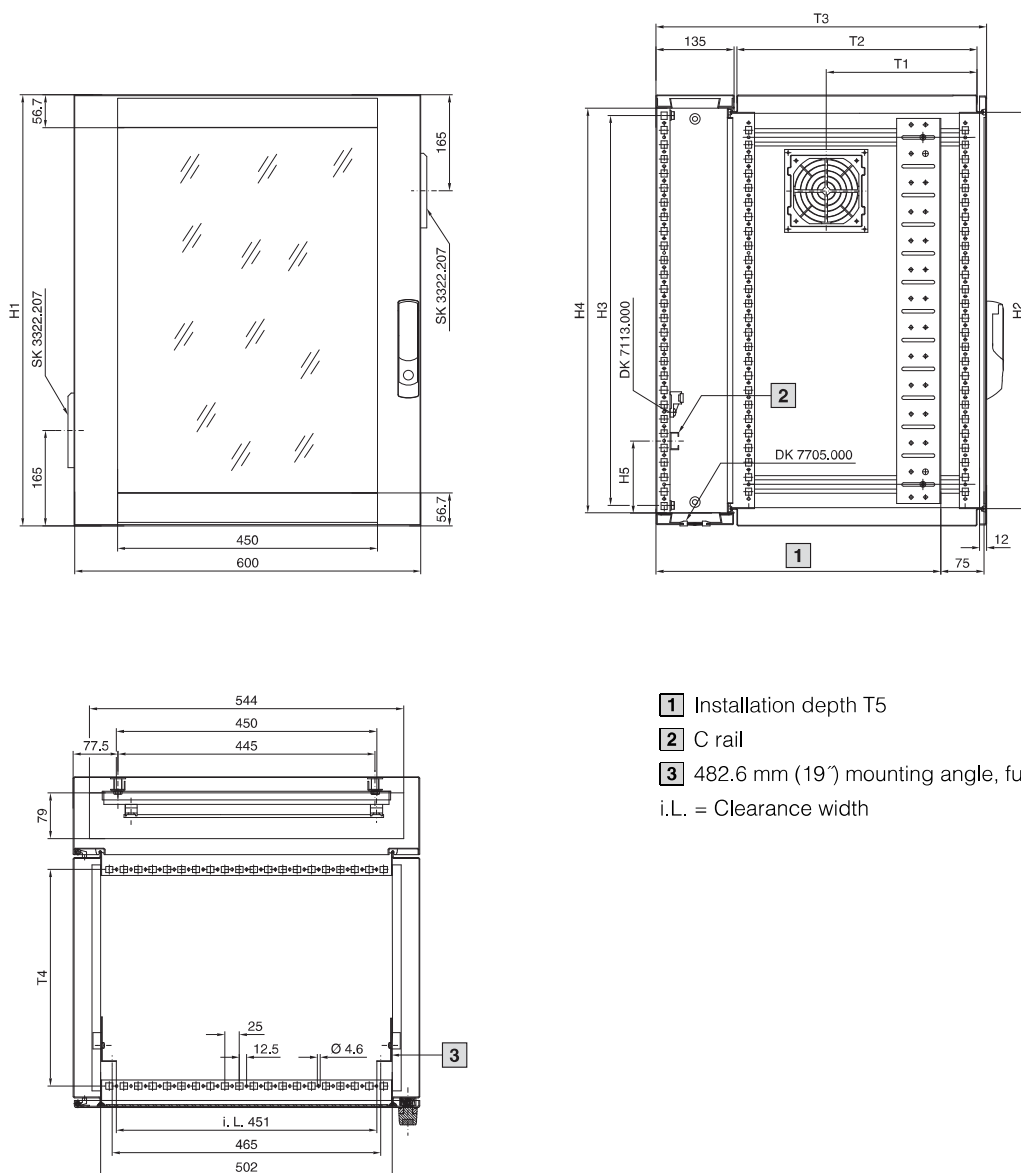


- 1 Installation depth T5
 - 2 C rail
 - 3 482.6 mm (19") mounting angle, fully depth-adjustable
- i.L. = Clearance width

Model No. DK	Enclosure depth mm	U	Height dimensions mm					Depth dimensions mm				
			H1	H2	H3	H4	H5	T1	T2	T3	T4	T5
7709.735	573	9	478	415	407	432	103.5	261	416	572.5	375	491.5 – max. 520
7715.735		15	746	684	674	699	124.5	261	416	572.5	375	491.5 – max. 520
7721.735		21	1012	949	941	965	133	261	416	572.5	375	491.5 – max. 520
7709.535	673	9	478	415	407	432	103.5	361	516	672.5	475	491.5 – max. 520
7715.535		15	746	684	674	699	124.5	361	516	672.5	475	491.5 – max. 520
7721.535		21	1012	949	941	965	133	361	516	672.5	475	491.5 – max. 520

Wall-mounted enclosure EL, 3-part

Depth 473 mm, with punched rails Catalogue 33, page 63

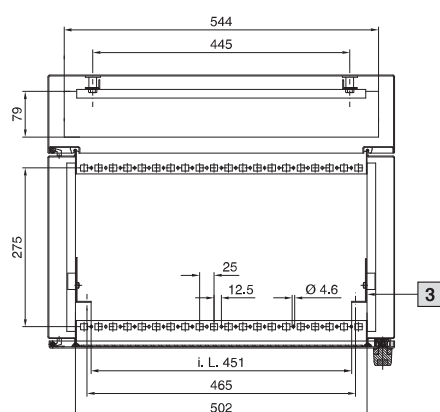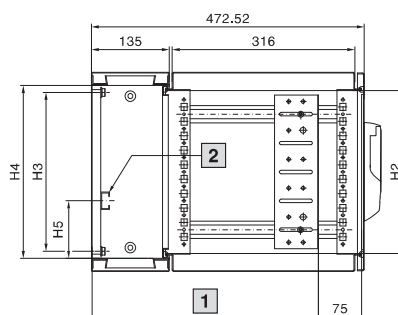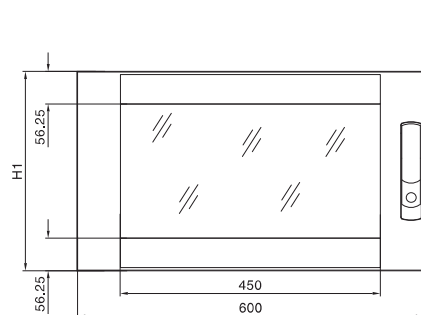

- 1** Installation depth D
 - 2** C rail
 - 3** 482.6 mm (19") mounting angle, fully depth-adjustable
- i.L. = Clearance width


Model No. DK	U	Height dimensions mm					Depth dimensions mm
		H1	H2	H3	H4	H5	D
7706.135	6	345	284	274	299	99.5	391 – max. 420
7709.135	9	478	417	407	432	103.5	391 – max. 420
7712.135	12	612	551	540	565	120	391 – max. 420
7715.135	15	746	684	674	699	124.5	391 – max. 420
7718.135	18	878	817	807	832	128.5	391 – max. 420
7721.135	21	1012	951	941	965	133	391 – max. 420

Enclosures

Wall-mounted network enclosures

Wall-mounted enclosure EL, 3-part


Depth 373/473 mm, with mounting plate Catalogue 33, page 64, 65

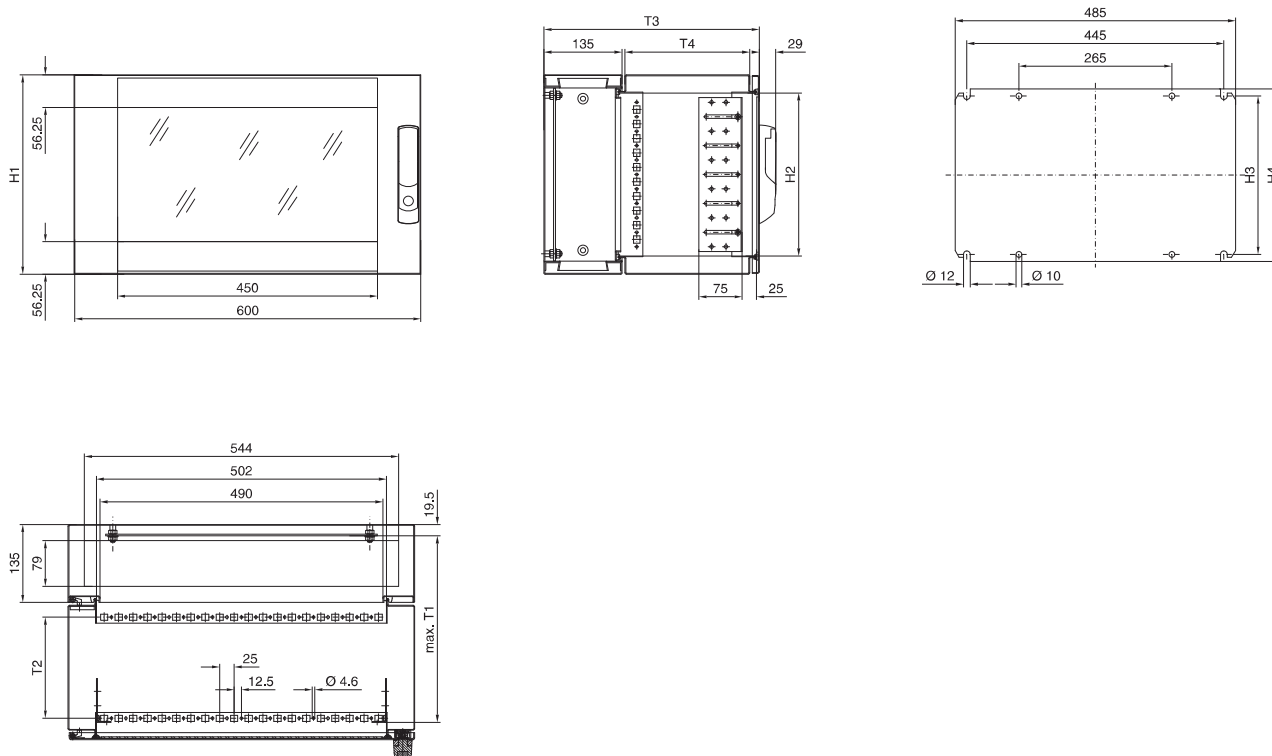

Model No. DK	Enclosure depth mm	U	Height dimensions mm				Depth dimensions mm			
			H1	H2	H3	H4	T1	T2	T3	T4
2243.605	373	3	212	151	141	165	320	175	372.5	216
2246.605		6	345	284	274	299	320	175	372.5	216
2249.605		9	478	417	407	432	320	175	372.5	216
2252.605		12	612	551	541	565	320	175	372.5	216
2255.605		15	746	684	674	699	320	175	372.5	216
2258.605		18	878	817	807	832	320	175	372.5	216
2261.605		21	1012	951	941	965	320	175	372.5	216
2253.605	473	3	212	151	141	165	420	275	472.5	316
2256.605		6	345	284	274	299	420	275	472.5	316
2259.605		9	478	417	407	432	420	275	472.5	316
2262.605		12	612	551	541	565	420	275	472.5	316
2265.605		15	746	684	674	699	420	275	472.5	316
2268.605		18	878	817	807	832	420	275	472.5	316
2271.605		21	1012	951	941	965	420	275	472.5	316

Wall-mounted enclosure EL, 2-part

Depth 369 mm, with swing frame Catalogue 33, page 66

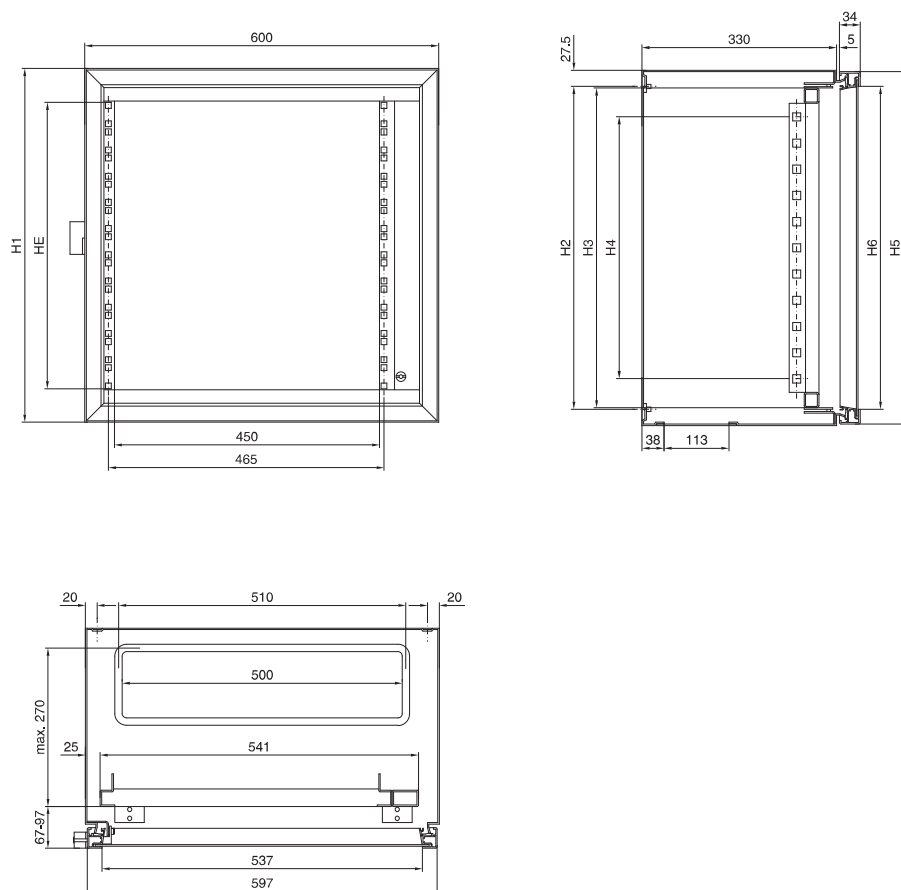

Model No. DK	U (HE)	Height dimensions mm					
		H1	H2	H3	H4	H5	H6
1919.500	6	380	330	320	222	377	317
1920.500	11	600	545	542	445	597	537
1926.500	14	760	705	676	578	757	697