


Enclosures

Operating housings

Compact Panel


Catalogue 33, page 142

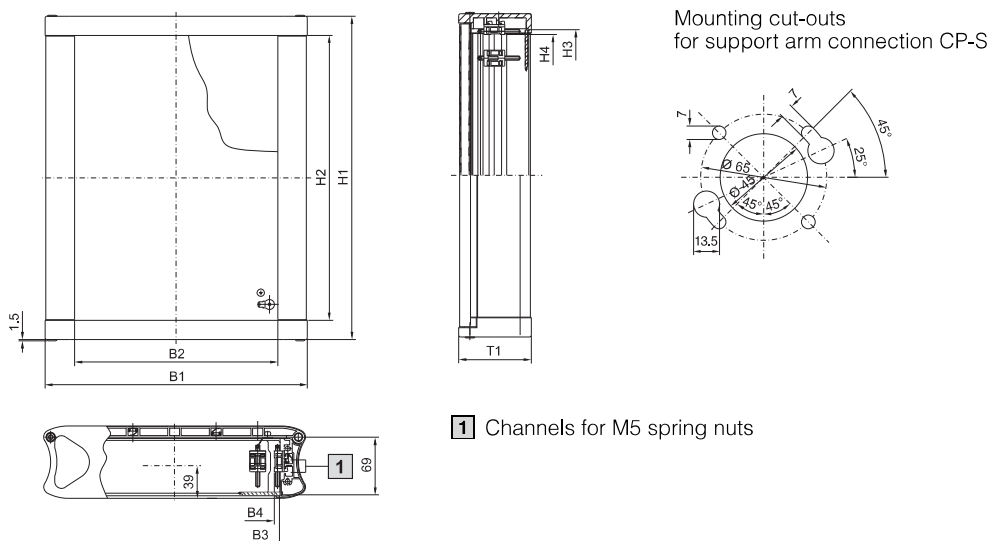

Model No. CP (with support arm connection CP-S)	6340.000	6340.100	6340.300	6340.400
Width (B1) mm	241	241	315	315
Height (H1) mm	238	388	238	388
Depth (T1) mm	87	87	87	87
B2 = Enclosure clearance width	170	170	244	244
B3 = Front panel width	178	178	252	252
B4 = Clearance width between screw clamps	164	164	238	238
H2 = Enclosure clearance height	192	342	192	342
H3 = Front panel height	200	350	200	350
H4 = Clearance height between screw clamps	186	336	186	336

Command panel housing with door

Catalogue 33, page 143

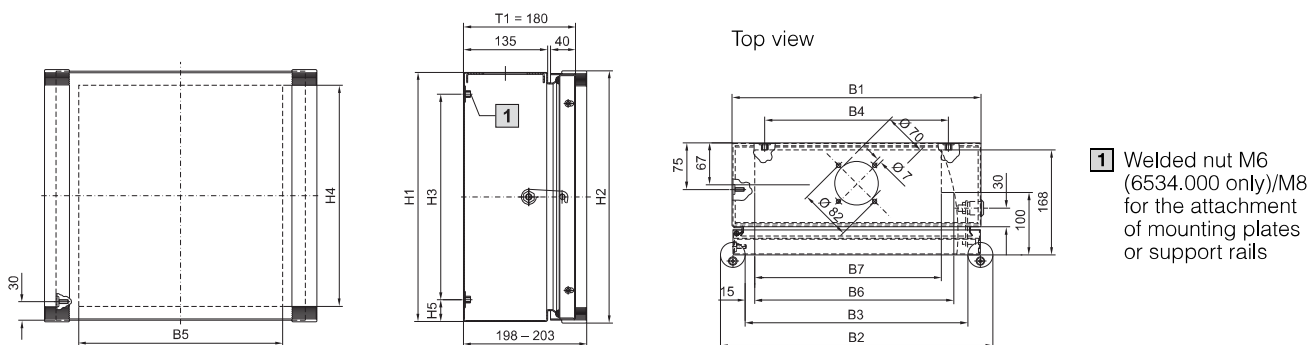

Model No. CP	1	6534.000	6535.000	6537.000	6536.000	6538.000	6544.000
Width (B1) mm	Packs of	300	300	300	400	400	500
Height (H1) mm		200	300	400	300	400	500
Depth (T1) mm		180	180	180	180	180	180
B2 = Enclosure width with handle strips		338	338	338	438	438	538
B3 = Clearance opening, front between handle strips		258	258	258	358	358	458
B4 = Spacing of mounting plate attachment		260	215	215	295	295	410
B5 = Max. front cut-out, width		227	227	227	327	327	427
B6 = Hinged width for depth 100 mm		220	220	220	320	320	420
B7 = Hinged width for depth 168 mm		200	200	200	300	300	400
H2 = Enclosure height with handle strips		205	305	405	305	405	505
H3 = Spacing of mounting plate attachment		122	250	350	250	330	445
H4 = Max. front cut-out, height		155	255	355	255	355	455
H5 = Distance from base – mounting plate attachment		39	25	25	25	35	27.5