

Enclosures


Connection components

Connection adaptor CP-L Ø 130 mm to CP-L □ 120 x 65 mm

Catalogue 33, page 164

CP 6071.000

Section A – A


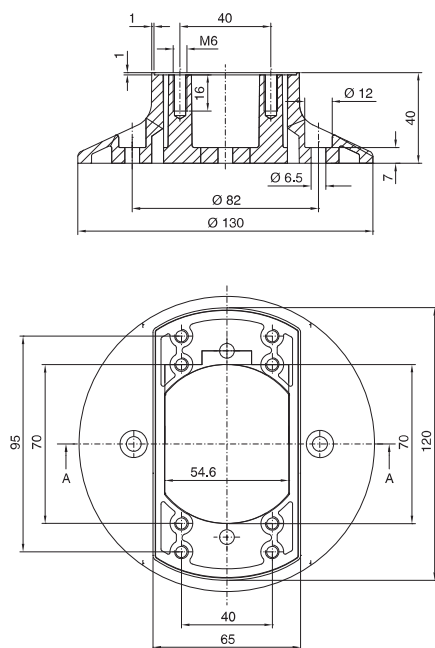


Connection adaptor CP-L to CP-XL

Catalogue 33, page 164

CP 6528.010


CP 6528.510

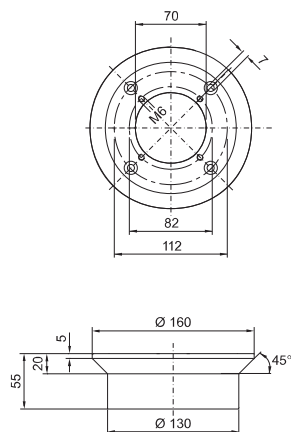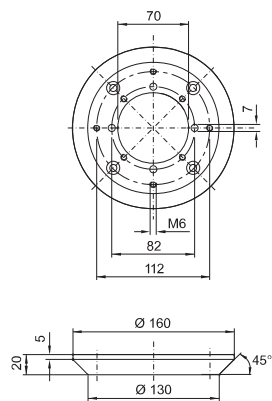

Adaptor for Siemens Pro-Panel

Catalogue 33, page 164


CP 6528.450

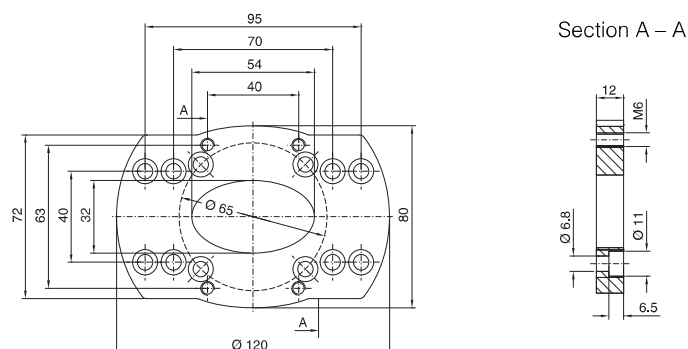

Connection console CP-L for Beckhoff Control-Panels

Catalogue 33, page 164


CP 6508.020

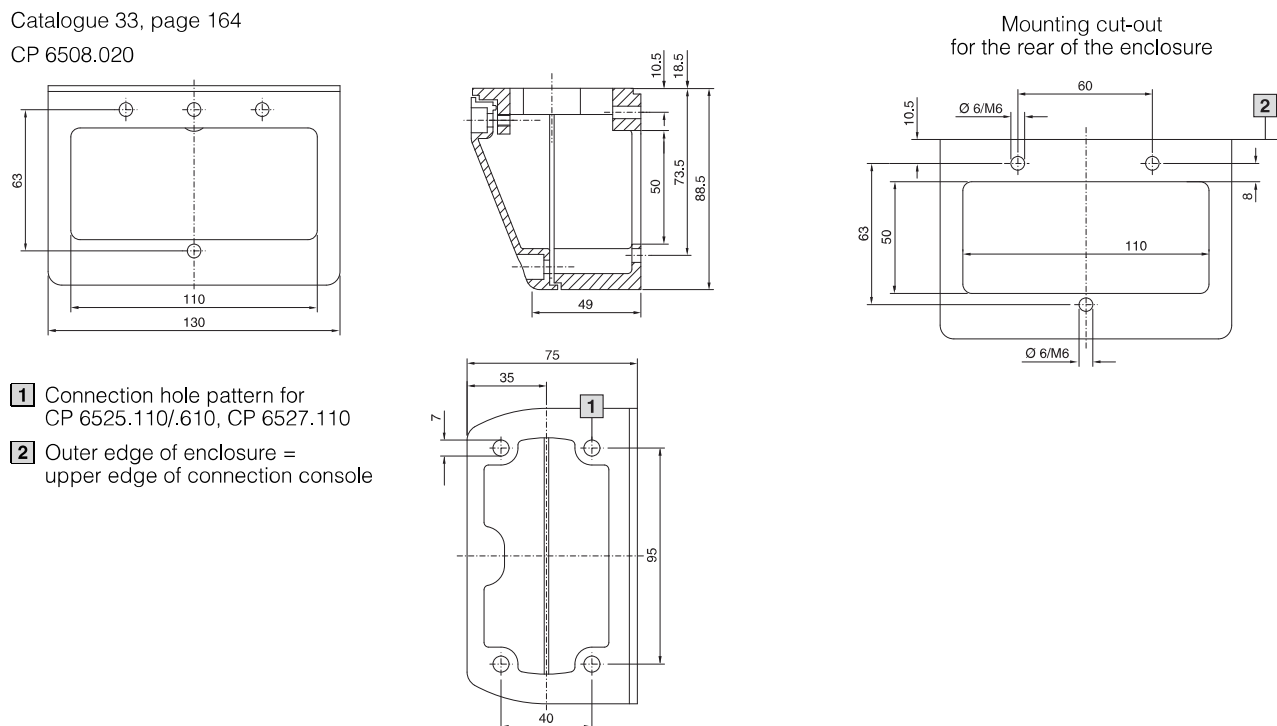

Connection plate CP-L

With reinforcement plate Catalogue 33, page 165

CP 6528.210

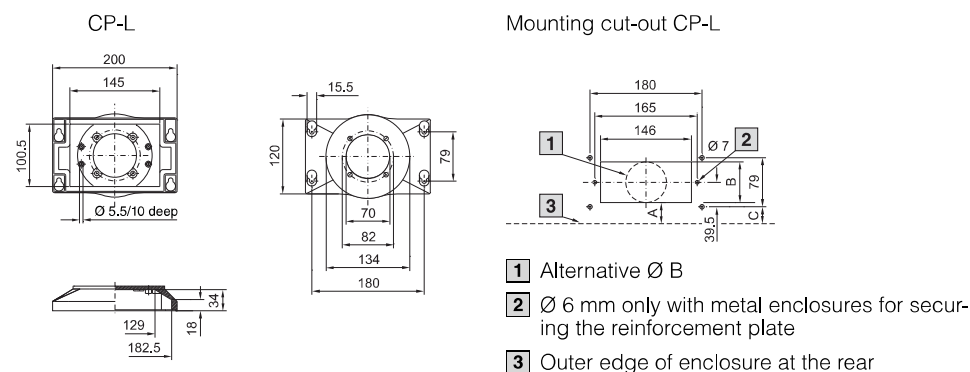

Enclosures


Connection components

Enclosure attachment, tilting, base mounting

CP-L □ 120 x 65 mm Catalogue 33, page 165


IW 6902.640

View B

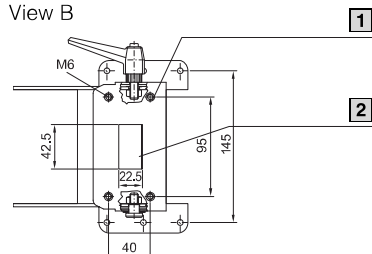

1 Prepared for enclosure with connection CP-L/CP-S, □ 120 x 65 mm or connection console CP-L CP 6508.0X0

2 Preparation for connector grommet SZ 2400.300/SZ 2400.500

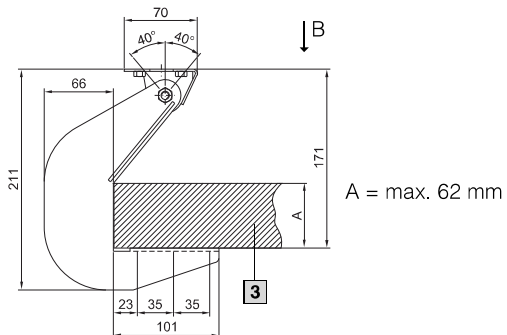


3 Worktop, e.g. IW 6902.310/IW 6902.320

Connection adaptor CP-C to CP-L

Catalogue 33, page 165

CP 6071.600

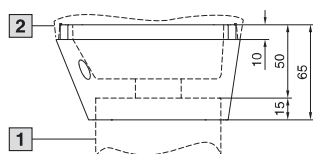

1 Support section CP-L
Support arm, height-adjustable CP-L


2 Connection of the CP-C system components CP 6071.400, CP 6071.800

Housing coupling CP-XL


For desktop mounting Catalogue 33, page 166

CP 6528.410

 Mounting cut-out for surfaces



Mounting cut-out on the enclosure side


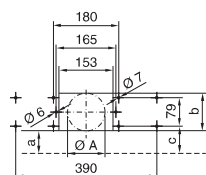


A or Ø A is manufactured to order in the case of Optipanel and Comfort Panel.

A_{max.} = 100 mm

	Installation depth mm	a	b	c
Comfort Panel	152/308	28.9	77.9	30.5
	191 – 464	43.1	82.5	48.1
Optipanel	150	34	65.5	28
Metal enclosure	—	1)	86	1)

1) Make the drilled holes/cut-out in the centre of the enclosure reinforcement plate.

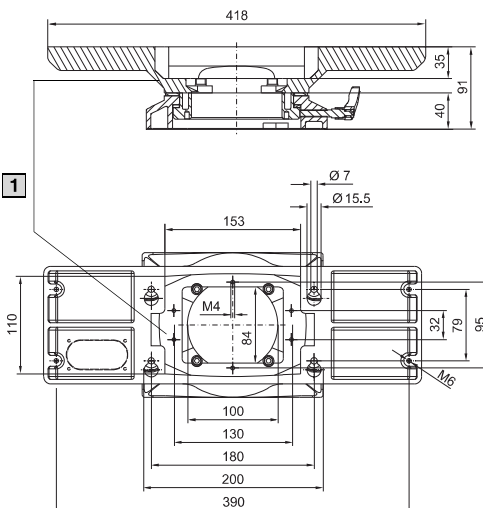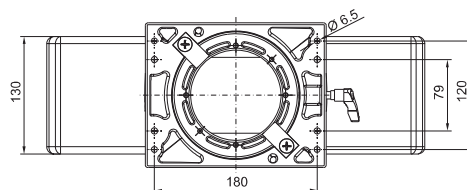

1 Space/preparation for assembly of adaptors with connector cut-out, 24-pole SZ 2477.010

Support arm, height-adjustable for support arm system CP-L


Catalogue 33, page 166

CP 6510.210

20 kg version





CP 6510.330, CP 6510.340

32 kg and 40 kg versions

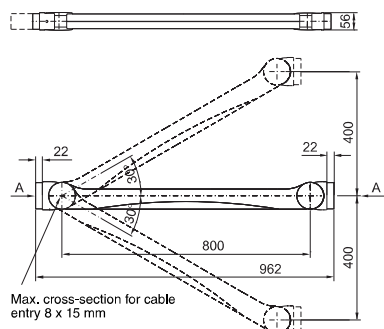

Max. cross-section for cable entry 8 x 15 mm

View A

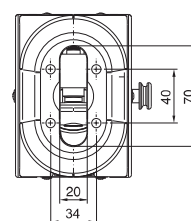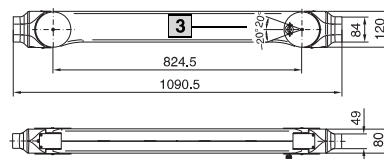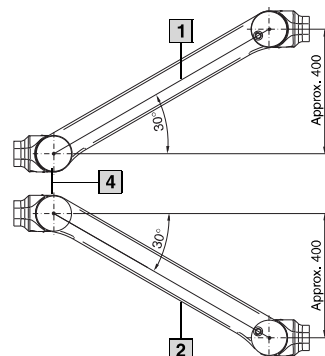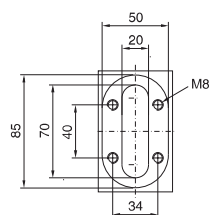

- 1 Top end stop
- 2 Bottom end stop
- 3 Lockable at +20° or -20°
- 4 Max. cross-section for cable entry 16 x 40 mm


Enclosures

Connection components


Pivot CP-L

With/without jib Catalogue 33, page 167

CP 6016.700

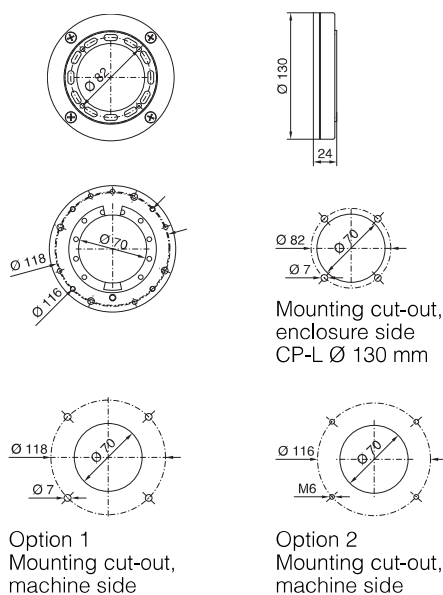


CP 6016.600

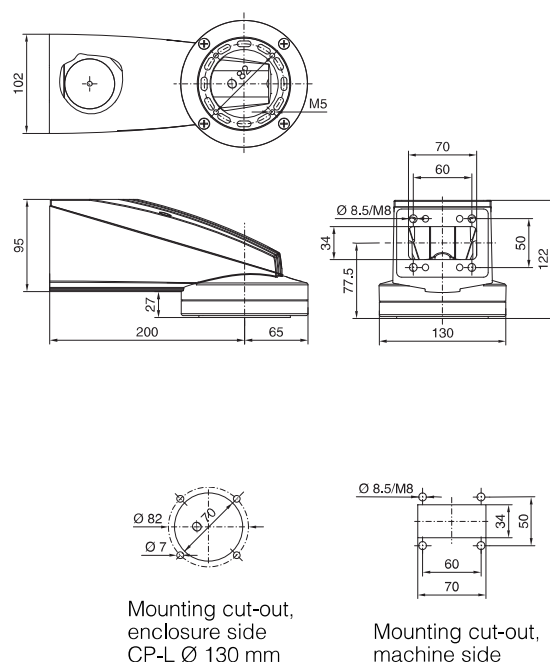

Support arm bracket 90° CP-L

Catalogue 33, page 167

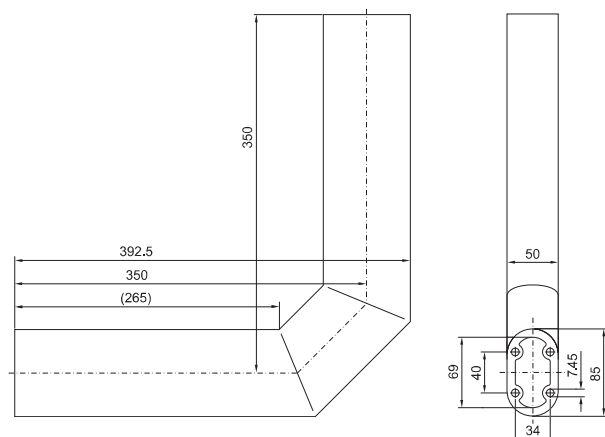


Colour RAL	Weight kg	Model No. CP
7035	3.4	6519.000



Angle adaptor 90°

Catalogue 33, page 168

CP 6501.090
CP-L to CP-S

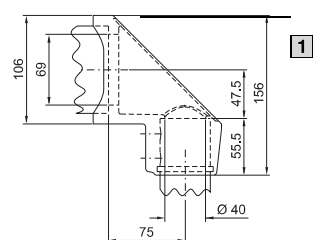

CP 6528.110
CP-XL to CP-L

 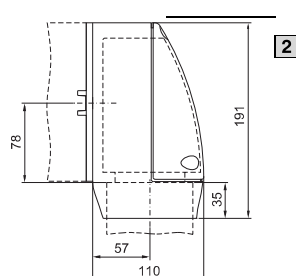

- 1 Removable plate 71 x 149 mm
- 2 Removable cover