


Enclosures

Stainless steel

Command panel housing with door


Catalogue 33, page 189

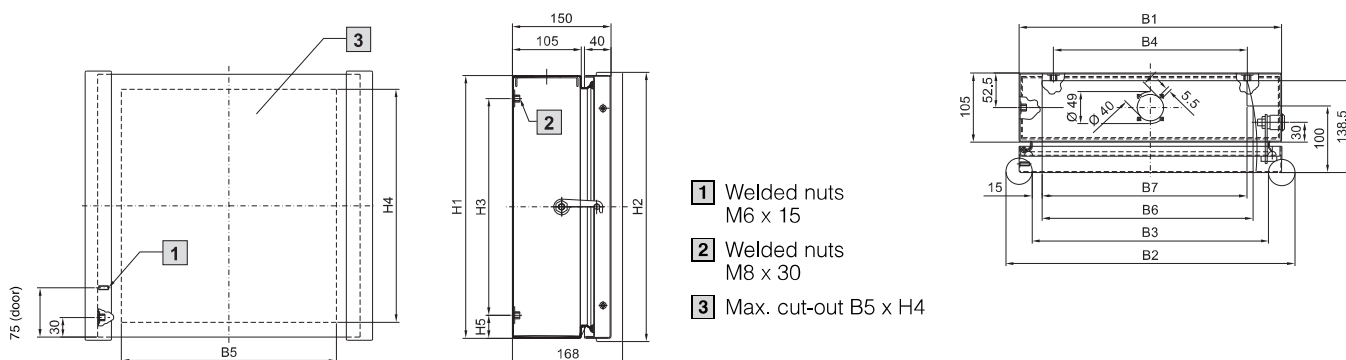


Model No. CP	6535.010	6536.010	6538.010	6539.010
Width (B1) mm	300	400	400	600
Height (H1) mm	300	300	400	400
Depth (T1) mm	150	150	150	150
B2 = Enclosure width with handle strips	340	440	440	640
B3 = Clearance opening, front	260	360	360	560
B4 = Spacing of mounting plate attachment	215	295	295	510
B5 = Max. front cut-out, width	225	325	325	525
B6 = Hinged width for depth 100 mm	220	320	320	520
B7 = Hinged width for depth 118 mm	206	310	310	510
H2 = Enclosure height with handle strips	310	310	410	410
H3 = Spacing of mounting plate attachment	250	250	330	330
H4 = Max. front cut-out, height	255	255	355	355
H5 = Distance from base – mounting plate attachment	25	25	35	35

Support arm system CP-S

Enclosure attachment CP-S, stainless steel Catalogue 33, page 191

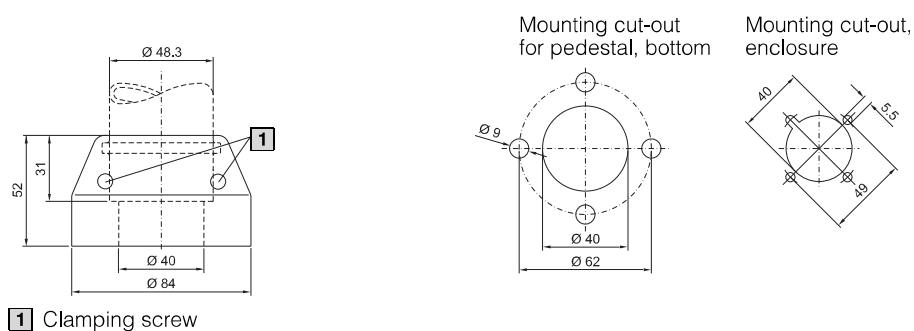


Housing coupling CP-S stainless steel Catalogue 33, page 191

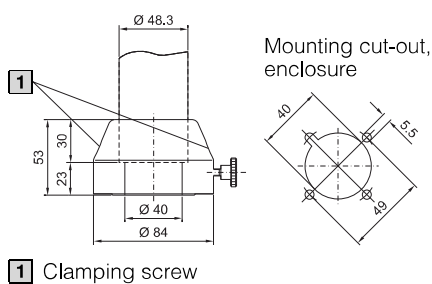

Support arm system CP-S


Wall/base mount, rigid

CP-S stainless steel Catalogue 33, page 191

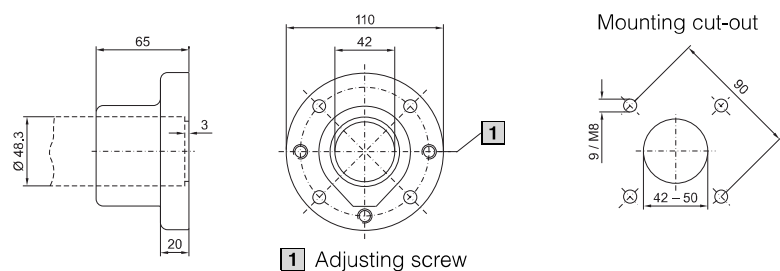


Base mount, rotating Catalogue 33, page 191


Rear attachment CP 6663.500

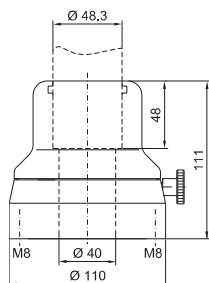


Mounting cut-out

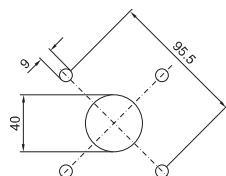

Front attachment CP 6663.400

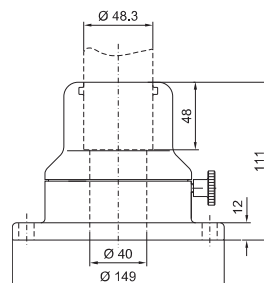


Mounting cut-out

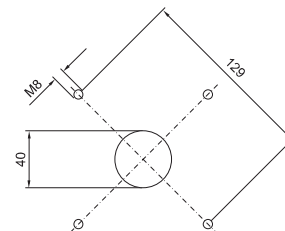


Wall console Catalogue 33, page 191


Rear attachment

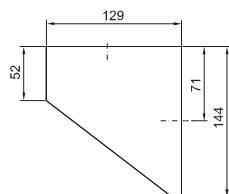



Mounting cut-out

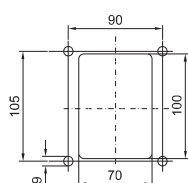

Front fastening

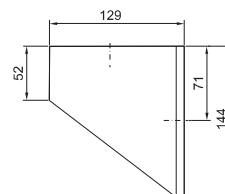


Mounting cut-out

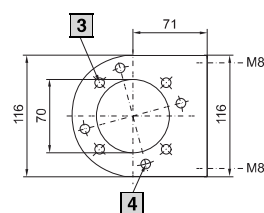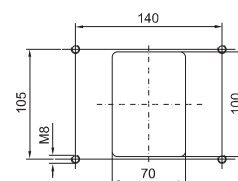

3 Hole for CP 6663.000

4 Hole for CP 6663.500

Tilting adaptor 10° Catalogue 33, page 191

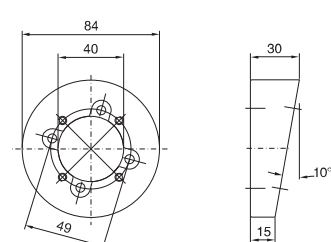

Mounting cut-out enclosure

