


CS New Basic enclosures

Catalogue 33, page 205

Section A – A

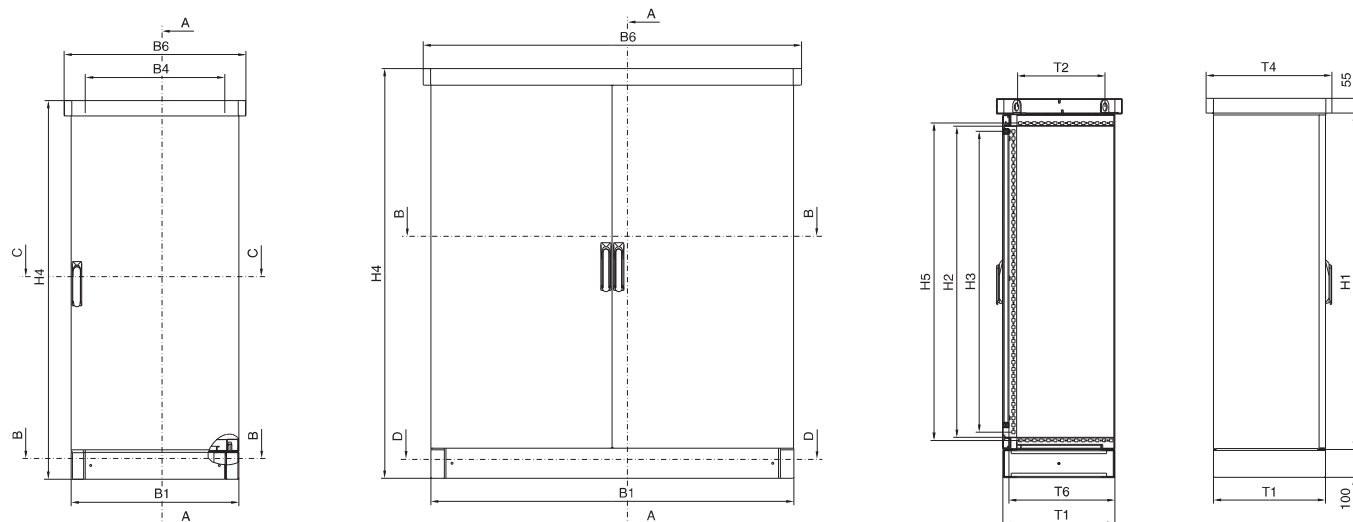

Section B – B

Section D – D

Section C – C

Section B – B

- B1 = Width of basic enclosure/standard base/plinth
- B2 = Clearance of enclosure frame
- B3 = Section length of system punchings
- B4 = Centre-to-centre distance between eyebolts
- B5 = Hole distance base/plinth – base mount
- B6 = Width of roof (overall width)
- B7 = Clearance of standard base/plinth opening
- B8 = System punchings
- B9 = System punchings
- H1 = Height of basic enclosure
- H2 = Clearance of enclosure frame
- H3 = Section length of system punchings
- H4 = Overall height
- H5 = System punchings
- T1 = Depth of basic enclosure/standard base/plinth
- T2 = Centre-to-centre distance between eyebolts
- T3 = Section length of system punchings
- T4 = Roof depth (overall depth)
- T5 = Hole distance base/plinth – base mount
- T6 = Maximum mounting depth
- T7 = Clearance of standard base/plinth opening

- B4 = Hole distance base/plinth – base mount
- B7 = System punchings

Enclosure	Width dimensions mm									Height dimensions mm					Depth dimensions mm						
Model No. CS	B1	B2	B3	B4	B5	B6	B7	B8	B9	H1	H2	H3	H4	H5	T1	T2	T3	T4	T5	T6	T7
9783.540	600	512	475	498	535	650	440	535	575	800	712	675	955	735	400	313	325	450	325	376	284.5
9783.550	600	512	475	498	535	650	440	535	575	1200	1112	1075	1355	1135	400	313	325	450	325	376	284.5
9783.530	600	512	475	498	535	650	440	535	575	1200	1112	1075	1355	1135	500	413	425	550	425	476	384.5
9783.510	800	712	675	698	735	850	640	735	775	800	712	675	955	735	400	313	325	450	325	376	284.5
9783.520	800	712	675	698	735	850	640	735	775	1200	1112	1075	1355	1135	400	313	325	450	325	376	284.5
9783.610	800	712	675	698	735	850	640	735	775	1200	1112	1075	1355	1135	500	413	425	550	425	476	384.5
9784.520	1200	1112	1075	1135	1250	1040	1135	1175	–	1200	1112	1075	1355	1135	400	313	325	450	325	376	284.5
9784.620	1200	512	475	1135	1250	1040	1135	1175	–	1200	1112	1075	1355	1135	400	313	325	450	325	376	284.5
9784.540	1200	1112	1075	1135	1250	1040	1135	1175	–	1200	1112	1075	1355	1135	500	413	425	550	425	476	384.5
9784.640	1200	512	475	1135	1250	1040	1135	1175	–	1200	1112	1075	1355	1135	500	413	425	550	425	476	384.5