

 
Climate control

Enclosure heaters


Enclosure heaters

Continuous thermal output 10 – 800 W Catalogue 33, page 471

Without fan



With fan

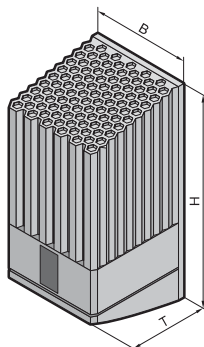

Without fan


Model No. SK	W (B) mm	H mm	D (T) mm
3105.310	45	120	46
3105.320	45	120	46
3105.330	64	155	56
3105.340	64	155	56
3105.350	64	230	56
3105.360	90	165	75
3105.370	90	180	75

With fan


Model No. SK	W (B) mm	H mm	D (T) mm
3105.380	103	200	103
3105.390	103	200	103
3105.400	103	200	103
3105.410	103	200	103
3105.420	103	200	103
3105.430	103	200	103

SK 3105.380 – SK 3105.430

Befestigung auf Montageplatte

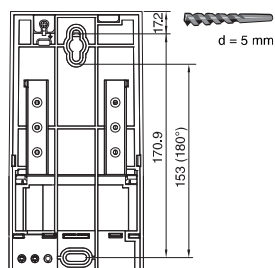


Befestigungsmöglichkeiten auf Tragschiene

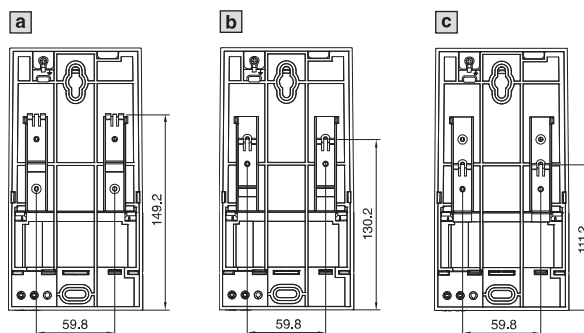


SK 3105.310/SK 3105.320

Befestigung auf Montageplatte

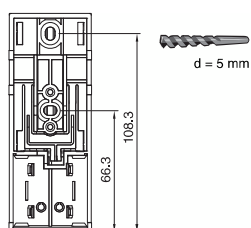


Befestigungsmöglichkeiten auf Tragschiene

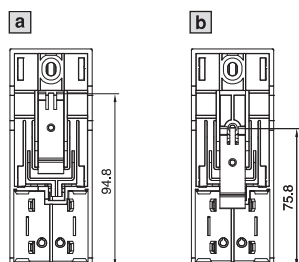


SK 3105.330 – SK 3105.350

Befestigung auf Montageplatte

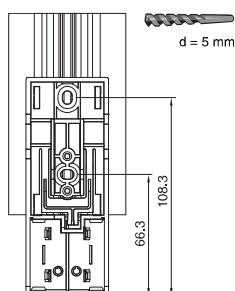


Befestigungsmöglichkeiten auf Tragschiene

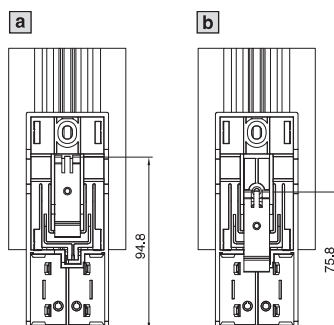

SK 3105.360/SK 3105.370

Befestigung auf Montageplatte

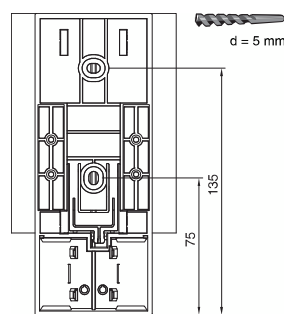

Befestigungsmöglichkeiten auf Tragschiene

