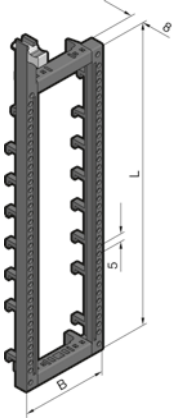


RiLine accessories: For RiLine60 component adaptors

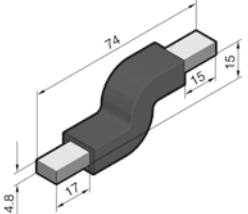
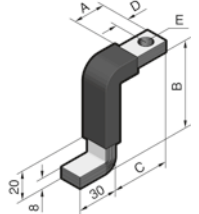
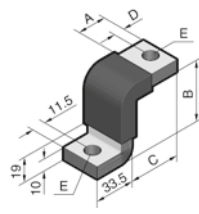
Support frame

Catalogue 33, page 320

For OM adaptor and OM support				
Width (B) mm	45	45	55	55
Length (L) mm	170	237	170	237
Model No. SV	9341.800	9341.820	9341.830	9341.850

Connection bracket

Catalogue 33, page 322

For circuit-breaker component adaptor												
Dimensions ¹⁾ mm	6 x 9 x 0.8				10 x 15.5 x 0.8				10 x 32 x 1			
A mm	—				26	19	23	19	26	29	28	—
B mm	—				65	66	71	67	51	57	62	—
C mm	—				43	36	40	36	62	46	38	—
D mm	—				9	10	9	7	9	12	14	—
E mm	—				Ø 11	Ø 11	Ø 11	Ø 8	Ø 12	Ø 12	Ø 12	—
Model No. SV	9342.570				9342.660	9342.670	9342.680	9342.690	9342.770	9342.780	9342.790	—

¹⁾ Number of membranes x membrane width x membrane thickness.