
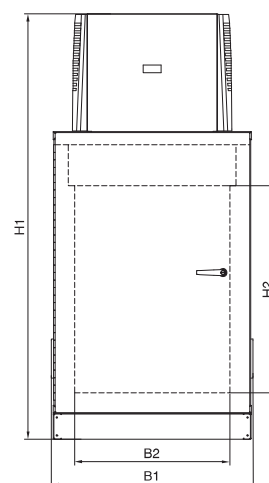


Basic Safe

Catalogue 33, page 504

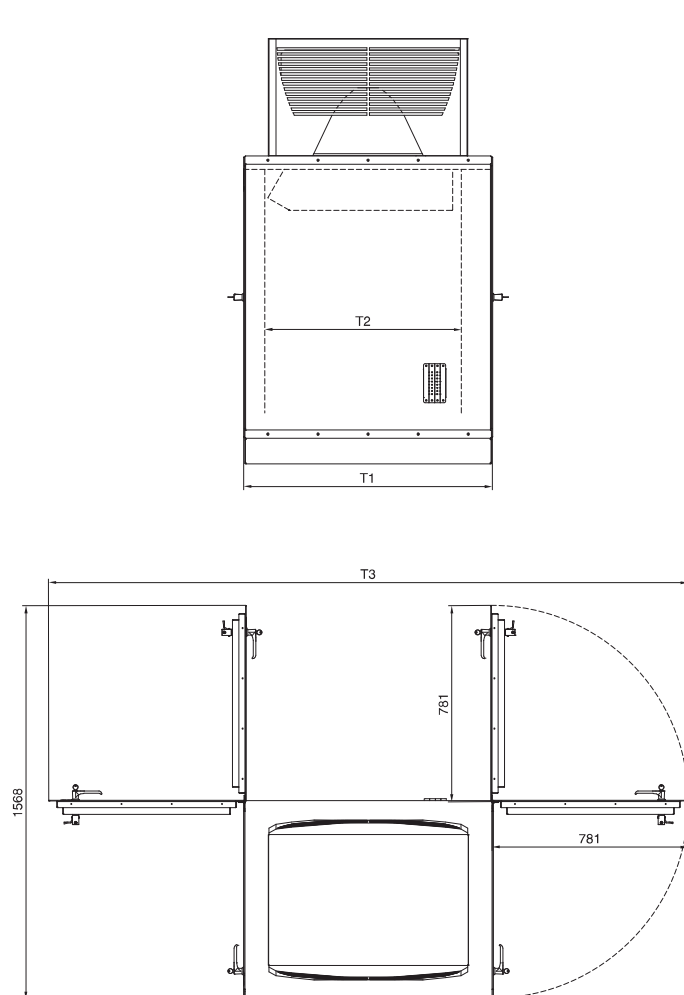

Model No. LS	B1 mm	B2 mm	H1 mm	H2 mm	T1 mm	T2 mm	T3 mm
7999.898	806	620	1699	827	1319	1024	2746

B = Width
T = Depth


Modular Safe/Modular Safe Extend

Catalogue 33, page 505/506

Step-by-step growth of your IT

- Physical hardware protection at high levels of security with fire and theft protection; extinguisher water- and flue gas-tight.
- Multi-functional protection solution for 482.6 mm (19") technology, network/hardware components.
- Modular, mobile security with form-fit connection technology.
- Fire- and theft-proof components may be built around existing, pre-configured network and server enclosures without interruptions to the system.
- Site changes or extensions are easily achieved at any time.


Modular safe units can be effortlessly connected with the computer operational. Each module is equipped with an operator and servicing door plus customer-specific accessories.

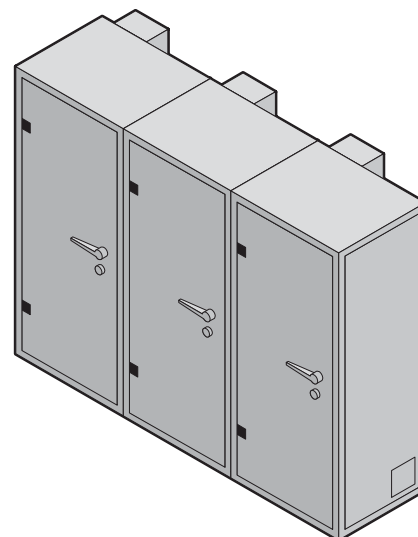


Modular Safe Extend

Catalogue 33, page 506


Single-leaf door at the front/double door at the rear

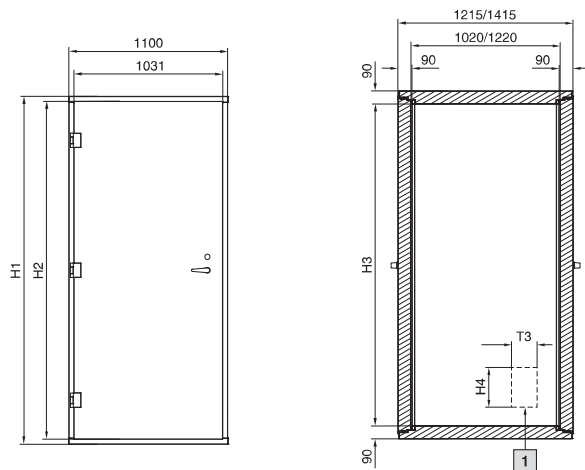


1 Cable duct

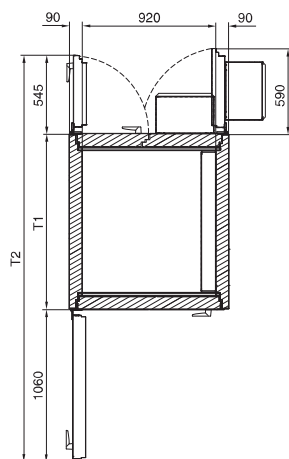

Double doors front and rear

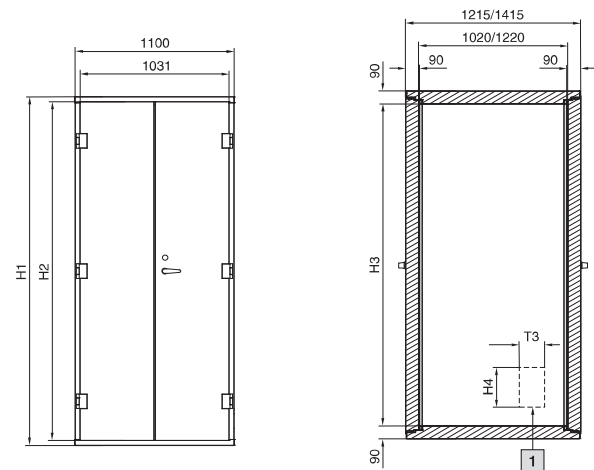

1 Cable duct

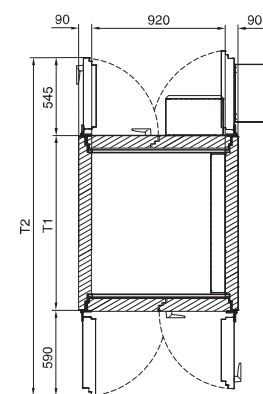

Model No. LS	H1 mm	H2 mm	H3 mm	H4 mm	T1 mm	T2 mm	T3 mm	Internal depth mm
7999.896	2210	2141	2030	169	1204	2809	262	1020
7999.897	2410	2341	2230	169	1204	2809	262	1020
7999.983	2210	2141	2030	169	1404	3009	262	1220
7999.987	2410	2341	2230	169	1404	3009	262	1220

Model No. LS	H1 mm	H2 mm	H3 mm	H4 mm	T1 mm	T2 mm	T3 mm	Internal depth mm
7999.896	2210	2141	2030	169	1204	2339	262	1020
7999.897	2410	2341	2230	169	1204	2339	262	1020
7999.983	2210	2141	2030	169	1404	2539	262	1220
7999.987	2410	2341	2230	169	1404	2539	262	1220

T = Depth