


Base/plinth, complete


Stainless steel for ES, PC-ES stainless steel, AP stainless steel Catalogue 33, page 552

Base/plinth, 100 mm high

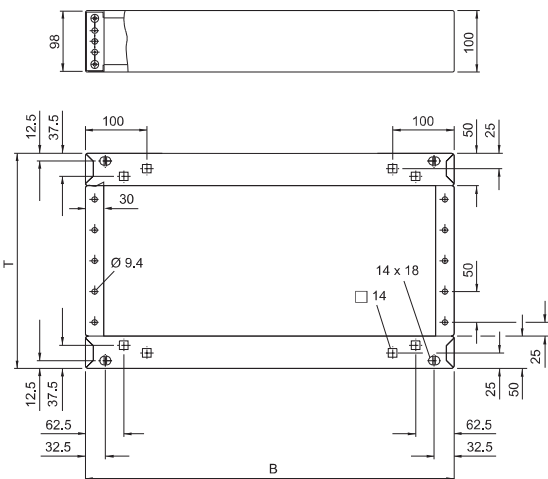

T = Enclosure depth – 50 mm
B = Enclosure width

Base/plinth, 200 mm high

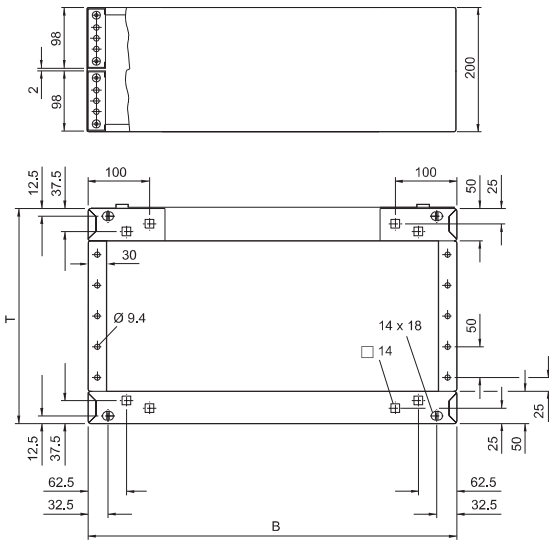


T = Enclosure depth – 50 mm
B = Enclosure width

Cross member

for TS, CM, TP, PC, IW, ES, adjustable Catalogue 33, page 552

TS 8601.450, TS 8601.680

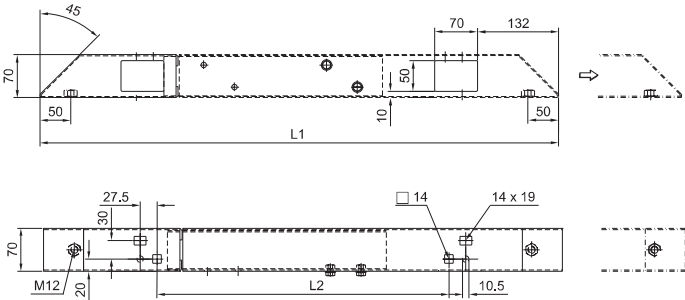

Model No. TS	For enclosure depth mm	L 1	L 2
8601.450	400	644	275
	500	744	375
8601.680	600	844	475
	800	1044	675