




### Swing frame, small

Catalogue 33, page 733

For 600 mm wide enclosures

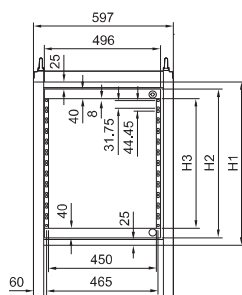

For 800 mm wide enclosures  
optionally at the side or in the centre

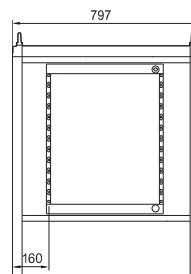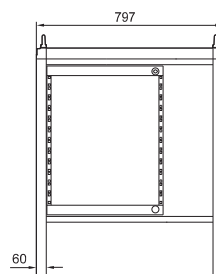

Height units	3 U	6 U	9 U	12 U	15 U	18 U
<b>Model No. SR</b>	<b>2377.030</b>	<b>2377.060</b>	<b>2377.090</b>	<b>2377.120</b>	<b>2377.150</b>	<b>2377.180</b>
H1 mm	275	408	541	675	808	941
H2 mm	217	350	483	617	750	883
H3 mm	137	270	403	537	670	803

Installation depth T max. = mm with dimension D<sup>1)</sup> of at least 45 mm

Enclosure width mm	600	800	800
Installation	central	side	central
Enclosure depth mm	T max.	T max.	T max.
400	185	310	310
500	185	410	370
≥ 600	185	500	370


<sup>1)</sup> D = Distance from the inner edge of the door to the front edge of the swing frame may be installed deeper on a 25 mm pitch pattern.

# System accessories


## 482.6 mm (19") installation system

### Examples for TS

**Partial installation** with 600 and 800 mm wide enclosures, each in the uppermost or lowest position.

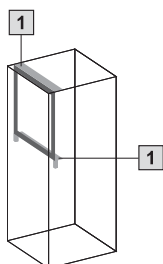

At the front

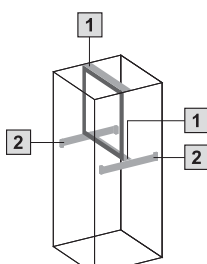


Set back

- 1** Installation kit for swing frame, small.
- 2** PS punched sections without mounting flanges 23 x 73 mm to match the enclosure depth in conjunction with 4 support brackets TS 8800.330 (two are included with the supply of the installation kit).


**Note:**

Height compensation between the 25 mm pitch pattern of holes in the enclosure and the height units of the swing frame is achieved by the support brackets TS (two are included with the supply of the installation kit).

**Partial installation, centre**  
in 600 and 800 mm wide enclosures.

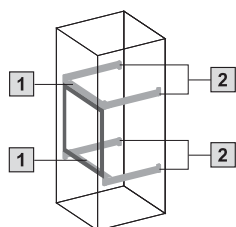

At the front

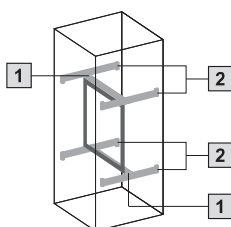

Set back

**Side installation**

With an enclosure depth of 600 or 800 mm, side installation of a small swing frame is identical to installation parallel to the front. For access to the swing frame we recommend the hinges for the TS side panel, see Catalogue 33, page 569.

