


Verkkokaapit TS 8

Päälueetelo 33, sivu 105, 106

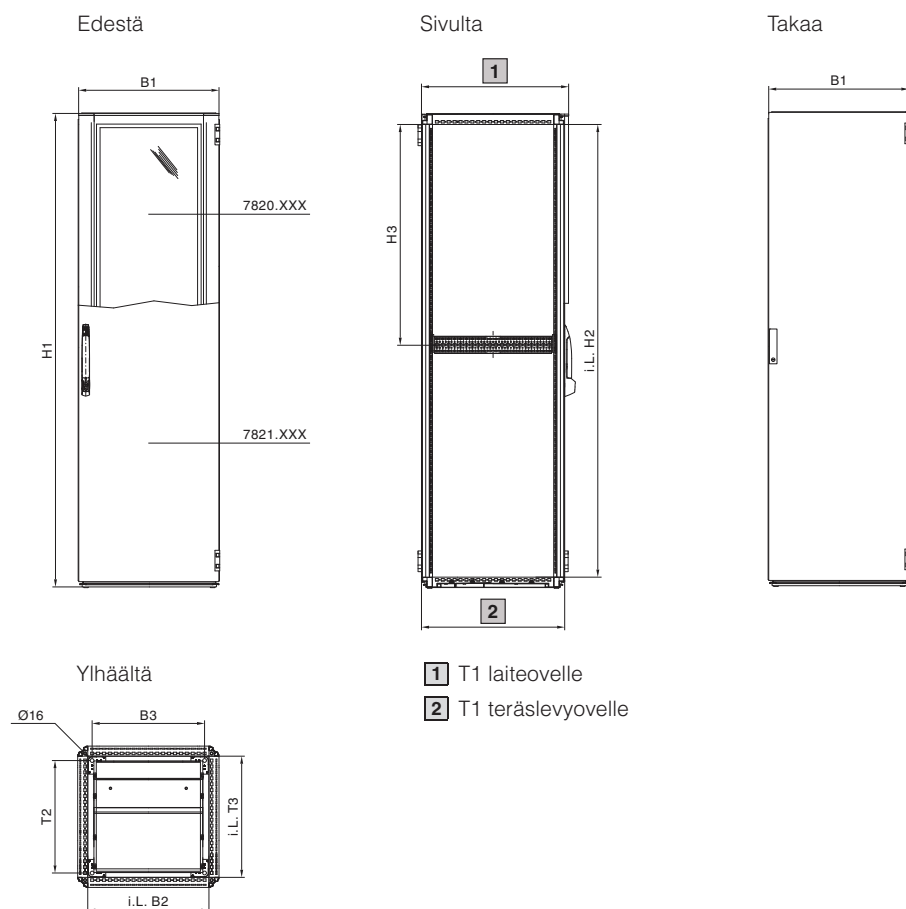

i.L. = Sisämitta

Til.nro DK		Leveysmitta mm			Korkeusmitta mm			Syvyysmitta mm			
Laiteovi	Teräslevyovi	B1	B2	B3	H1	H2	H3	T1 laiteovi	T1 teräslevyovi	T2	T3
7820.100	7821.100	597	512	475	805	712	431	622	605	512	475
7820.200	7821.200	597	512	475	1005	912	531	622	605	512	475
7820.240	7821.240	797	712	675	1005	912	531	622	605	512	475
7820.300	7821.300	597	512	475	1205	1112	631	622	605	512	475
7820.340	7821.340	797	712	675	1205	1112	631	622	605	512	475
7820.350	—	797	712	675	1205	1112	631	822	—	712	675
7820.410	7821.410	597	512	475	1405	1312	731	822	805	712	675
7820.500	7821.500	597	512	475	1605	1512	831	822	805	512	475
7820.510	7821.510	597	512	475	1605	1512	831	822	805	512	675
7820.600	7821.600	597	512	475	1805	1712	931	622	605	512	475
7820.610	7821.610	597	512	475	1805	1712	931	822	805	712	675
7820.650	7821.650	797	712	675	1805	1712	931	822	805	712	675
7820.670	7821.670	797	712	675	1805	1712	931	1022	1005	912	875
7820.700	7821.700	597	512	475	2005	1912	1031	622	605	512	475
7820.710	7821.710	597	512	475	2005	1912	1031	822	805	712	675
7820.730	7821.730	597	512	475	2005	1912	1031	1022	1005	912	875
7820.740	7821.740	797	712	675	2005	1912	1031	622	605	512	475
7820.750	7821.750	797	712	675	2005	1912	1031	822	805	712	675
7820.770	7821.770	797	712	675	2005	1912	1031	1022	1005	912	875
7820.800	7821.800	597	512	475	2205	2112	1031	622	605	512	475
7820.810	7821.810	597	512	475	2205	2112	1031	822	805	712	675
7820.850	7821.850	797	712	675	2205	2112	1031	822	805	712	675