



# Enclosures

## PC enclosure systems



### PC enclosure systems

with keyboard drawer

With glazed door and drawer  
PC 5366.000, PC 5368.000

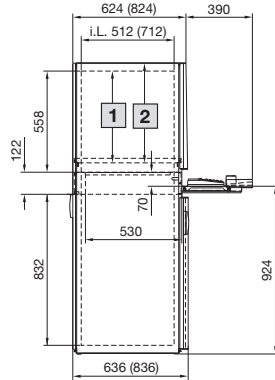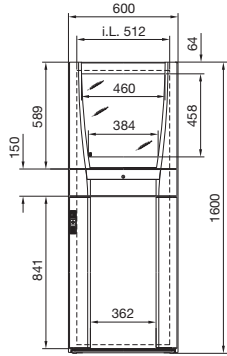



With mounting compartment, small and drawer  
PC 5366.300

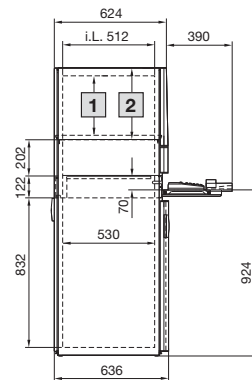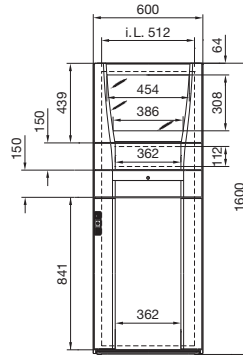

- 1 Max. 505, adjustable on a 25 mm pitch pattern
- 2 Max. 547, adjustable on a 25 mm pitch pattern

- 1 Max. 355, adjustable on a 25 mm pitch pattern
- 2 Max. 397, adjustable on a 25 mm pitch pattern

With mounting compartment, large and drawer  
PC 5366.400

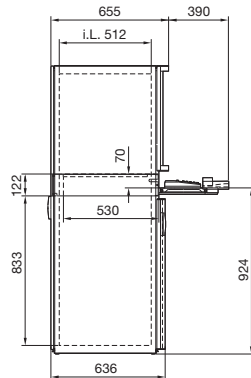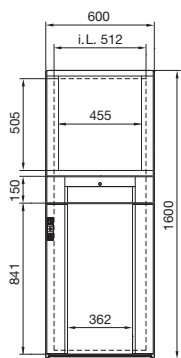

i.L. = Clearance width


		Model No. PC				
		Depth 636 mm	5366.000	5366.300	5366.400	
		Depth 836 mm	5368.000	-	-	
Supply includes	Version	Material	Colour RAL			
Enclosure	Enclosure structure with one-piece side panels and roof	Sheet steel, 1.5 mm	7035 textured	■	■	■
	Gland plates, three-part (5368.000, four-part)	Sheet steel, 1.5 mm	Zinc-plated	■	■	■
Rear door	With locking rod and double-bit insert, r/h hinge	Sheet steel, 2.0 mm	7035 textured	■	■	■
	With support frame latched from the inside <sup>1)</sup> , r/h hinge	Sheet steel, 1.5 mm	7015	■	■	-
Glazed door, top	Vertical decorative trim panels	Plastic to UL 94-V0	7035	■	■	-
	Pane with screen-printed mask	Toughened safety glass 4.0 mm	7015			
Mounting compartment, large, top	Vertical bars, latched from the inside <sup>1)</sup> , r/h hinge	Aluminium section	7035	-	-	■
	Installation plate	Sheet steel, 1.5 mm	7015			
	Trim strip top/bottom	Plastic to UL 94-V0	7035			
Component shelf for monitor	Slotted, permanently installed	Sheet steel, 1.5 mm	7015	■	■	-
Drawer for keyboard	Enclosure	Sheet steel, 1.5 mm	7035	■	■	■
	Keyboard extension piece with cable support, pull-out mousepad and keyboard cradle	Sheet steel, 1.5 mm	7035	■	■	■
	Trim panel with handle strip, folded as handrest, with lock no. 3524 E	Plastic to UL 94-V0	7035/7015/9006			
Mounting compartment, small	R/h hinge, screw-fastened from the inside on the left, folded mounting plate	Sheet steel, 1.5 mm	7015	-	■	-
	Decorative side trim panels	Plastic to UL 94-V0	7035			
Bottom door	Vertical bars with locking rod and double-bit insert, r/h hinge	Aluminium section	7035	■	■	■
	Door or installation plate folded	Sheet steel, 1.5 mm	7015			

<sup>1)</sup> With unlatching for top glazed door


### PC enclosure systems

with folding keyboard or desk section

With glazed door and fold-out tray  
PC 5366.100

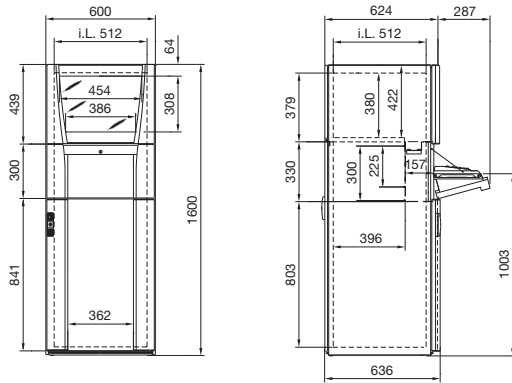

With glazed door and desk section  
PC 5366.200

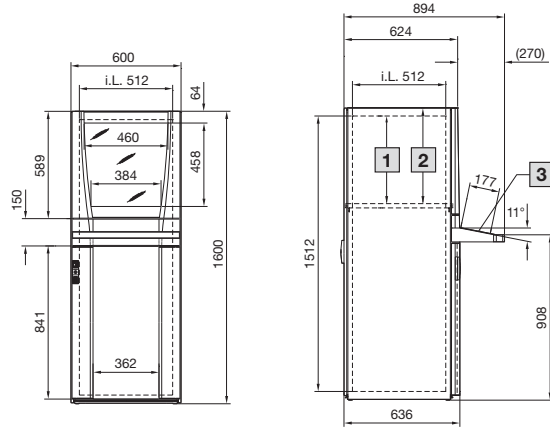

- 1 Max. 505, adjustable on a 25 mm pitch pattern
- 2 Max. 547, adjustable on a 25 mm pitch pattern
- 3 Max. installation area 540 x 175 mm

i.L. = Clearance width

				Model No. PC		
				Depth 636 mm	5366.100	5366.200
Supply includes	Version	Material	Colour RAL			
Enclosure	Enclosure structure with moulded side panels and roof	Sheet steel, 1.5 mm	7035 textured	■	■	
	Gland plates, three-part	Sheet steel, 1.5 mm	Zinc-plated			
Rear door	With locking rod and double-bit insert, r/h hinge	Sheet steel, 2.0 mm	7035 textured	■	■	
Glazed door, top	With support frame latched from the inside <sup>1)</sup> , r/h hinge	Sheet steel, 1.5 mm	7015			
	Vertical decorative trim panels	Plastic to UL 94-V0	7035	■	■	
	Pane with screen-printed mask	Toughened safety glass 4.0 mm	7015			
Component shelf for monitor	Slotted, permanently installed	Sheet steel, 1.5 mm	7015	■	■	
Fold-out tray for keyboard	Enclosure with mouse support and cut-out in the rear panel, width 482.6 mm (19) x height 4 U, for rear attachment	Sheet steel, 1.5 mm	7035			
	Trim panel hinged at the bottom, with 2 retaining cords, with lock no. 3524 E	Plastic to UL 94-V0	7035/7015/9006	■		–
Desk section	Keyboard support with mousepad extension piece and 2 nylon loop tapes for keyboard	Sheet steel, 1.5 mm	7035			
	Enclosure with removable cover top and bottom	Sheet steel 1.5 mm/2.0 mm	7035			
Bottom door	Trim strip, top and handle strip	Plastic to UL 94-V0	7035/7015/9006	–		■
	Vertical bars with locking rod and double-bit insert, r/h hinge	Aluminium section	7035	■	■	
	Door or installation plate folded	Sheet steel, 1.5 mm	7015			

<sup>1)</sup> With unlatching for top glazed door