


### PC enclosure systems

With keyboard drawer

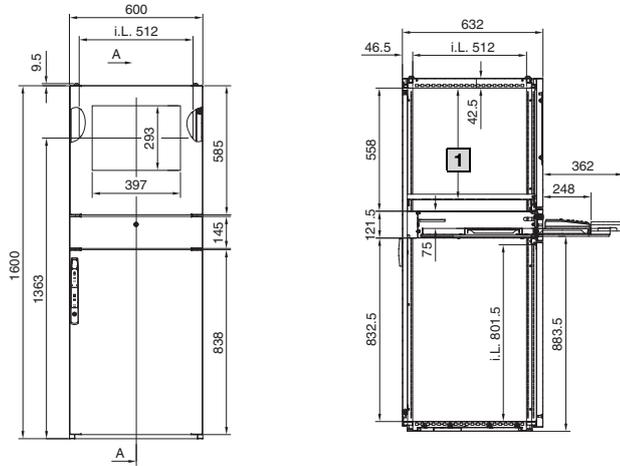

1 Max. 504.5, adjustable on a 25 mm pitch pattern

i.L. = Clearance width

				Model No. PC
				4650.100
				Width mm
				Height mm
				Depth mm
Enclosure	Solid top and sides, open at the bottom	Stainless steel, 1.5 mm	Brushed, grain size 400	■
	Gland plates, three-part	Stainless steel, 1.5 mm		
Rear door	With locking rod and double-bit insert, hinged on the r/h side	Stainless steel, 2.0 mm	Brushed, grain size 400	■
Glazed door, top	Latched from the inside <sup>1)</sup> , r/h hinge	Stainless steel, 1.5 mm	Brushed, grain size 400	■
	Viewing window	Toughened safety glass 4.0 mm		
Component shelf	Slotted, fixed installation	Sheet steel, 1.5 mm	RAL 7015	■
Drawer	Enclosure	Sheet steel, 1.25 mm	RAL 7035	
	Keyboard extension piece with cable support, plus pull-out mousepad	Sheet steel, 1.5 mm	RAL 7035	■
	Trim panel, folded as handrest, with fastener, lock no. 3524 E	Stainless steel, 1.25 mm	Brushed, grain size 400	
	<sup>1)</sup> With unlatching for top glazed door			■
Bottom door	With locking rod and double-bit insert, r/h hinge	Stainless steel, 1.5 mm	Brushed, grain size 400	■