


Kytöntäkaapit

Jakokaapit

Data Rack

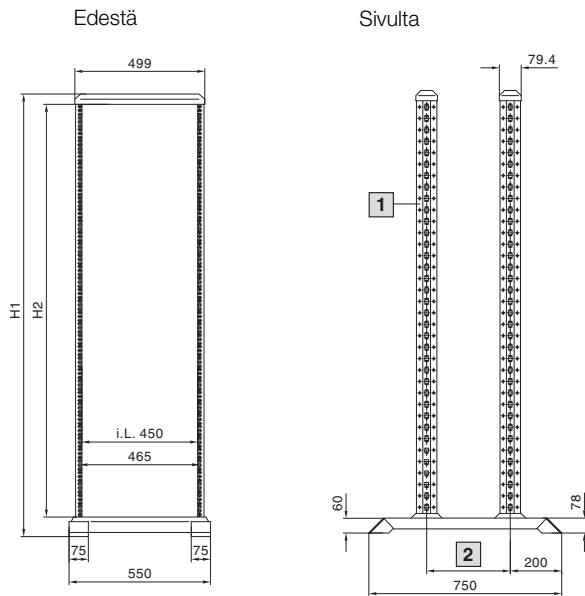

- 1 Toinen kiinnitystaso
DK 7296.000/31 HE
DK 7297.000/36 HE
DK 7298.000/40 HE
DK 7299.000/45 HE

- 2 50 mm rasterissa
(min. 150 – maks. 350)

i.L. = Clearance width

Til.nro DK	U	Korkeusmitta mm	
		H1	H2
7391.000	31	1500	i.L. 1382
7396.000	36	1722	i.L. 1604
7400.000	40	1900	i.L. 1782
7445.000	45	2122	i.L. 2004