


# Outdoor-Gehäuse

## CS New Basicgehäuse

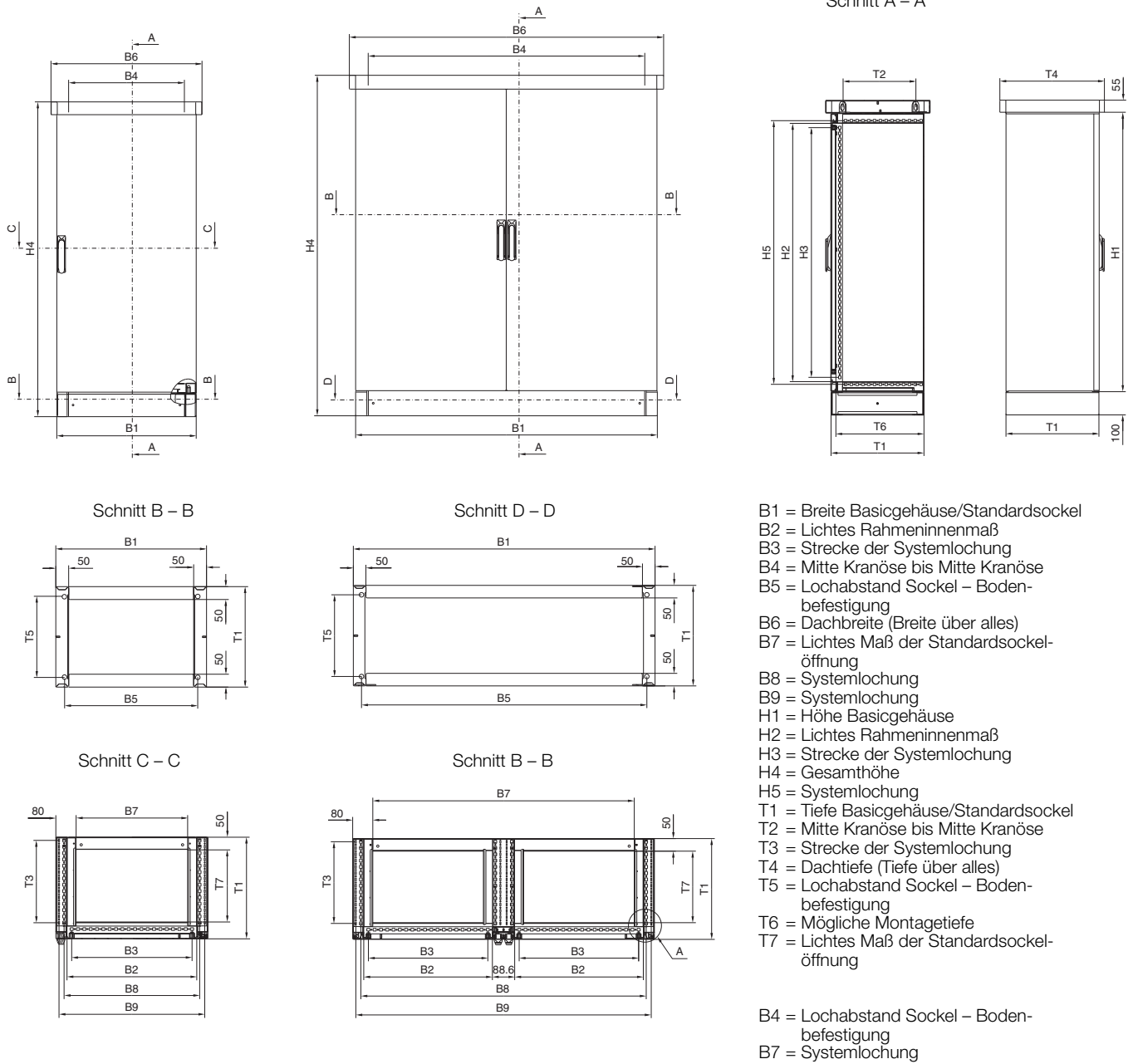

Gehäuse Best.-Nr. CS	Breitenmaße mm									Höhenmaße mm					Tiefenmaße mm						
	B1	B2	B3	B4	B5	B6	B7	B8	B9	H1	H2	H3	H4	H5	T1	T2	T3	T4	T5	T6	T7
9783.530	600	512	475	498	535	650	440	535	575	1200	1112	1075	1355	1135	500	413	425	550	425	476	384,5
9783.610	800	712	675	698	735	850	640	735	775	1200	1112	1075	1355	1135	500	413	425	550	425	476	384,5
9784.540	1200	512	475	1198	1135	1250	1040	1135	1175	1200	1112	1075	1355	1135	500	413	425	550	425	476	384,5